

Sealing brush strip



STRIP 1m


Straight rigid support 1 metre

- Provides a seal for the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Materials:
 - Frame: anodised aluminium
 - Brush: black polypropylene fibres with anti-UV treatment

Option

- Can be modified to order (subject to min quantity)

Aluminium strip

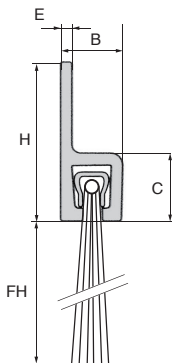

Can be modified to order

DISCOUNTS

Qty	1+	6+	25+	50+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	FH	H	B	C	E	Stock*	Price each 1 to 5
STRIP3-15-1000	1000	15	15	6,2	6,5	1,2	✓	13,77 €
STRIP3-20-1000	1000	20	15	6,2	6,5	1,2	✓	14,83 €
STRIP3-25-1000	1000	25	15	6,2	6,5	1,2	- New	16,20 €
STRIP5-25-1000	1000	25	25	8	8	1,2	✓	16,77 €
STRIP5-30-1000	1000	30	25	8	8	1,2	✓	17,36 €
STRIP5-40-1000	1000	40	25	8	8	1,2	- New	20,46 €
STRIP5-50-1000	1000	50	25	8	8	1,2	- New	21,72 €
STRIP8-40-1000	1000	40	50	13	13	2	✓	26,35 €
STRIP8-60-1000	1000	60	50	13	13	2	✓	32,43 €
STRIP8-80-1000	1000	80	50	13	13	2	✓	36,71 €
STRIP8-120-1000	1000	120	50	13	13	2	- New	68,22 €
STRIP8-150-1000	1000	150	50	13	13	2	- New	78,81 €

*Depending on availability - Dimensions in mm

Sealing brush strip



STRIP

Rigid support

- Provides a seal to the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Materials:



Frame: anodised aluminium

Brush: black polypropylene fibres



Aluminium
STRIP

Can be modified
to order

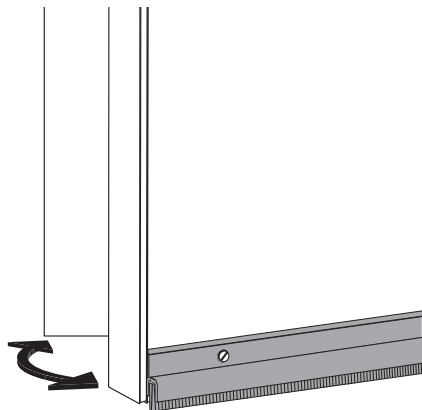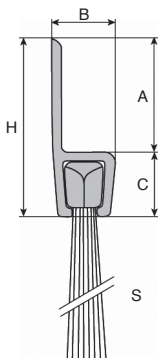

DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	A	B	C	H	S	Stock*	Price each 1 to 3
STRIP5-25	3000	17	8,0	8	25	25	✓	50,41 €
STRIP8-80	3000	37	12,6	13	50	80	✓	110,27 €

*Depending on availability - Dimensions in mm



Sealing brush strip


Right angled rigid support

STRIP

- Provides a seal for the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Material:
 - Frame: anodised aluminium
 - Brush: black polypropylene fibres with anti-UV treatment

Option

- Can be modified to order (subject to min quantity)

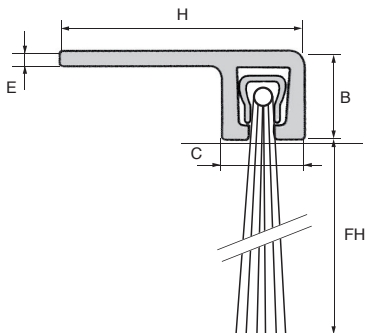

Can be modified to order

DISCOUNTS

Qty	1+	6+	25+	50+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	FH	H	B	C	E	Stock*	Price each 1 to 5
STRIP3-15F-1000	1000	15	15	6,5	6,5	1,2	✓	13,77 €
STRIP3-20F-1000	1000	20	15	6,5	6,5	1,2	✓	14,83 €
STRIP5-25F-1000	1000	25	25	8	8	1,2	✓	16,77 €
STRIP5-30F-1000	1000	30	25	8	8	1,2	✓	17,36 €
STRIP8-40F-1000	1000	40	50	13	13	2	✓	26,35 €
STRIP8-60F-1000	1000	60	50	13	13	2	✓	32,43 €
STRIP8-80F-1000	1000	80	50	13	13	2	✓	36,71 €

*Depending on availability - Dimensions in mm

Our other products




BLHB50

Right angled gearbox, bored shafts, up to 30 Nm



PSG125

 Spur gear - precision range, Pre-hardened Steel 35NCD6



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



G01

Single universal joint, Normal duty



CHB

Single output shaft, For CHB gearbox



MFBSC

Stainless steel flexible bellows coupling, Stainless steel - with cl...



ACLLPP

Latch for aluminium profile, Spring operated latch



BABtss

303 Stainless steel ball pin, 303 Stainless steel



KBS_UU

Stainless steel closed precision linear



RCX-6

Spherical tilt washer - DIN6319, convex



PLM-20SC

Threaded cylindrical magnet, With



CHAGC-AL

Screw-in garnet hinge, Screw-on

Complementary products



STRIPF

Sealing brush strip, 1m length



STRIP1000

Sealing brush strip, 1m length