

# Sealing brush strip



## STRIP 1m


### Straight rigid support 1 metre

- Provides a seal for the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Materials:
  - Frame: anodised aluminium
  - Brush: black polypropylene fibres with anti-UV treatment

### Option

- Can be modified to order (subject to min quantity)

*Aluminium strip*

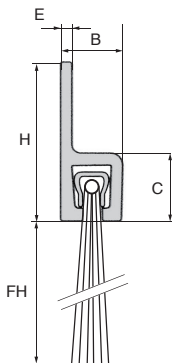

**Can be modified to order**

### DISCOUNTS

Qty	1+	6+	25+	50+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	FH	H	B	C	E	Stock*	Price each 1 to 5
STRIP3-15-1000	1000	15	15	6,2	6,5	1,2	✓	13,77 €
STRIP3-20-1000	1000	20	15	6,2	6,5	1,2	✓	14,83 €
STRIP3-25-1000	1000	25	15	6,2	6,5	1,2	- New	16,20 €
STRIP5-25-1000	1000	25	25	8	8	1,2	✓	16,77 €
STRIP5-30-1000	1000	30	25	8	8	1,2	✓	17,36 €
STRIP5-40-1000	1000	40	25	8	8	1,2	- New	20,46 €
STRIP5-50-1000	1000	50	25	8	8	1,2	- New	21,72 €
STRIP8-40-1000	1000	40	50	13	13	2	✓	26,35 €
STRIP8-60-1000	1000	60	50	13	13	2	✓	32,43 €
STRIP8-80-1000	1000	80	50	13	13	2	✓	36,71 €
STRIP8-120-1000	1000	120	50	13	13	2	- New	68,22 €
STRIP8-150-1000	1000	150	50	13	13	2	- New	78,81 €

\*Depending on availability - Dimensions in mm

# Sealing brush strip



## STRIP

## Rigid support

- Provides a seal to the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Materials:



Frame: anodised aluminium

Brush: black polypropylene fibres



Aluminium  
STRIP

Can be modified  
to order

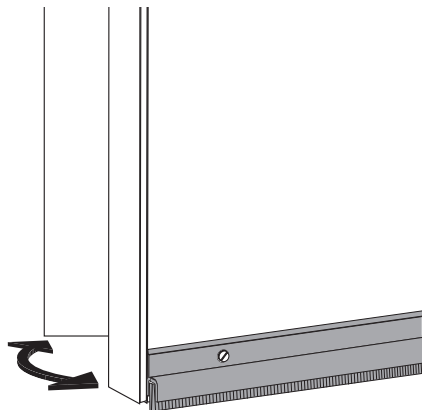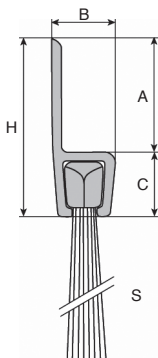

### DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	A	B	C	H	S	Stock*	Price each 1 to 3
STRIP5-25	3000	17	8,0	8	25	25	✓	50,41 €
STRIP8-80	3000	37	12,6	13	50	80	✓	110,27 €

\*Depending on availability - Dimensions in mm



# Sealing brush strip


## Right angled rigid support

## STRIP

- Provides a seal for the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Material:
  - Frame: anodised aluminium
  - Brush: black polypropylene fibres with anti-UV treatment

### Option

- Can be modified to order (subject to min quantity)

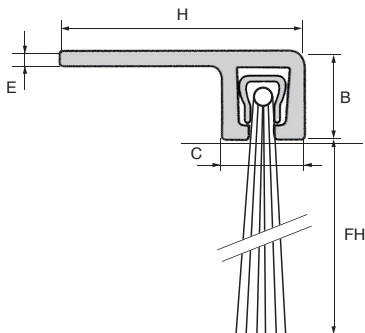

Can be modified to order

### DISCOUNTS

Qty	1+	6+	25+	50+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	FH	H	B	C	E	Stock*	Price each 1 to 5
STRIP3-15F-1000	1000	15	15	6,5	6,5	1,2	✓	13,77 €
STRIP3-20F-1000	1000	20	15	6,5	6,5	1,2	✓	14,83 €
STRIP5-25F-1000	1000	25	25	8	8	1,2	✓	16,77 €
STRIP5-30F-1000	1000	30	25	8	8	1,2	✓	17,36 €
STRIP8-40F-1000	1000	40	50	13	13	2	✓	26,35 €
STRIP8-60F-1000	1000	60	50	13	13	2	✓	32,43 €
STRIP8-80F-1000	1000	80	50	13	13	2	✓	36,71 €

\*Depending on availability - Dimensions in mm

## Our other products



DPAR\_DKON  
Progressive stop,  
Steel



UGH40  
H Type Guide units,  
For Ø40 actuators



NDS20  
Double cross clamp,  
Parallel



BTE  
Universal tension arm,  
For standard  
applications



PRF\_CLIP\_22  
Cable clip for  
aluminium profile, For  
electric and  
pneumatic cables




LRX  
Linear roller slide,  
Chariot - from 9410 N  
to 101000 N



PSG3  
Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6



 HLA19  
Right angle spiro  
bevel gearbox, Up to  
43Nm



SH0  
Parallel axis helical  
gear, Machined plastic



HTD5M\_09  
HTD Heavy duty  
timing pulley, HTD5



GLB  
Small 6 lobe threaded  
handle - female,



BPLF  
Ball transfer unit light  
duty, Light

## Complementary products



STRIP  
Sealing brush strip,  
1m length



STRIP  
Sealing brush strip,  
3m length