

# Sealing brush strip



## STRIP 1m


### Straight rigid support 1 metre

- Provides a seal for the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Materials:
  - Frame: anodised aluminium
  - Brush: black polypropylene fibres with anti-UV treatment

### Option

- Can be modified to order (subject to min quantity)

Aluminium strip

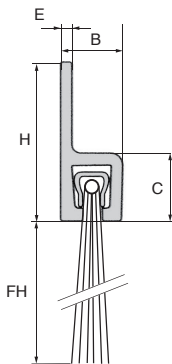

Can be modified to order

### DISCOUNTS

Qty	1+	6+	25+	50+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	FH	H	B	C	E	Stock*	Price each 1 to 5
STRIP3-15-1000	1000	15	15	6,2	6,5	1,2	✓	13,77 €
STRIP3-20-1000	1000	20	15	6,2	6,5	1,2	✓	14,83 €
STRIP3-25-1000	1000	25	15	6,2	6,5	1,2	- New	16,20 €
STRIP5-25-1000	1000	25	25	8	8	1,2	✓	16,77 €
STRIP5-30-1000	1000	30	25	8	8	1,2	✓	17,36 €
STRIP5-40-1000	1000	40	25	8	8	1,2	- New	20,46 €
STRIP5-50-1000	1000	50	25	8	8	1,2	- New	21,72 €
STRIP8-40-1000	1000	40	50	13	13	2	✓	26,35 €
STRIP8-60-1000	1000	60	50	13	13	2	✓	32,43 €
STRIP8-80-1000	1000	80	50	13	13	2	✓	36,71 €
STRIP8-120-1000	1000	120	50	13	13	2	- New	68,22 €
STRIP8-150-1000	1000	150	50	13	13	2	- New	78,81 €

\*Depending on availability - Dimensions in mm

# Sealing brush strip



## STRIP

## Rigid support

- Provides a seal to the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Materials:



Frame: anodised aluminium

Brush: black polypropylene fibres



Aluminium  
STRIP

Can be modified  
to order

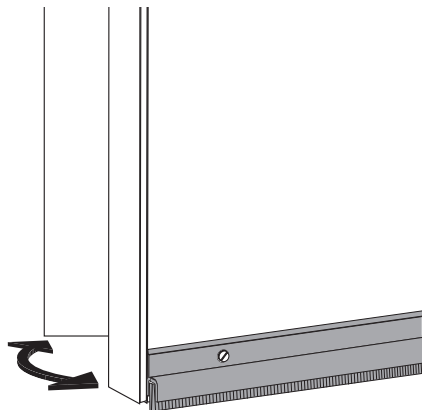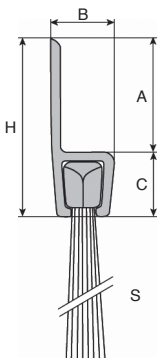

### DISCOUNTS

Qty	1+	4+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	A	B	C	H	S	Stock*	Price each 1 to 3
STRIP5-25	3000	17	8,0	8	25	25	✓	50,41 €
STRIP8-80	3000	37	12,6	13	50	80	✓	110,27 €

\*Depending on availability - Dimensions in mm



# Sealing brush strip


## Right angled rigid support

## STRIP

- Provides a seal for the bottoms of doors, gates or roller shutters
- Prevents rodent entry
- Material:
  - Frame: anodised aluminium
  - Brush: black polypropylene fibres with anti-UV treatment

### Option

- Can be modified to order (subject to min quantity)

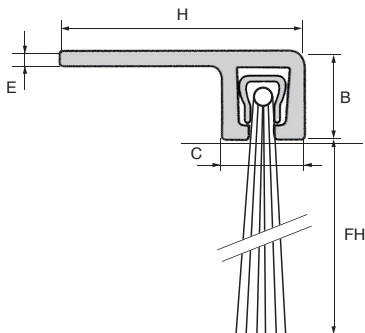

Can be modified to order

### DISCOUNTS

Qty	1+	6+	25+	50+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	FH	H	B	C	E	Stock*	Price each 1 to 5
STRIP3-15F-1000	1000	15	15	6,5	6,5	1,2	✓	13,77 €
STRIP3-20F-1000	1000	20	15	6,5	6,5	1,2	✓	14,83 €
STRIP5-25F-1000	1000	25	25	8	8	1,2	✓	16,77 €
STRIP5-30F-1000	1000	30	25	8	8	1,2	✓	17,36 €
STRIP8-40F-1000	1000	40	50	13	13	2	✓	26,35 €
STRIP8-60F-1000	1000	60	50	13	13	2	✓	32,43 €
STRIP8-80F-1000	1000	80	50	13	13	2	✓	36,71 €

\*Depending on availability - Dimensions in mm

## Our other products




DTR

Chain idler sprocket,  
Chain idler sprocket -  
Steel



STC

Shock Absorber - stop  
collar, Universal  
flange

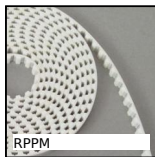

RPPM

RPP type belt per  
metre, RPP14 Steel  
cored polyurethane



QNU

Single row cylindrical  
roller bearing, Free  
inner ring



CHAE3030PA

Square decorative  
screwed hinges,  
Polyamide



SHO

Parallel axis helical  
gear, Machined plastic  
(delrin)



CHNrb

Warning chain with  
red and white links,  
Steel



BLHB60

Right angled gearbox,  
bored shafts, up to 70  
Nm



PTAF80-PAMF80

Articulated fixable  
foot with pressed  
base Ø80, Ø 80



B DPR

Holding arm, Rigid



BAC105

Storage bin, 8mm



PO

Pull handle - Multi-  
sector, Tapped  
recessed insert

## Complementary products



STRIP1000

Sealing brush strip,  
1m length



STRIP

Sealing brush strip,  
3m length