
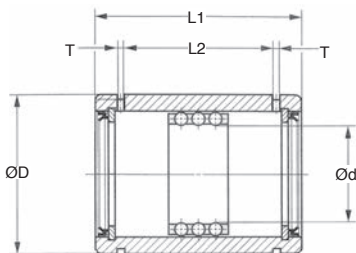


For combined rotary and linear movements

- Permits both linear and rotary movement
- Sealed
- Material: steel
- Stroke: should not exceed 80% of the max. stroke length indicated in the table
- Max. temperature: +120°C

Assembly

- Use shafts with hardness 58-64 HRC, Ra 0.2
- When mounted vertically use:
 - shaft: k5, m5
 - housing: H6, H7
- Otherwise use
 - shaft: n5, p6
 - housing: j6, j7

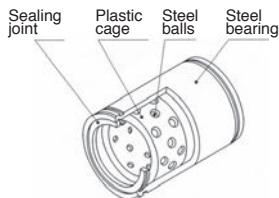

DISCOUNTS

Qty	1+	5+	10+	25+
Disc. List	-6%	-12%	On request	

Part number	Ød	ØD	L1	L2	T	Max. stroke (mm)	Static load Co (N)	Dynamic load C (N)	Weight (g)	Stock*	Price each 1 to 4
STU-8	8	15	24	12,3	1,5	14	211	315	16,5	✓	32,71 €
STU-10	10	19	30	15,5	1,5	16	466	659	30,7	✓	34,95 €
STU-12	12	23	32	17,1	1,5	17	822	1110	45,0	✓	37,22 €
STU-16	16	28	37	21,1	1,5	24	998	1230	74,0	✓	41,52 €
STU-20	20	32	45	26,8	2,0	32	1250	1390	107,0	✓	43,60 €
STU-25	25	37	45	26,8	2,0	32	1430	1450	121,0	✓	56,85 €
STU-30	30	45	65	45,1	2,5	65	3160	3110	215,0	✓	69,71 €
STU-35	35	52	70	50,1	2,5	75	3550	3290	342,0	-	82,47 €
STU-40	40	60	80	59,9	2,5	91	4810	4340	529,0	✓	104,30 €

*Depending on availability - Dimensions in mm

Our other products



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm



 
RPCpl

Swivel castor with double brake, Steel - Polyamide



BABFCFO

Ball pin socket, Mounting collar with a round flange



PTR

Idler chain sprocket, For standard applications



LRX

Linear roller slide, Chariot - from 9410 N to 101000 N




PRF4590_E

Bracket for aluminium profile, PRF4590



PF60

 Worm and wheel gear reducer, up to 118 Nm




RPP5

RPP heavy duty timing belt, RPP5



HLC24

 Right angle spiro bevel gearbox, Up to 78Nm



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



BTCW

Cap for square tube to be welded, To be welded



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation

Complementary products