

# Stroke rotary bush





## STU IKO

## For combined rotary and linear movements

- Permits both linear and rotary movement
- Sealed
- Material: steel
- Stroke: should not exceed 80% of the max. stroke length indicated in the table
- Max. temperature: +120°C

### Assembly

- Use shafts with hardness 58-64 HRC, Ra 0.2
- When mounted vertically use:  
shaft: k5, m5  
housing: H6, H7
- Otherwise use  
shaft: n5, p6  
housing: J6, J7

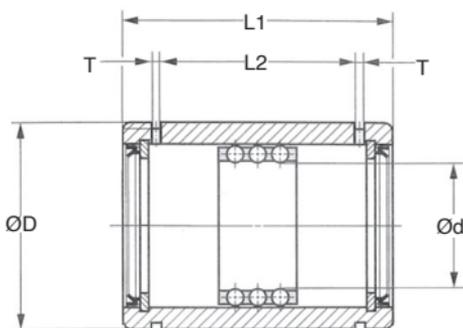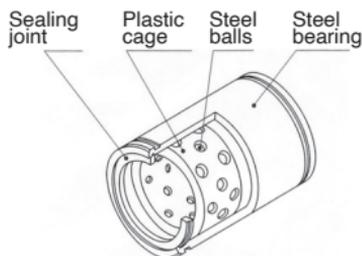

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc. List	-6%	-12%	On request	

Part number	Ød	ØD	L1	L2	T	Max. stroke (mm)	Static load Co (N)	Dynamic load C (N)	Weight (g)	Stock	Price each 1 to 4
										✓	
STU-8	8	15	24	12,3	1,5	14	211	315	16,5	✓	40,98 €
STU-10	10	19	30	15,5	1,5	16	466	659	30,7	✓	43,76 €
STU-12	12	23	32	17,1	1,5	17	822	1110	45,0	✓	46,63 €
STU-16	16	28	37	21,1	1,5	24	998	1230	74,0	✓	52,02 €
STU-20	20	32	45	26,8	2,0	32	1250	1390	107,0	✓	54,63 €
STU-25	25	37	45	26,8	2,0	32	1430	1450	121,0	-	71,23 €
STU-30	30	45	65	45,1	2,5	65	3160	3110	215,0	✓	87,35 €
STU-35	35	52	70	50,1	2,5	75	3550	3290	342,0	-	103,32 €
STU-40	40	60	80	59,9	2,5	91	4810	4340	529,0	-	130,71 €

\*Depending on availability - Dimensions in mm