
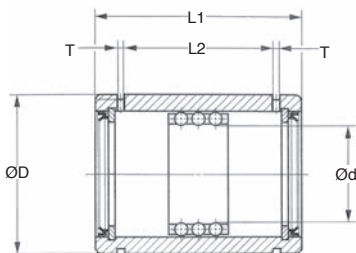


For combined rotary and linear movements

- Permits both linear and rotary movement
- Sealed
- Material: steel
- Stroke: should not exceed 80% of the max. stroke length indicated in the table
- Max. temperature: +120°C

Assembly

- Use shafts with hardness 58-64 HRC, Ra 0.2
- When mounted vertically use:
 - shaft: k5, m5
 - housing: H6, H7
- Otherwise use
 - shaft: n5, p6
 - housing: j6, j7

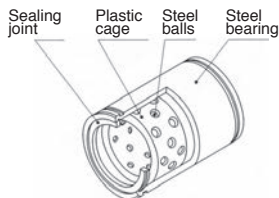

DISCOUNTS

Qty	1+	5+	10+	25+
Disc. List	-6%	-12%	On request	

Part number	Ød	ØD	L1	L2	T	Max. stroke (mm)	Static load Co (N)	Dynamic load C (N)	Weight (g)	Stock*	Price each 1 to 4
STU-8	8	15	24	12,3	1,5	14	211	315	16,5	✓	32,71 €
STU-10	10	19	30	15,5	1,5	16	466	659	30,7	✓	34,95 €
STU-12	12	23	32	17,1	1,5	17	822	1110	45,0	✓	37,22 €
STU-16	16	28	37	21,1	1,5	24	998	1230	74,0	✓	41,52 €
STU-20	20	32	45	26,8	2,0	32	1250	1390	107,0	✓	43,60 €
STU-25	25	37	45	26,8	2,0	32	1430	1450	121,0	✓	56,85 €
STU-30	30	45	65	45,1	2,5	65	3160	3110	215,0	✓	69,71 €
STU-35	35	52	70	50,1	2,5	75	3550	3290	342,0	-	82,47 €
STU-40	40	60	80	59,9	2,5	91	4810	4340	529,0	✓	104,30 €

*Depending on availability - Dimensions in mm

Our other products



BRI
Panel holder, Panel holder



HAS
Captive C washer, Slotted flat headed shoulder screw



MCLred
Reducing sleeve female/female, Cylindrical - steel



ERC
Quick fitting cable terminal, Fork



PR820
Idler sprocket for slat top chain, Rangs 820 and 815



R205
Die spring ISO10243, Heavy



LACT_SS
Adjustable Stainless steel cam lever, Male



UGAC_UGET
Actuator guide kit, Coupling for threaded cylinder end



SH1
Parallel axis helical gear, Machined plastic (delrin)



SH1
Parallel axis helical gear, Machined plastic (delrin)



BPM
Slotted spring plunger with ball tip, Stainless steel 303



PDM_PDV
Detectable plastic palm grip, blue thermoplastic

Complementary products