

# Single chain supplied by the metre


## Pitch

## 4.0 to

## 19.05 mm

## Steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of either 1, 5 metre (in box) or 50 metre (in chain reel) lengths depending on model

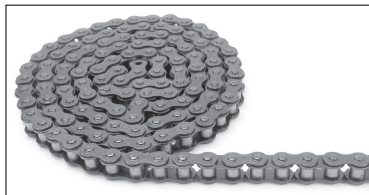

### Option


- American pitch (ASA) available on request

### Accessories

- TRE arm and PTR sprocket idlers
- Roll-Ring® RLR idler (tome 4 p.128 to p.141)



New in chain reel

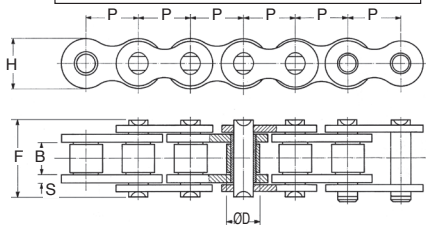

### DISCOUNTS **A**

No. metres	1+	10+	25+	55+
Discount	List	-5%	-10%	On request

### DISCOUNTS **B**

No. metres	1+	100+
Discount	List	On request

Part number	DIN	Pitch		Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Stock	Price per metre
		P (mm)	B (mm)								
<b>In box</b>											
SUA-4	-	4,00	2,70	2,50	6,8	4,1	-	1,8	1 metre	✓	Ⓐ185,10 €
SUA-6/M	04-1	6,00	2,80	4,00	7,8	5,0	0,60	3	5 metres	✓	Ⓐ12,64 €
SUA-250/M	-	6,35	3,30	3,30	8,0	6,0	-	4	5 metres	✓	Ⓐ15,49 €
SBR-8/M	05B-1	8,00	3,00	5,00	8,9	7,1	0,80	5	5 metres	✓	Ⓐ10,49 €
SBR-375/M	06B-1	9,52	5,72	6,35	14,1	8,2	1,30	9	5 metres	✓	Ⓐ8,08 €
SBR-500/M	08B-1	12,70	7,75	8,51	18,2	11,8	1,60	18	5 metres	✓	Ⓐ7,81 €
SBR-625/M	10B-1	15,88	9,65	10,16	20,9	14,7	1,70	22,4	5 metres	✓	Ⓐ9,74 €
SBR-750/M	12B-1	19,05	11,68	12,07	24,2	16,0	1,85	29	5 metres	✓	Ⓐ12,53 €
<b>In chain reel</b>											
SUA-6/M/T	04-1	6,00	2,80	4,00	7,8	5,0	0,60	3	50 metres		
SBR-8/M/T	05B-1	8,00	3,00	5,00	8,9	7,1	0,80	5	50 metres		
SBR-375/M/T	06B-1	9,52	5,72	6,35	14,1	8,2	1,30	9	50 metres		
SBR-500/M/T	08B-1	12,70	7,75	8,51	18,2	11,8	1,60	18	50 metres		
SBR-625/M/T	10B-1	15,88	9,65	10,16	20,9	14,7	1,70	22,4	50 metres		
SBR-750/M/T	12B-1	19,05	11,68	12,07	24,2	16,0	1,85	29	50 metres		

\*Depending on availability - Dimensions in mm

## Our other products



BPM

Slotted spring plunger with ball tip, Stainless steel 303



WJUM20

Drylin® W bearing block, Slide



RTN

BoWex® curved tooth gear coupling, Nylon



PITAss

Locking bolt, with T handle



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm




VELprf

Clip-on base for hook-and-loop strip, Polyamide



ZBconique

Machined plastic bevel gear, 1:1

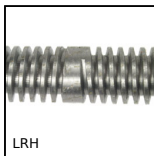

LRH

Bi-directional leadscrew, Bi-directional - 1 thread



CF

Cam follower, Standard - steel




PSP

Support profile, Panel support



BOX-TOR-D

Box set of Nitrile O-rings in nitrile, 18.00 x 2.00mm to 50.00 x

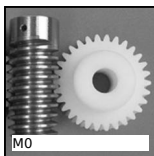

M0

Worm and wheel set, Machined plastic (delrin)

## Complementary products



SUA4\_L

Chain link, Steel



SUA4\_L

Chain link, Steel



PCS37K

Chain sprocket with hardened teeth, 9.525mm (DIN06B-1)



PCS50K

Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)