

Adjustable latch clamp with catch plate **StaSta**

SVG26 Span adjustable from 82 to 92mm



- Adjustable latch clamp with catch-plate

- Materials:

- Chromed steel
- Non treated 304 stainless steel

Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

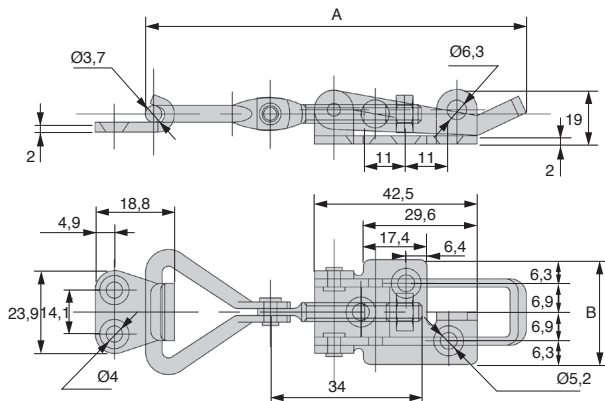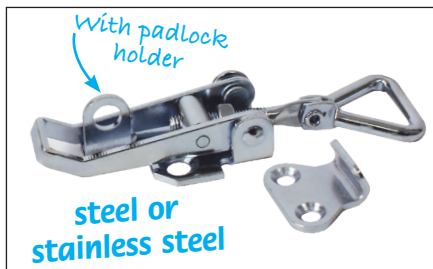

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Stock*	Price each 1 to 9
SVG26-82-92	82 to 92	26,4	Steel	Galvanised	48	✓	6,75 €
SVG26-82-92/SS	82 to 92	26,4	S-Steel 304	Natural	48	✓	11,32 €

*Subject to availability - Dimensions in mm



Ste Sta Adjustable latch clamp with catch plate

Span adjustable from 106.7 to 121.4mm **SVG32**

- Adjustable latch clamp with catch-plate
- Materials:
Chromed steel
Non treated 304
stainless steel

Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

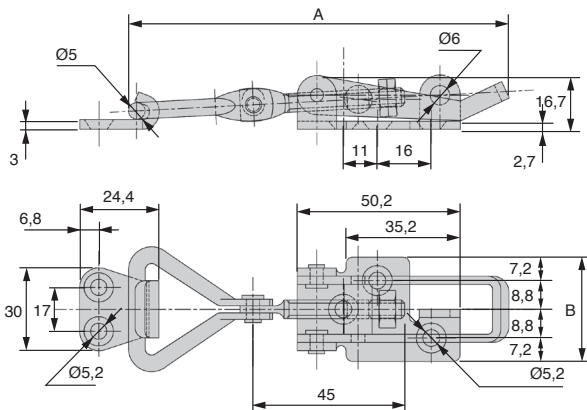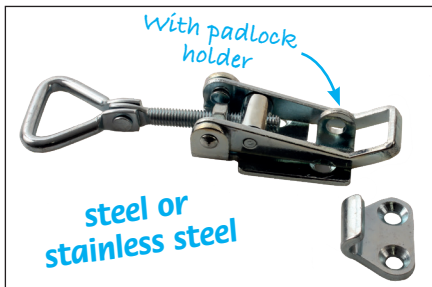

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Price each 1 to 9
SVG32-106-121	106.7 to 121.4	32	Steel	Galvanised	102	6.60 €
SVG32-106-121/SS	106.7 to 121.4	32	S-Steel 304	Natural	102	18.91 €

*Subject to availability - Dimensions in mm

Adjustable latch clamp with catch plate **Ste|Sta**

SVG39 Span adjustable from 118 to 130.5mm


- Adjustable latch clamp with catch-plate

- Materials:

- Chromed steel
- Non treated 304 stainless steel

Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

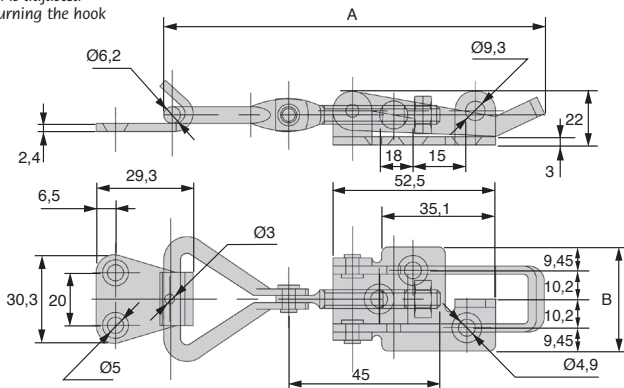

DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Stock*	Price each 1 to 9
SVG39-118-130	118 to 130,5	39,3	Steel	Galvanised	124	✓	11,51 €
SVG39-118-130/SS	118 to 130,5	39,3	S-Steel 304	Natural	124	✓	25,25 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel



SteSta Adjustable latch clamp with catch plate

Span adjustable from 174 to 190mm **SVG50**

- Adjustable latch clamp with catch-plate
- Screw fixing
- Materials:
 - Chromed steel
 - Non treated 304 stainless steel

Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

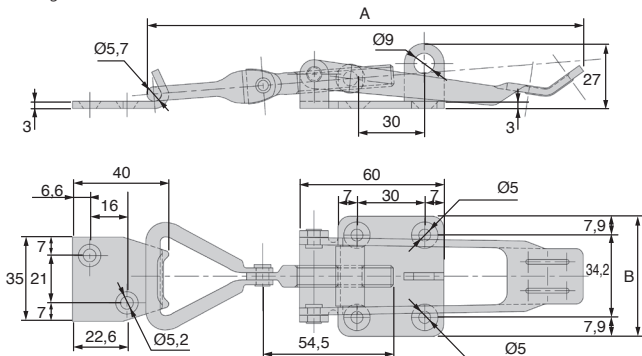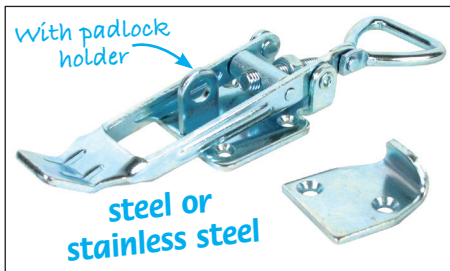

DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Stock*	Price each 1 to 9
SVG50-174-190	174 to 190	50	Steel	Galvanised	236	✓	14,75 €
SVG50-174-190/SS	174 to 190	50	S-Steel 304	Natural	236	-	48,36 €

*Subject to availability - Dimensions in mm

 
Our other products



BTCW
Cap for square tube to be welded, To be welded



RPP
Connecting plate for RPP type timing belts, RPP14



PRF4545r90
Standard aluminium profile, 45 x 45 mm - R90°



PF55
Worm and wheel gear reducer, up to 57 Nm



BCH_SS
Mushroom headed button, M3 to M8



PR105
Articulated foot Ø103, Ø 103



BOX-CS
Hose clamp, Box set of steel hose clamps



LRX
Linear roller slide, Rail - from 9410 N to 101000 N



S2B
Short linear bearing housing, Closed - Slim



MDB_MTB
Moulded plastic bevel gear (nylon), 3:1



PSG35
Spur gear - precision range, Stainless steel 316



CHM50-MOT
Asynchronous AC motorgearboxes 0.18 to 0.75kW, 0.18 to 0.75kW

Complementary products



SVG
Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



SVG
Adjustable latch clamp with strike plate, Stroke from 174mm to 190mm