

# Adjustable latch clamp with catch plate **StaSta**

## SVG26 Span adjustable from 82 to 92mm



### - Adjustable latch clamp with catch-plate

#### - Materials:

- Chromed steel
- Non treated 304 stainless steel

### Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

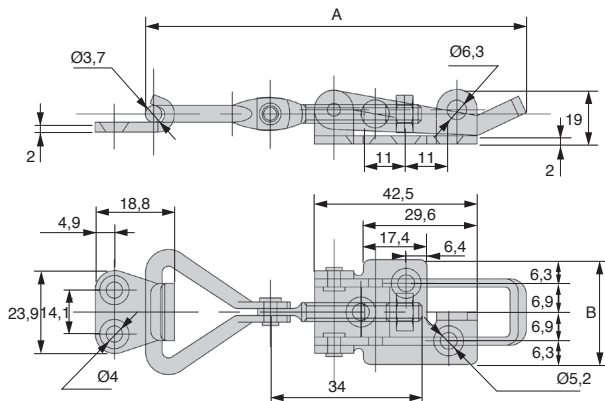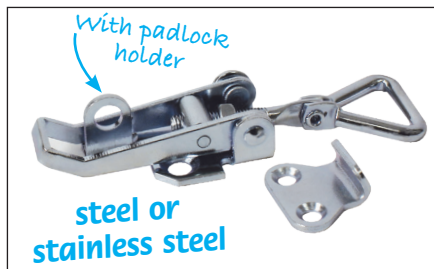

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Stock*	Price each 1 to 9
SVG26-82-92	82 to 92	26,4	Steel	Galvanised	48	✓	6,75 €
SVG26-82-92/SS	82 to 92	26,4	S-Steel 304	Natural	48	✓	11,32 €

\*Subject to availability - Dimensions in mm



# Ste Sta Adjustable latch clamp with catch plate

Span adjustable from 106.7 to 121.4mm **SVG32**

- Adjustable latch clamp with catch-plate
- Materials:  
Chromed steel  
Non treated 304  
stainless steel

## Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

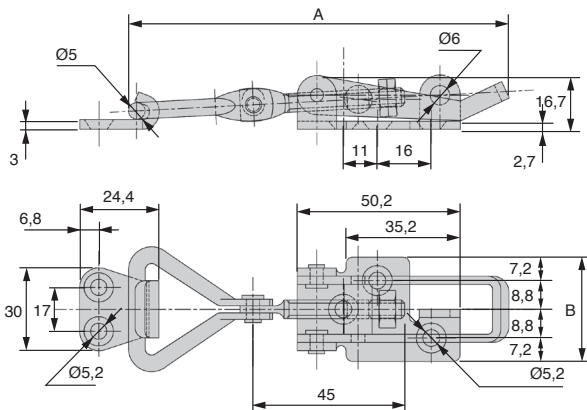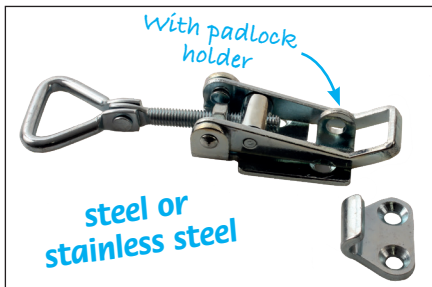

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Price each 1 to 9
SVG32-106-121	106.7 to 121.4	32	Steel	Galvanised	102	6.60 €
SVG32-106-121/SS	106.7 to 121.4	32	S-Steel 304	Natural	102	18.91 €

\*Subject to availability - Dimensions in mm

# Adjustable latch clamp with catch plate **Ste|Sta**

## SVG39 Span adjustable from 118 to 130.5mm


### - Adjustable latch clamp with catch-plate

#### - Materials:

- Chromed steel
- Non treated 304 stainless steel

### Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

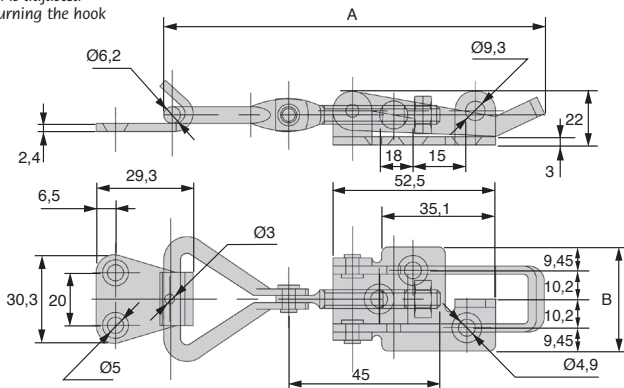

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	Material	Finish	Weight (g)	Stock*	Price each 1 to 9
SVG39-118-130	118 to 130,5	39,3	Steel	Galvanised	124	✓	11,51 €
SVG39-118-130/SS	118 to 130,5	39,3	S-Steel 304	Natural	124	✓	25,25 €

\*Subject to availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel



# SteSta Adjustable latch clamp with catch plate

Span adjustable from 174 to 190mm **SVG50**

- Adjustable latch clamp with catch-plate
- Screw fixing
- Materials:
  - Chromed steel
  - Non treated 304 stainless steel

## Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

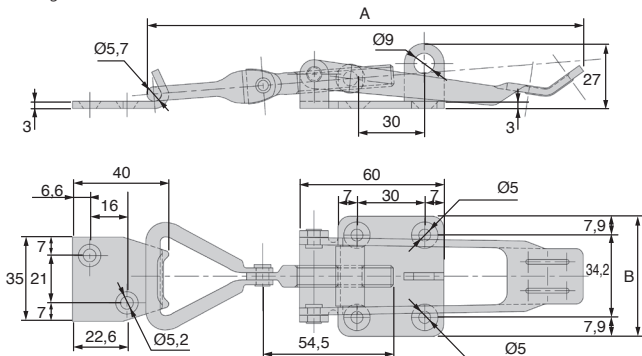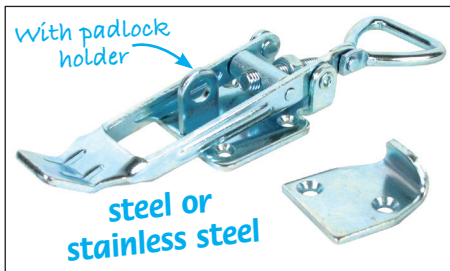

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	A	B	Material	Finish	Weight (g)	Stock*	Price each 1 to 9
SVG50-174-190	174 to 190	50	Steel	Galvanised	236	✓	14,75 €
SVG50-174-190/SS	174 to 190	50	S-Steel 304	Natural	236	-	48,36 €

\*Subject to availability - Dimensions in mm

## Our other products



ADL\_M

Male eye bolt conforms to DIN580, Stainless steel



GLT3E-50

Telescopic drawer,



 
PRES7HR

Manual workbench press, Force up to 700kg



SCA\_SS

Stainless steel flat cable clamp, Stainless steel



JFM

Flanged polymer bush, Universal polymer



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



KBS\_UU

Stainless steel closed precision linear bearing, Precision - staine...



PR85

Articulated foot Ø83, Ø 83



PO

Pull handle - Multi-sector, Tapped



PRF\_FIX\_STD

Fastener for aluminium profile,



TCC\_SS

Stainless steel rigging screw (hook/hook),



UGCG

Actuator guide kit, Long housing

## Complementary products



SVG

Adjustable latch clamp with strike plate, Stroke from 106,7mm to 121...



SVG

Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



GEC

Rubber latch clamp with strike plate, Lockable



GAC

Latch clamp with lock, Lockable