

- Material:
Stainless steel 302 AMS 5688
- Standard springs are right hand wound

Options

- For left hand wound springs, replace R in the part number with L
- Custom made springs

Info.


- *A/S = Spring width
- Not supplied individually, contact us for details




TO-L: Left hand wound spring (Option)




TO-R: Right hand wound spring (Standard)

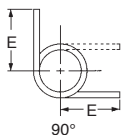


90°

 


180°

 

270°

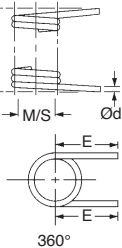

360°

 

DISCOUNTS

| Qty | 1+ | 10+ | 25+ | 50+ |
|-------|------|------|------|------------|
| Disc. | List | -15% | -45% | On request |

| Part number | Wire Ød | Outside Ø Do | Torque (N/mm) T | Loaded position R | M/S recommended pin ø | Leg Length E (mm) | A/S | | | Price each 1 to 9 |
|---------------|---------|--------------|-----------------|-------------------|-----------------------|-------------------|------------------------|-------------|--------|-------------------|
| | | | | | | | Min. axle length (mm)* | Fleet angle | Stock* | |
| T0120-900-55R | 0,30 | 2,36 | 5,31 | 4,75 | 1,40 | 9,52 | 1,17 | 90° | ✓ | 4,16 € |
| T0121-800-67R | 0,30 | 2,77 | 5,31 | 4,75 | 1,70 | 9,52 | 2,18 | 180° | ✓ | 4,16 € |
| T0122-700-62R | 0,30 | 2,59 | 5,31 | 4,75 | 1,57 | 9,52 | 3,53 | 270° | - | 4,24 € |
| T0121-801-09R | 0,30 | 4,22 | 5,31 | 6,35 | 2,77 | 12,70 | 1,50 | 180° | ✓ | 4,24 € |
| T0122-701-09R | 0,30 | 4,32 | 5,31 | 6,35 | 2,77 | 12,70 | 2,18 | 270° | ✓ | 4,24 € |
| T0123-601-09R | 0,30 | 4,42 | 5,31 | 6,35 | 2,77 | 12,70 | 2,81 | 360° | ✓ | 4,24 € |

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -15% | -45% | On request |

| Part number | Wire Ød | Outside Ø Do | Torque (N/mm) T | Loaded position R | M/S recom- mended pin ø | Leg Length E (mm) | A/S Min. axle length (mm) ¹ | Fleet angle | Stock* | Price each 1 to 9 |
|---------------|------------|--------------------|-----------------------|-------------------------|----------------------------------|-------------------------|---|----------------|--------|-------------------------|
| | | | | | | | | | | |
| T0170-900-93R | 0,43 | 4,06 | 13,22 | 6,35 | 2,36 | 12,70 | 2,06 | 90° | ✓ | 4,24 € |
| T0171-800-93R | 0,43 | 4,37 | 13,22 | 6,35 | 2,36 | 12,70 | 3,23 | 180° | ✓ | 4,24 € |
| T0172-700-93R | 0,43 | 4,06 | 13,22 | 6,35 | 2,36 | 12,70 | 4,88 | 270° | - | 4,24 € |
| T0171-801-56R | 0,43 | 6,32 | 13,22 | 9,52 | 3,96 | 19,05 | 2,39 | 180° | ✓ | 7,23 € |
| T0172-701-56R | 0,43 | 6,58 | 13,22 | 9,52 | 3,96 | 19,05 | 3,13 | 270° | - | 7,23 € |
| T0173-601-40R | 0,43 | 5,97 | 13,22 | 9,52 | 3,56 | 19,05 | 4,32 | 360° | ✓ | 7,23 € |
| T0200-901-09R | 0,51 | 4,85 | 21,10 | 9,52 | 2,77 | 19,05 | 2,41 | 90° | ✓ | 4,24 € |
| T0201-801-09R | 0,51 | 4,55 | 21,10 | 9,52 | 2,77 | 19,05 | 4,32 | 180° | ✓ | 4,24 € |
| T0202-700-93R | 0,51 | 4,45 | 21,10 | 9,52 | 2,36 | 19,05 | 6,22 | 270° | - | 4,24 € |
| T0201-801-40R | 0,51 | 6,15 | 21,10 | 12,70 | 3,56 | 25,40 | 3,30 | 180° | ✓ | 7,23 € |
| T0202-701-72R | 0,51 | 6,81 | 21,10 | 12,70 | 4,37 | 25,40 | 4,19 | 270° | - | 7,23 € |
| T0203-601-56R | 0,51 | 6,45 | 21,10 | 12,70 | 3,96 | 25,40 | 6,35 | 360° | - | 7,23 € |
| T0250-901-40R | 0,64 | 5,97 | 42,40 | 9,52 | 3,56 | 19,05 | 2,44 | 90° | ✓ | 4,24 € |
| T0251-801-40R | 0,64 | 5,69 | 42,40 | 9,52 | 3,56 | 19,05 | 5,23 | 180° | ✓ | 4,24 € |
| T0252-701-40R | 0,64 | 5,56 | 42,40 | 9,52 | 3,56 | 19,05 | 8,03 | 270° | ✓ | 4,24 € |
| T0251-802-03R | 0,64 | 7,72 | 42,40 | 12,70 | 5,16 | 25,40 | 3,84 | 180° | ✓ | 7,23 € |
| T0252-702-18R | 0,64 | 8,64 | 42,40 | 12,70 | 5,54 | 25,40 | 5,23 | 270° | ✓ | 7,23 € |
| T0253-602-18R | 0,64 | 8,23 | 42,40 | 12,70 | 5,54 | 25,40 | 7,32 | 360° | - | 7,23 € |
| T0320-901-72R | 0,81 | 7,32 | 92,70 | 12,70 | 4,34 | 25,40 | 3,86 | 90° | ✓ | 7,23 € |
| T0321-801-56R | 0,81 | 6,86 | 92,70 | 12,70 | 3,96 | 25,40 | 6,91 | 180° | ✓ | 7,23 € |
| T0322-701-56R | 0,81 | 6,71 | 92,70 | 12,70 | 3,96 | 25,40 | 9,70 | 270° | - | 7,23 € |
| T0321-802-18R | 0,81 | 9,30 | 92,70 | 12,70 | 5,54 | 25,40 | 5,28 | 180° | ✓ | 8,55 € |
| T0322-702-18R | 0,81 | 8,99 | 92,70 | 12,70 | 5,54 | 25,40 | 7,52 | 270° | ✓ | 8,55 € |
| T0323-602-34R | 0,81 | 9,70 | 92,70 | 12,70 | 5,95 | 25,40 | 8,94 | 360° | ✓ | 8,55 € |
| T0350-901-87R | 0,89 | 8,00 | 113,00 | 15,88 | 4,75 | 31,75 | 3,43 | 90° | ✓ | 7,23 € |
| T0351-801-87R | 0,89 | 7,70 | 113,00 | 15,88 | 4,75 | 31,75 | 7,37 | 180° | ✓ | 7,23 € |
| T0352-701-87R | 0,89 | 7,90 | 113,00 | 15,88 | 4,75 | 31,75 | 11,23 | 270° | ✓ | 7,23 € |
| T0351-802-81R | 0,89 | 11,43 | 113,00 | 15,88 | 7,14 | 31,75 | 5,38 | 180° | ✓ | 8,55 € |
| T0352-702-81R | 0,89 | 11,05 | 113,00 | 15,88 | 7,14 | 31,75 | 8,33 | 270° | ✓ | 8,47 € |
| T0353-603-12R | 0,89 | 11,96 | 113,00 | 15,88 | 7,92 | 31,75 | 10,29 | 360° | ✓ | 8,55 € |

*Subject to availability - Dimensions in mm

Our other products



NJM

Multiple junction
clamp, Multiple



PW_PWG05

Wheel - precision
range, Bronze



PCS_PA6

Plastic sprocket,
12.7mm (DIN 08B-1)



BLHB20

Right angled gearbox,
bored shafts, up to
1.77 Nm




RFK58C

Hypoid gearbox -
Stainless steel, up to
500 Nm



BPM_LOK

 Long-Lok slotted
spring plunger with
ball tip, LONG-LOK -
Stainless ...



LVTMFC

Device for controlling
limit switches, For
mini-actuator LVT



PM3

Worm and wheel set,
Hardened steel



PRES2HR

Manual workbench
press, Force up to
500 N



M0

Worm and wheel set,
Non hardened steel



VTLB

 
Three-lobed knob,
Thermoplastic / Brass



M0

Worm and wheel set,
Bronze

Complementary products



T0

Torsion spring,
Stainless steel