 


# T type toothed timing pulley bar stock

## T10-BAR

Aluminium


 


- Toothed bar stock to be cut to length by the customer

- The overall length is the same as the maximum length

- Material : Aluminium suitable for hard anodic oxidation

- Finish : Supplied not-treated

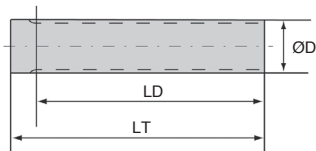

### Info.

- We are unable to modify this product

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each
10T10-BAR	10	29,98	140	140	14,92 €
11T10-BAR	11	33,16	140	140	17,46 €
12T10-BAR	12	36,35	140	140	20,29 €
13T10-BAR	13	39,55	140	140	21,88 €
14T10-BAR	14	42,70	140	140	27,56 €
15T10-BAR	15	45,90	140	140	30,55 €
16T10-BAR	16	49,10	160	160	34,78 €
17T10-BAR	17	52,25	160	160	38,16 €
18T10-BAR	18	55,45	160	160	41,76 €
19T10-BAR	19	58,65	160	160	46,76 €
20T10-BAR	20	61,80	160	160	50,82 €
21T10-BAR	21	65,00	160	160	55,19 €
22T10-BAR	22	68,15	160	160	65,23 €
23T10-BAR	23	71,35	160	160	65,82 €
24T10-BAR	24	74,55	160	160	73,50 €
26T10-BAR	26	80,90	160	160	82,46 €
28T10-BAR	28	87,25	160	160	91,78 €
30T10-BAR	30	93,65	160	160	111,30 €
32T10-BAR	32	100,00	160	160	122,19 €
34T10-BAR	34	106,40	160	160	133,63 €
36T10-BAR	36	112,75	160	160	148,54 €
38T10-BAR	38	119,10	160	160	170,16 €
40T10-BAR	40	125,45	160	160	183,65 €
45T10-BAR	45	141,40	160	160	242,62 €
48T10-BAR	48	150,95	160	160	259,35 €
60T10-BAR	60	189,15	160	160	427,26 €
72T10-BAR	72	227,29	160	160	611,19 €

Dimensions in mm

## Our other products



SHS  
Shoulder screw  
stainless steel 303,  
Stainless steel 303




DOMI50  
Connecting kits, XZ  
linking kit



CHA225  
Screwed hinge with  
threaded insert, 225  
degrees



 PVL  
Small lobed handle,  
Polyamide



ZR  
Plastic rack, Delrin



ZG2  
Plastic spur gear,  
Machined plastic  
(delrin)



PLM-20SC  
Cylindrical magnet,  
Cylindrical magnet



NT92  
Spur gear coaxial  
gearbox, from 15 to  
40 Nm - In-line



RDE-N  
Sealing washer  
Hygienic Usit®,  
Stainless steel - Black



GB-RA  
Brass spur gear, Brass  
CuZn39Pb3



CAP815  
Slim slat top chain  
stainless steel,  
Narrow range 815



AT5-10ECO  
AT type timing pulley,  
Economy range - AT5  
aluminium

## Complementary products



T10\_21\_AL  
T type timing pulley,  
Economy range - T10  
aluminium



T10\_30\_AL  
T type timing pulley,  
Economy range - T10  
aluminium



T10\_21N1F  
T type timing pulley,  
Economy range - T10  
moulded plastic  
(nylon)



T10courrie  
T type timing belt,  
T10 Steel cored  
polyurethane