 


T type toothed timing pulley bar stock

T10-BAR

Aluminium


 


- Toothed bar stock to be cut to length by the customer

- The overall length is the same as the maximum length

- Material : Aluminium suitable for hard anodic oxidation

- Finish : Supplied not-treated

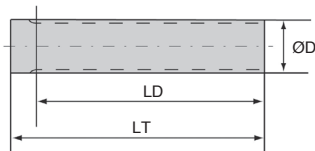

Info.

- We are unable to modify this product

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L _D	Total length L _T	Price each
10T10-BAR	10	29,98	140	140	14,92 €
11T10-BAR	11	33,16	140	140	17,46 €
12T10-BAR	12	36,35	140	140	20,29 €
13T10-BAR	13	39,55	140	140	21,88 €
14T10-BAR	14	42,70	140	140	27,56 €
15T10-BAR	15	45,90	140	140	30,55 €
16T10-BAR	16	49,10	160	160	34,78 €
17T10-BAR	17	52,25	160	160	38,16 €
18T10-BAR	18	55,45	160	160	41,76 €
19T10-BAR	19	58,65	160	160	46,76 €
20T10-BAR	20	61,80	160	160	50,82 €
21T10-BAR	21	65,00	160	160	55,19 €
22T10-BAR	22	68,15	160	160	65,23 €
23T10-BAR	23	71,35	160	160	65,82 €
24T10-BAR	24	74,55	160	160	73,50 €
26T10-BAR	26	80,90	160	160	82,46 €
28T10-BAR	28	87,25	160	160	91,78 €
30T10-BAR	30	93,65	160	160	111,30 €
32T10-BAR	32	100,00	160	160	122,19 €
34T10-BAR	34	106,40	160	160	133,63 €
36T10-BAR	36	112,75	160	160	148,54 €
38T10-BAR	38	119,10	160	160	170,16 €
40T10-BAR	40	125,45	160	160	183,65 €
45T10-BAR	45	141,40	160	160	242,62 €
48T10-BAR	48	150,95	160	160	259,35 €
60T10-BAR	60	189,15	160	160	427,26 €
72T10-BAR	72	227,29	160	160	611,19 €

Dimensions in mm

Our other products



WSRM
Cylindrical polymer nut, Polymer (Iglidur®) - 1 thread



GAL22
Conveyor wheel, Zinc plated steel



PRF JL4
Lip seal for panel, Door seal - Ø 4mm



BDPR
Holding arm, Rigid



 
MEB
Moulded plastic bevel gear (nylon), 1:1




RPCpl
Swivel castor with double brake, Steel - Polyamide



SFWR
End support, Surface mounting



LAT2
2A motorised linear actuator, 2 amperes

 

RPP
Connecting plate for RPP type timing belts,



SH4
Parallel axis helical gear, Steel 20NCD2



SLB
Indexing plunger, steel class 5.8



S2B
Short linear bearing housing, Closed - Slim

Complementary products



T10_21_AL
T type timing pulley, Economy range - T10 aluminium



T10_30_AL
T type timing pulley, Economy range - T10 aluminium



T10_21N1F
T type timing pulley, Economy range - T10 moulded plastic polyurethane (nylon)



T10courrie
T type timing belt, T10 Steel cored polyurethane