

T type toothed timing pulley bar stock

T2.5-BAR

Aluminium




- **Toolthed bar stock to be cut to length by the customer**
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



Info.

- We are unable to modify this product

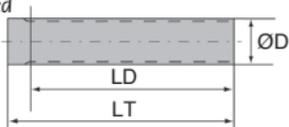

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L _D	Total length L _T	Price each
10T2.5-BAR	10	7,45	50	75	3,01 €
12T2.5-BAR	12	9,00	50	75	3,06 €
13T2.5-BAR	13	9,80	50	75	3,16 €
14T2.5-BAR	14	10,60	50	75	3,37 €
15T2.5-BAR	15	11,40	50	75	3,46 €
16T2.5-BAR	16	12,20	50	75	3,62 €
17T2.5-BAR	17	13,00	50	75	3,70 €
18T2.5-BAR	18	13,80	50	75	3,95 €
19T2.5-BAR	19	14,60	90	120	7,13 €
20T2.5-BAR	20	15,40	90	120	7,50 €
21T2.5-BAR	21	16,20	90	120	7,97 €
22T2.5-BAR	22	17,00	125	140	10,53 €
24T2.5-BAR	24	18,55	125	140	11,16 €
26T2.5-BAR	26	20,15	125	140	12,68 €
27T2.5-BAR	27	20,95	125	140	12,77 €
28T2.5-BAR	28	21,75	125	140	13,13 €
29T2.5-BAR	29	22,55	125	140	13,93 €
30T2.5-BAR	30	23,35	125	140	14,00 €
32T2.5-BAR	32	24,95	125	140	15,23 €
34T2.5-BAR	34	26,55	125	140	15,83 €
35T2.5-BAR	35	27,35	132	140	16,93 €
36T2.5-BAR	36	28,10	132	140	18,07 €
38T2.5-BAR	38	29,70	140	140	18,50 €
40T2.5-BAR	40	31,30	140	140	19,79 €
42T2.5-BAR	42	32,90	140	140	22,05 €
44T2.5-BAR	44	34,50	140	140	24,53 €
45T2.5-BAR	45	35,30	140	140	25,01 €
48T2.5-BAR	48	37,70	140	140	26,37 €
50T2.5-BAR	50	39,29	160	160	32,10 €
60T2.5-BAR	60	47,25	160	160	41,35 €
65T2.5-BAR	65	51,20	160	160	47,77 €
70T2.5-BAR	70	55,20	160	160	52,20 €
72T2.5-BAR	72	56,80	160	160	55,02 €
90T2.5-BAR	90	71,12	160	160	79,67 €
100T2.5-BAR	100	79,08	160	160	106,35 €

Dimensions in mm

Alu T type toothed timing pulley bar stock

Aluminium

T5-BAR




- **Toothed bar stock to be cut to length by the customer**
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



Info.

- We are unable to modify this product

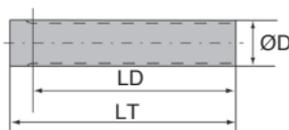

DISCOUNTS

Qty	1+	2+	4+
Disc. List	-20%		On request

Part number	Z Teeth	ØD External	Length of teeth L _D	Total length L _T	Price each
10T5-BAR	10	15,05	125	140	8,80 €
11T5-BAR	11	16,65	125	140	9,51 €
12T5-BAR	12	18,25	125	140	10,34 €
13T5-BAR	13	19,85	125	140	10,34 €
14T5-BAR	14	21,45	140	140	12,06 €
15T5-BAR	15	23,05	140	140	13,05 €
16T5-BAR	16	24,60	140	140	14,60 €
17T5-BAR	17	26,20	140	140	15,44 €
18T5-BAR	18	27,00	140	140	17,01 €
19T5-BAR	19	29,40	140	140	18,49 €
20T5-BAR	20	31,00	160	160	21,14 €
21T5-BAR	21	32,70	160	160	22,01 €
22T5-BAR	22	34,15	160	160	24,49 €
23T5-BAR	23	35,85	160	160	24,74 €
24T5-BAR	24	37,40	160	160	26,47 €
25T5-BAR	25	38,95	160	160	28,41 €
26T5-BAR	26	40,60	160	160	31,33 €
27T5-BAR	27	42,20	160	160	31,50 €
28T5-BAR	28	43,75	160	160	34,55 €
29T5-BAR	29	45,35	160	160	34,83 €
30T5-BAR	30	46,95	160	160	37,06 €
32T5-BAR	32	50,10	160	160	42,97 €
34T5-BAR	34	53,25	160	160	46,88 €
35T5-BAR	35	54,85	160	160	47,23 €
36T5-BAR	36	56,45	160	160	49,89 €
37T5-BAR	37	58,06	160	160	52,62 €
38T5-BAR	38	59,65	160	160	52,91 €
40T5-BAR	40	62,85	160	160	57,35 €
42T5-BAR	42	66,00	160	160	62,24 €
44T5-BAR	44	69,20	160	160	72,69 €
45T5-BAR	45	70,80	160	160	73,26 €
46T5-BAR	46	72,40	160	160	73,84 €
48T5-BAR	48	75,55	160	160	81,88 €
50T5-BAR	50	78,75	160	160	91,27 €
60T5-BAR	60	94,65	160	160	122,84 €
72T5-BAR	72	113,75	160	160	172,41 €
80T5-BAR	80	126,48	160	160	201,15 €
90T5-BAR	90	142,40	160	160	264,47 €
100T5-BAR	100	158,31	160	160	349,26 €

Dimensions in mm