 


# T type toothed timing pulley bar stock

## T10-BAR

Aluminium


 


- Toothed bar stock to be cut to length by the customer

- The overall length is the same as the maximum length

- Material : Aluminium suitable for hard anodic oxidation

- Finish : Supplied not-treated

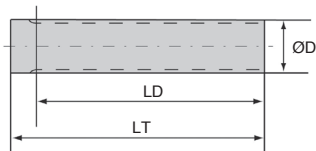

### Info.

- We are unable to modify this product

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each
10T10-BAR	10	29,98	140	140	14,92 €
11T10-BAR	11	33,16	140	140	17,46 €
12T10-BAR	12	36,35	140	140	20,29 €
13T10-BAR	13	39,55	140	140	21,88 €
14T10-BAR	14	42,70	140	140	27,56 €
15T10-BAR	15	45,90	140	140	30,55 €
16T10-BAR	16	49,10	160	160	34,78 €
17T10-BAR	17	52,25	160	160	38,16 €
18T10-BAR	18	55,45	160	160	41,76 €
19T10-BAR	19	58,65	160	160	46,76 €
20T10-BAR	20	61,80	160	160	50,82 €
21T10-BAR	21	65,00	160	160	55,19 €
22T10-BAR	22	68,15	160	160	65,23 €
23T10-BAR	23	71,35	160	160	65,82 €
24T10-BAR	24	74,55	160	160	73,50 €
26T10-BAR	26	80,90	160	160	82,46 €
28T10-BAR	28	87,25	160	160	91,78 €
30T10-BAR	30	93,65	160	160	111,30 €
32T10-BAR	32	100,00	160	160	122,19 €
34T10-BAR	34	106,40	160	160	133,63 €
36T10-BAR	36	112,75	160	160	148,54 €
38T10-BAR	38	119,10	160	160	170,16 €
40T10-BAR	40	125,45	160	160	183,65 €
45T10-BAR	45	141,40	160	160	242,62 €
48T10-BAR	48	150,95	160	160	259,35 €
60T10-BAR	60	189,15	160	160	427,26 €
72T10-BAR	72	227,29	160	160	611,19 €

Dimensions in mm

## Our other products



DPAR\_DKON  
Conical elasto buffer,  
Steel



BUT  
Panel stop, Panel stop



PRF\_ROUL  
Castor for aluminium  
profile, No brake



ESCB  
Combined bipod  
support base, Bipod  
support element with  
cross support



RCX-6  
Spherical tilt washer -  
DIN6319, convex



 
PCLA\_M  
Technopolymer  
clamping lever -  
female, Plastic



HK  
Manual locking clamp,  
Manual locking clamp  
LRX



PRES  
Manual workbench  
press accessory for  
PRES-3HR end  
PRES-4HR, Tool hol...



IN1  
Internal gear,  
Machined plastic



GDR880  
Straight track for slat  
top chain, Ranges 880



gt64r  
Rotating bent lever  
with spring, Increased



RHTplss  
High Temperature  
Castor, up to 200kg

## Complementary products



T10\_21\_AL  
T type timing pulley,  
Economy range - T10  
aluminium



T10\_30\_AL  
T type timing pulley,  
Economy range - T10  
aluminium



T10\_21N1F  
T type timing pulley,  
Economy range - T10  
moulded plastic  
(nylon)



T10courrie  
T type timing belt,  
T10 Steel cored  
polyurethane