

 
# T-type timing pulley



## Pitch T10

## Aluminium

Belt width 16mm




Economy range

- Pitch 10mm
- Materials:
  - Pulley: aluminium
  - Flanges: steel

### Info.

- \*\*Pilot bore given as a guide only
- We are unable to modify these parts

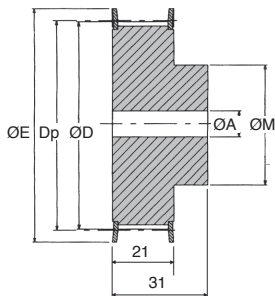

### DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-21-AL	12	38,35	36,35	42	28	6	✓	8,37 €
14T10-21-AL	14	44,70	42,70	48	32	8	✓	10,18 €
15T10-21-AL	15	47,90	45,90	51	32	8	✓	11,29 €
16T10-21-AL	16	51,10	49,10	54	35	8	✓	12,53 €
18T10-21-AL	18	57,45	55,45	60	40	8	✓	14,96 €
19T10-21-AL	19	60,65	58,65	66	44	8	-	16,54 €
20T10-21-AL	20	63,80	61,80	66	46	8	✓	17,95 €
22T10-21-AL	22	70,20	68,20	75	52	8	-	22,21 €
24T10-21-AL	24	76,55	74,55	83	58	8	✓	24,96 €
25T10-21-AL	25	79,75	77,75	83	60	8	-	25,24 €
26T10-21-AL	26	82,90	80,90	87	60	8	-	28,00 €
27T10-21-AL	27	86,10	84,10	91	60	8	-	30,67 €
28T10-21-AL	28	89,25	87,25	93	60	8	-	30,91 €
30T10-21-AL	30	95,65	93,65	102	60	8	-	36,63 €
32T10-21-AL	32	102,00	100,00	106	65	10	-	39,90 €
36T10-21-AL	36	114,75	112,75	119	70	10	✓	46,98 €
40T10-21-AL	40	127,45	125,45	131	80	10	-	58,58 €

\*Depending on availability - Dimensions in mm

## Our other products



PRF\_ROUL\_F  
Castor for aluminium profile, With brake



BCM\_CC  
Modular cylindrical brush, Horsehair bristles



NSB  
Standard linear bearing housing, Closed - Long



HTD8M\_30  
HTD Heavy duty timing pulley, HTD8 Cast



ACLEFS  
Floor anchor for aluminium profile, Adjustable



PT882  
Drive sprocket for slat top chain, Range 882



M1  
Worm and wheel set, Non hardened steel



VRC2  
Retaining clamp, dual sided, Dual sided



 
ZBconique  
Machined plastic bevel gear, 1:1



VMS  
Stainless steel knurled thumb screw, Knurled



CMM  
Male rod ends DIN ISO12240-4, Steel / bronze



CHTRB  
Single and dual output gearboxes, Up to 16,5 Nm

## Complementary products



T10courroie  
T type timing belt, T10 Steel cored polyurethane



T10\_21N1F  
T type timing pulley, Economy range - T10 moulded plastic (nylon)



T10-BAR  
T type tooth bar stock, T10



GTC  
Belt tensioner, For standard applications