

T-type timing pulley

 


Pitch

Aluminium

T10

Belt width 16mm





Economy range

- Pitch 10mm
- Materials:
Pulley: aluminium
Flanges: steel

Info.

- **Pilot bore given as a guide only
- We are unable to modify these parts

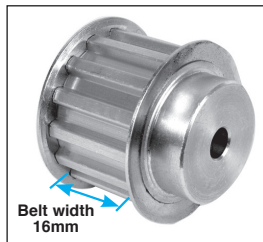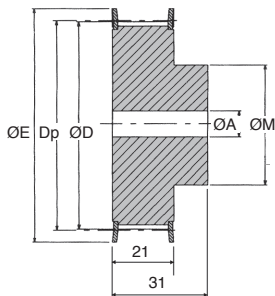

DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-21-AL	12	38,35	36,35	42	28	6	✓	8,37 €
14T10-21-AL	14	44,70	42,70	48	32	8	✓	10,18 €
15T10-21-AL	15	47,90	45,90	51	32	8	✓	11,29 €
16T10-21-AL	16	51,10	49,10	54	35	8	✓	12,53 €
18T10-21-AL	18	57,45	55,45	60	40	8	✓	14,96 €
19T10-21-AL	19	60,65	58,65	66	44	8	-	16,54 €
20T10-21-AL	20	63,80	61,80	66	46	8	✓	17,95 €
22T10-21-AL	22	70,20	68,20	75	52	8	-	22,21 €
24T10-21-AL	24	76,55	74,55	83	58	8	✓	24,96 €
25T10-21-AL	25	79,75	77,75	83	60	8	-	25,24 €
26T10-21-AL	26	82,90	80,90	87	60	8	-	28,00 €
27T10-21-AL	27	86,10	84,10	91	60	8	-	30,67 €
28T10-21-AL	28	89,25	87,25	93	60	8	-	30,91 €
30T10-21-AL	30	95,65	93,65	102	60	8	-	36,63 €
32T10-21-AL	32	102,00	100,00	106	65	10	-	39,90 €
36T10-21-AL	36	114,75	112,75	119	70	10	✓	46,98 €
40T10-21-AL	40	127,45	125,45	131	80	10	-	58,58 €

*Depending on availability - Dimensions in mm

Our other products



BOXKU

Boxed set of half round (Woodruff) keys NFE22179, Boxed set of half ...



RJUM05

Drylin R® linear bearing housing, Closed - Slim



MHWC

Double-disc flexible coupling, Double disk



PSG25

Spur gear - precision range, Stainless steel 316



CDP

Flanged drill bushing, Steel



PRF-P

Aluminium profile feet support, For feet or casters



DOMI_MD

Domino rotary table, 55/1



ZG4

Plastic spur gear, Machined plastic (delrin)



GE_ES_2RS

Spherical bushing, Steel / steel with seals



CDGamme

Compression spring DIN2095, DIN 2095



SLBWSS

Indexing plunger, weldable, Weldable -



DB

Steel bevel gear, 2:1

Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10_21N1F

T type timing pulley, Economy range - T10 moulded plastic (nylon)



T10-BAR

T type tooth bar stock, T10



GTC

Belt tensioner, For standard applications