

# T-type timing pulley

 


## Pitch

## Aluminium

# T10

Belt width 16mm




**Economy range**

- Pitch 10mm
- Materials:  
Pulley: aluminium  
Flanges: steel

### Info.

- \*\*Pilot bore given as a guide only
- We are unable to modify these parts

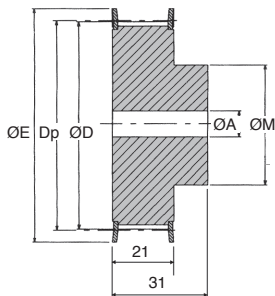

### DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-21-AL	12	38,35	36,35	42	28	6	✓	8,37 €
14T10-21-AL	14	44,70	42,70	48	32	8	✓	10,18 €
15T10-21-AL	15	47,90	45,90	51	32	8	✓	11,29 €
16T10-21-AL	16	51,10	49,10	54	35	8	✓	12,53 €
18T10-21-AL	18	57,45	55,45	60	40	8	✓	14,96 €
19T10-21-AL	19	60,65	58,65	66	44	8	-	16,54 €
20T10-21-AL	20	63,80	61,80	66	46	8	✓	17,95 €
22T10-21-AL	22	70,20	68,20	75	52	8	-	22,21 €
24T10-21-AL	24	76,55	74,55	83	58	8	✓	24,96 €
25T10-21-AL	25	79,75	77,75	83	60	8	-	25,24 €
26T10-21-AL	26	82,90	80,90	87	60	8	-	28,00 €
27T10-21-AL	27	86,10	84,10	91	60	8	-	30,67 €
28T10-21-AL	28	89,25	87,25	93	60	8	-	30,91 €
30T10-21-AL	30	95,65	93,65	102	60	8	-	36,63 €
32T10-21-AL	32	102,00	100,00	106	65	10	-	39,90 €
36T10-21-AL	36	114,75	112,75	119	70	10	✓	46,98 €
40T10-21-AL	40	127,45	125,45	131	80	10	-	58,58 €

\*Depending on availability - Dimensions in mm

## Our other products



CF

Cam follower,  
Standard - steel



J53

Spur gear coaxial  
gearbox, from 0.43 to  
1.15 - Inline



BPM

Slotted spring plunger  
with ball tip, Stainless  
steel 303



EP7

Electronic digital  
position indicator, 5  
numbers



BLHB50

Right angled gearbox,  
bored shafts, up to 30  
Nm



FBL6000\_K13

Brush strip per meter  
PP fibres Ø0.2, Black  
striated polypropylene  
...



PTGP

Tensioner pulley, For  
flat belts



HSE-HSB

Hexagonal spacer,  
Brass



PO

Pull handle - Multi-  
sector, Smooth hole



 
AF

Shaft clamp with  
keyway, Set screw



PSPT

Flexible tube handle,  
PVC



CFC

Spring loaded position  
switch, Electric  
contact

## Complementary products



T10courroie

T type timing belt,  
T10 Steel cored  
polyurethane



T10\_21N1F

T type timing pulley,  
Economy range - T10  
moulded plastic  
(nylon)



T10-BAR

T type tooth bar  
stock, T10



GTC

Belt tensioner, For  
standard applications