

 
# T-type timing pulley



## Pitch T10

## Aluminium

Belt width 16mm




**Economy range**

- Pitch 10mm
- Materials:  
Pulley: aluminium  
Flanges: steel

### Info.

- \*\*Pilot bore given as a guide only
- We are unable to modify these parts

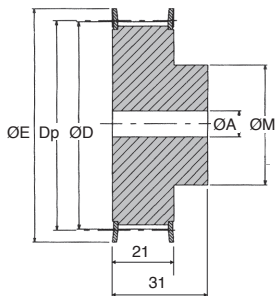

### DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-21-AL	12	38,35	36,35	42	28	6	✓	8,37 €
14T10-21-AL	14	44,70	42,70	48	32	8	✓	10,18 €
15T10-21-AL	15	47,90	45,90	51	32	8	✓	11,29 €
16T10-21-AL	16	51,10	49,10	54	35	8	✓	12,53 €
18T10-21-AL	18	57,45	55,45	60	40	8	✓	14,96 €
19T10-21-AL	19	60,65	58,65	66	44	8	-	16,54 €
20T10-21-AL	20	63,80	61,80	66	46	8	✓	17,95 €
22T10-21-AL	22	70,20	68,20	75	52	8	-	22,21 €
24T10-21-AL	24	76,55	74,55	83	58	8	✓	24,96 €
25T10-21-AL	25	79,75	77,75	83	60	8	-	25,24 €
26T10-21-AL	26	82,90	80,90	87	60	8	-	28,00 €
27T10-21-AL	27	86,10	84,10	91	60	8	-	30,67 €
28T10-21-AL	28	89,25	87,25	93	60	8	-	30,91 €
30T10-21-AL	30	95,65	93,65	102	60	8	-	36,63 €
32T10-21-AL	32	102,00	100,00	106	65	10	-	39,90 €
36T10-21-AL	36	114,75	112,75	119	70	10	✓	46,98 €
40T10-21-AL	40	127,45	125,45	131	80	10	-	58,58 €

\*Depending on availability - Dimensions in mm

## Our other products



SSDB

Stainless steel bevel gear, 2:1




PDD

Spring plunger, With sensor adaptor



YG1

HEAVY DUTY spur gear, Steel 35NCD6

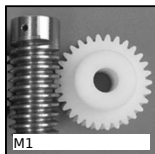

M1

Worm and wheel set, Machined plastic (delrin)



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with tapped ins...




CTZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



CLSCLP

Clevis components, short version, Steel - Short range

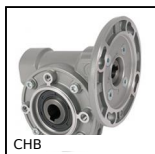

CHB

Worm and wheel gear reducer, up to 22 Nm



MPE

Hexagonal spacer, Steel



RVM25

Manually operated gearbox, Bevel



PPF

Indexing plunger with flange, with drilled flange



CMM

Male rod ends DIN ISO12240-4, Steel / bronze

## Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10\_21N1F

T type timing pulley, Economy range - T10 moulded plastic (nylon)



T10-BAR

T type tooth bar stock, T10



GTC

Belt tensioner, For standard applications