

**Moulded** nylon PA6

Pitch  
**T2.5**

Belt width 6mm

- **Positioning pulley**
- Pitch 2.5mm (T2.5)
- **Material:**  
Moulded PA6 nylon reinforced with 30% glass fibre
- **We are unable to modify these parts**

**Economy range**




### Info

- Moulded pre-bore must be machined to suit the application
- \*Pilot bore dimension given as a guide only

### Accessories

- T2,5 belt (**tome 4 p.53**)

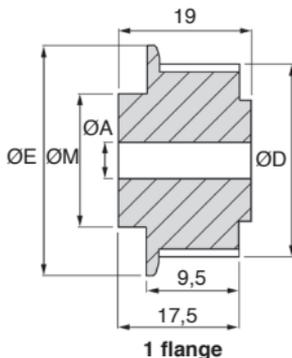

*ØA: Pilot bore must be finished*

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc. List	-12%	-25%	-33%	-37%	On request	

Part number	Z teeth	ØD	ØM	Pilot bore not guaranteed ØA*(mm)	ØE	Stock*	Price each 1 to 5
10T2.5-10-N1F	10	7,40	12	3	12	✓	5,45 €
12T2.5-10-N1F	12	9,00	12	3	12	✓	5,45 €
15T2.5-10-N1F	15	11,40	12	2	15	-	On request
16T2.5-10-N1F	16	12,18	12	2	16	✓	On request
22T2.5-10-N1F	22	17,00	14	4	22	-	On request
25T2.5-10-N1F	25	19,35	14	3	24	-	On request
26T2.5-10-N1F	26	20,14	16	4	26	-	On request
30T2.5-10-N1F	30	23,35	18	5	30	✓	9,05 €
32T2.5-10-N1F	32	24,95	18	5	32	-	On request
33T2.5-10-N1F	33	25,70	18	5	32	-	On request

\*Depending on availability - Dimensions in mm

# T-type timing pulley



## Pitch T2,5



## Aluminium

For 6mm belts

- For use with T2.5 belts
- Pitch 2.5mm
- Material:  
Aluminium

### Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

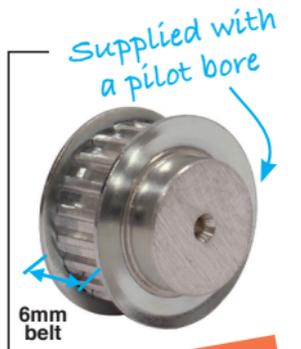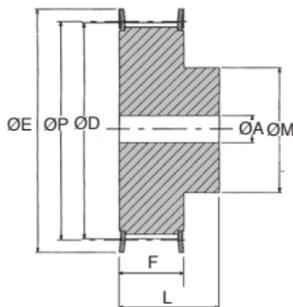

**Economy range**

### Accessories

- T2.5 belts (tome 4 p.53)
- GTC tension rollers (tome 4 p.146)

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No. of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA*	Price	
									Stock*	each 1 to 5
12T2.5-10/ECO	12	9,60	9,00	13	13	9	16	solid	✓	6,19 €
14T2.5-10/ECO	14	11,20	10,60	15	15	9	16	solid	✓	6,31 €
15T2.5-10/ECO	15	12,00	11,40	15	15	9	16	solid	-	6,67 €
16T2.5-10/ECO	16	12,80	12,20	16	16	9	16	solid	✓	7,32 €
18T2.5-10/ECO	18	14,40	13,80	17,5	10	10	16	solid	-	6,24 €
19T2.5-10/ECO	19	15,20	14,60	20	10	10	16	solid	-	6,85 €
20T2.5-10/ECO	20	16,00	15,40	20	11	10	16	solid	✓	6,82 €
22T2.5-10/ECO	22	17,60	17,00	22	11	10	16	solid	✓	6,26 €
24T2.5-10/ECO	24	19,15	18,55	22	12	10	16	4	✓	7,35 €
25T2.5-10/ECO	25	19,95	19,35	25	13	10	16	4	✓	7,44 €
26T2.5-10/ECO	26	20,75	20,15	26	14	10	16	4	✓	7,73 €
28T2.5-10/ECO	28	22,35	21,75	26	14	10	16	4	✓	8,08 €
30T2.5-10/ECO	30	23,95	23,35	26	16	10	16	6	✓	8,42 €
32T2.5-10/ECO	32	25,55	24,95	32	16	10	16	6	✓	6,46 €
36T2.5-10/ECO	36	28,75	28,10	36	20	10	16	6	✓	7,07 €
40T2.5-10/ECO	40	31,90	31,30	38	22	10	16	6	✓	7,63 €
44T2.5-10/ECO	44	35,10	34,50	-	24	10	16	6	✓	8,67 €
48T2.5-10/ECO	48	38,30	37,70	-	26	10	16	6	✓	7,92 €
60T2.5-10/ECO	60	47,85	47,25	-	34	10	16	8	✓	10,54 €

\*Depending on availability - Dimensions in mm

Aluminium

Pitch  
**T2.5**




Belt width 4mm

- Pitch 2.5mm
- Materials:  
Pulley: Aluminium 6082  
Flanges: Aluminium for pulleys with up to 84 teeth, steel for 85 teeth or more
- All pulleys have flanges

### Options

- Choose from 10 to 230 teeth

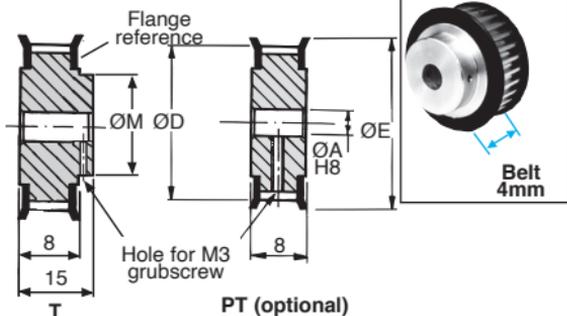

PT (optional)

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z	Teeth	Ø	PCD	ØD	ØM	ØA	Flange ref.	ØE	Price each 1 to 5
										T PT
10T2.5-8	10	7,96	7,40	13	3	10 X,Y	13,00			On request
12T2.5-8	12	9,55	9,00	13	3	10 X,Y	13,00			
14T2.5-8	14	11,14	10,60	18	3	16 X,Y	18,00			
15T2.5-8	15	11,94	11,40	18	3	16 X,Y	18,00			
16T2.5-8	16	12,73	12,20	18	4	16 X,Y	18,00			
18T2.5-8	18	14,32	13,80	18	4	31 X,Y	18,00			
19T2.5-8	19	15,12	14,60	20	4	32 X,Y	20,00			
20T2.5-8	20	15,92	15,40	20	4	32 X,Y	20,00			
21T2.5-8	21	16,71	16,20	20	4	32 X,Y	20,00			
22T2.5-8	22	17,51	17,00	20	4	32 X,Y	20,00			
24T2.5-8	24	19,10	18,55	13	4	12 XL	25,15			
25T2.5-8	25	19,89	19,35	13	4	12 XL	25,15			
26T2.5-8	26	20,69	20,15	13	5	12 XL	25,15			
30T2.5-8	30	23,87	23,35	20	5	16 XL	31,74			
31T2.5-8	31	24,67	24,15	20	5	18 XL	34,80			
32T2.5-8	32	25,46	24,95	20	5	18 XL	34,80			
40T2.5-8	40	31,83	31,30	24	6	21XL	39,68			
44T2.5-8	44	35,01	34,50	24	6	21XL	39,68			
48T2.5-8	48	38,20	37,70	24	6	24XL	44,70			
52T2.5-8	52	41,38	40,85	24	6	24XL	44,70			
57T2.5-8	57	45,36	44,85	24	6	28XL	51,05			
60T2.5-8	60	47,75	47,25	24	6	30XL	54,36			
80T2.5-8	80	63,66	63,16	24	6	17H	74,61			
84T2.5-8	84	66,85	66,35	24	6	18H	79,38			

↓ **Pulleys available up to this size** ↓  
**230T2.5-8 230** Dimensions : contact us

Dimensions in mm


# T-type timing pulley



## Pitch Aluminium T2.5

Belt width 6mm

- Pitch 2.5mm
- Materials:  
Pulley: Aluminium 6082  
Flanges: Aluminium for pulleys with up to 84 teeth, steel for 85 teeth or more
- All pulleys have flanges

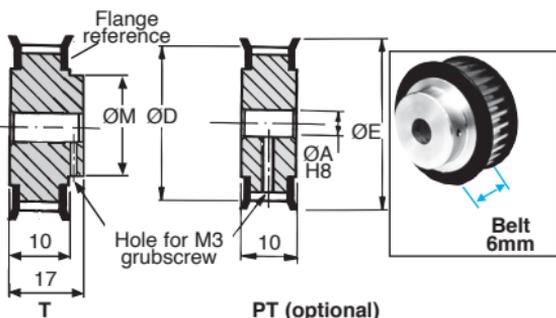

### Options

- Choose from 10 to 230 teeth



PT (optional)

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	Ø PCD	ØD	ØM	ØA	Flange ref.	ØE	Stock*	Price each 1 to 5	
									T	PT
10T2.5-10	10	7,96	7,40	13	3	10 X,Y	13,00		On request	On request
12T2.5-10	12	9,55	9,00	13	3	10 X,Y	13,00			
14T2.5-10	14	11,14	10,60	18	3	16 X,Y	18,00			
15T2.5-10	15	11,94	11,40	18	3	16 X,Y	18,00			
16T2.5-10	16	12,73	12,20	18	4	16 X,Y	18,00			
18T2.5-10	18	14,32	13,80	18	4	31 X,Y	18,00			
19T2.5-10	19	15,12	14,60	20	4	32 X,Y	20,00			
20T2.5-10	20	15,92	15,40	20	4	32 X,Y	20,00			
21T2.5-10	21	16,71	16,20	20	4	32 X,Y	20,00			
22T2.5-10	22	17,51	17,00	20	4	32 X,Y	20,00			
24T2.5-10	24	19,10	18,55	13	4	12 XL	25,15			
25T2.5-10	25	19,89	19,35	13	4	12 XL	25,15			
26T2.5-10	26	20,69	20,15	13	5	12 XL	25,15			
30T2.5-10	30	23,87	23,35	20	5	16 XL	31,74			
31T2.5-10	31	24,67	24,15	20	5	18 XL	34,80			
32T2.5-10	32	25,46	24,95	20	5	18 XL	34,80			
40T2.5-10	40	31,83	31,30	24	6	21XL	39,68			
44T2.5-10	44	35,01	34,50	24	6	21XL	39,68			
48T2.5-10	48	38,20	37,70	24	6	24XL	44,70			
52T2.5-10	52	41,38	40,85	24	6	24XL	44,70			
57T2.5-10	57	45,36	44,85	24	6	28XL	51,05			
60T2.5-10	60	47,75	47,25	24	6	30XL	54,36			
80T2.5-10	80	63,66	63,16	24	6	17H	74,61			
84T2.5-10	84	66,85	66,35	24	6	18H	79,38			
↓ Pulleys available up to this size ↓										
230T2,5-10	230	Dimensions : contact us								

\*Depending on availability - Dimensions in mm

Aluminium

Pitch  
**T5**


**Economy range**



- For use with T5 belts
- Pitch 5mm
- Material:  
Aluminium

### Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this products**

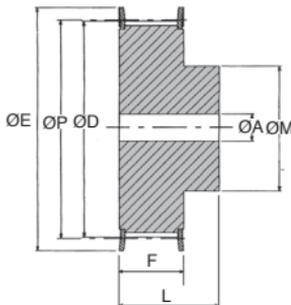

*Supplied with a pilot bore*

### Accessories

- T5 belts (tome 4 p.54)
- GTC tension rollers (tome 4 p.146)

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No. of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA*	Stock*	Price each 1 to 5
10T5-15/ECO	10	15,92	15,05	19,5	8	15	21	solid	✓	3,76 €
12T5-15/ECO	12	19,10	18,25	23	11	15	21	solid	✓	4,24 €
14T5-15/ECO	14	22,29	21,45	25	13	15	21	solid	✓	4,75 €
15T5-15/ECO	15	23,88	23,05	28	16	15	21	6	✓	5,18 €
16T5-15/ECO	16	25,47	24,60	32	18	15	21	6	✓	5,67 €
18T5-15/ECO	18	28,65	27,80	32	20	15	21	6	✓	5,94 €
19T5-15/ECO	19	30,25	29,40	36	22	15	21	6	✓	6,49 €
20T5-15/ECO	20	31,83	31,00	36	23	15	21	6	✓	6,75 €
22T5-15/ECO	22	35,02	34,15	38	24	15	21	6	✓	7,58 €
24T5-15/ECO	24	38,21	37,40	42	26	15	21	6	✓	8,10 €
25T5-15/ECO	25	39,80	38,95	44	26	15	21	6	✓	8,93 €
26T5-15/ECO	26	41,39	40,60	44	26	15	21	6	✓	9,53 €
27T5-15/ECO	27	42,98	42,20	48	30	15	21	8	✓	9,96 €
28T5-15/ECO	28	44,58	43,75	48	32	15	21	8	✓	10,43 €
30T5-15/ECO	30	47,76	46,95	51	34	15	21	8	✓	11,27 €
32T5-15/ECO	32	50,94	50,10	54	38	15	21	8	✓	12,51 €
36T5-15/ECO	36	57,31	56,45	64	38	15	21	8	✓	14,63 €
40T5-15/ECO	40	63,66	62,85	66,5	40	15	21	8	✓	16,38 €
42T5-15/ECO	42	66,86	66,00	70	40	15	21	8	-	17,65 €
44T5-15/ECO	44	70,05	69,20	-	45	15	21	8	-	17,49 €
48T5-15/ECO	48	76,42	75,55	-	50	15	21	8	✓	19,79 €
60T5-15/ECO	60	95,52	94,65	-	65	15	21	8	✓	29,55 €

\* Depending on availability - Dimensions in mm

# T-type timing pulley



## Pitch T5

## Aluminium


**Economy range**

For 16mm belts

- For use with T5 belts
- Pitch 5mm
- Material:  
Aluminium

### Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

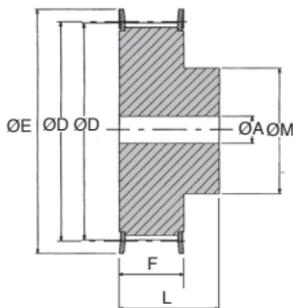

*Supplied with a pilot bore*

### Accessories

- T5 belts (tome 4 p.54)
- GTC tension rollers (tome 4 p.146)

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No. of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed		Price each 1 to 5
								ØA*	Stock*	
10T5-21/ECO	10	15,92	15,05	19,5	8	21	27	solid	✓	4,10 €
12T5-21/ECO	12	19,10	18,25	23	11	21	27	solid	✓	4,86 €
14T5-21/ECO	14	22,29	21,45	25	13	21	27	solid	✓	5,36 €
15T5-21/ECO	15	23,88	23,05	28	16	21	27	6	✓	5,84 €
16T5-21/ECO	16	25,47	24,60	32	18	21	27	6	✓	6,41 €
18T5-21/ECO	18	28,65	27,80	32	20	21	27	6	✓	6,85 €
19T5-21/ECO	19	30,25	29,40	36	22	21	27	6	-	7,57 €
20T5-21/ECO	20	31,83	31,00	36	23	21	27	6	✓	7,89 €
22T5-21/ECO	22	35,02	34,15	38	24	21	27	6	✓	9,05 €
24T5-21/ECO	24	38,21	37,40	42	26	21	27	6	✓	9,64 €
25T5-21/ECO	25	39,80	38,95	44	26	21	27	6	✓	10,25 €
26T5-21/ECO	26	41,39	40,60	44	26	21	27	6	-	11,55 €
27T5-21/ECO	27	42,98	42,20	48	30	21	27	8	✓	11,33 €
28T5-21/ECO	28	44,58	43,75	48	32	21	27	8	-	12,26 €
30T5-21/ECO	30	47,76	46,95	51	34	21	27	8	✓	13,07 €
32T5-21/ECO	32	50,94	50,10	54	38	21	27	8	✓	14,81 €
36T5-21/ECO	36	57,31	56,45	64	38	21	27	8	✓	17,23 €
40T5-21/ECO	40	63,66	62,85	66,5	40	21	27	8	✓	19,48 €
42T5-21/ECO	42	66,86	66,00	70	40	21	27	8	-	20,83 €
44T5-21/ECO	44	70,05	69,20	-	45	21	27	8	✓	21,53 €
48T5-21/ECO	48	76,42	75,55	-	50	21	27	8	-	24,02 €
60T5-21/ECO	60	95,52	94,65	-	65	21	27	8	✓	35,70 €

\*Depending on availability - Dimensions in mm

## Aluminium

## Pitch T5




Belt width 6mm

- Pitch 5mm
- Materials:
  - Pulley: Aluminium 6082
  - Flanges: Aluminium for pulleys with up to 46 teeth, steel for 47 teeth or more
- All pulleys have flanges

### Options

- Choose from 10 to 150 teeth

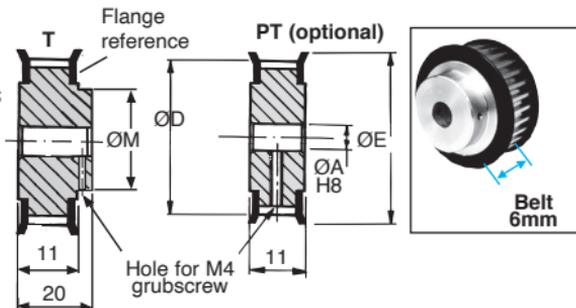

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	PCD (mm)	ØD (mm)	ØM (mm)	ØA (mm)	Flange ref.	ØE (mm)	Price each 1 to 5	
								T	PT
10T5-11	10	15,92	15,05	12	5	11XL	23,62	On request	On request
12T5-11	12	19,10	18,25	13	5	12XL	25,15		
14T5-11	14	22,28	21,45	16	5	14XL	28,44		
15T5-11	15	23,87	23,05	16	6	14XL	28,44		
16T5-11	16	25,46	24,60	16	6	14XL	28,44		
17T5-11	17	27,06	26,20	16	6	16XL	31,74		
18T5-11	18	28,65	27,80	20	6	18XL	34,80		
19T5-11	19	30,24	29,40	20	6	18XL	34,80		
20T5-11	20	31,83	31,00	20	6	20XL	38,10		
24T5-11	24	38,20	37,80	25	6	24XL	44,70		
25T5-11	25	39,79	39,00	25	6	24XL	44,70		
30T5-11	30	47,75	46,95	30	8	28XL	51,05		
32T5-11	32	50,93	50,10	30	8	16L	55,56		
36T5-11	36	57,30	56,45	30	8	14H	61,91		
37T5-11	37	58,89	58,05	40	8	15H	66,68		
40T5-11	40	63,66	62,85	40	8	16H	69,85		
45T5-11	45	71,62	70,80	40	8	18H	79,38		
48T5-11	48	76,39	75,55	40	8	19H	82,55		
50T5-11	50	79,58	78,75	60	10	20H	85,73		
56T5-11	56	89,13	88,30	60	10	22H	95,25		
60T5-11	60	95,49	94,65	60	10	24H	103,19		
70T5-11	70	111,41	110,60	60	10	28H	119,06		
80T5-11	80	127,32	126,50	60	10	32H	134,94		
84T5-11	84	133,69	132,85	60	10	33H	139,70		

↓ **Pulleys available up to this size** ↓

**150T5-11 150** dimensions : contact us

Dimensions in mm

# T-type timing pulley



## Pitch Aluminium

# T5



Belt width 10mm

- Pitch 5mm

- Materials:



Pulley: Aluminium 6082

Flanges: Aluminum for pulleys with up to 46 teeth, steel for 47 teeth or more

- All pulleys have flanges

### Options

- Choose from 10 to 150 teeth

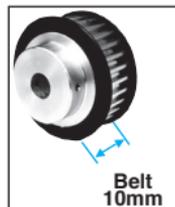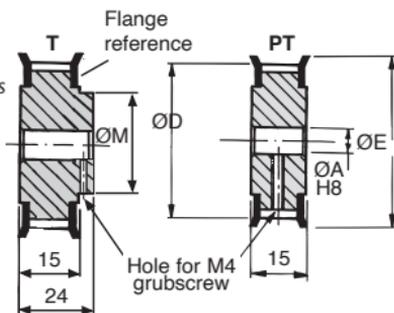

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	PCD (mm)	ØD (mm)	ØM (mm)	ØA (mm)	Flange ref.	ØE (mm)	Price each 1 to 5				
								T	PT			
10T5-15	10	15,92	15,05	12	5	11XL	23,62	<b>On request</b>	<b>On request</b>			
12T5-15	12	19,10	18,25	13	5	12XL	25,15					
14T5-15	14	22,28	21,45	16	5	14XL	28,44					
15T5-15	15	23,87	23,05	16	6	14XL	28,44					
16T5-15	16	25,46	24,60	16	6	14XL	28,44					
17T5-15	17	27,06	26,20	16	6	16XL	31,74					
18T5-15	18	28,65	27,80	20	6	18XL	34,80					
19T5-15	19	30,24	29,40	20	6	18XL	34,80					
20T5-15	20	31,83	31,00	20	6	20XL	38,10					
24T5-15	24	38,20	37,35	25	6	24XL	44,70					
25T5-15	25	39,79	39,00	25	6	24XL	44,70					
30T5-15	30	47,75	46,95	30	8	28XL	51,05					
32T5-15	32	50,93	50,10	30	8	16L	55,56					
36T5-15	36	57,30	56,45	30	8	14H	61,91					
37T5-15	37	58,89	58,05	40	8	15H	66,68					
40T5-15	40	63,66	62,85	40	8	16H	69,85					
45T5-15	45	71,62	70,80	40	8	18H	79,38					
48T5-15	48	76,39	75,55	40	8	19H	82,55					
50T5-15	50	79,58	78,75	60	10	20H	85,73					
56T5-15	56	89,13	88,30	60	10	22H	95,25					
60T5-15	60	95,49	94,65	60	10	24H	103,19					
70T5-15	70	111,41	110,60	60	10	28H	119,06					
80T5-15	80	127,32	126,50	60	10	32H	134,94					
84T5-15	84	133,69	132,85	60	10	33H	139,70					
<b>Pulleys available up to this size</b>												
150T5-11	150	dimensions : contact us										


Dimensions in mm



- Pitch 5mm
- Materials:  
Pulley: Aluminium 6082  
Flanges: Aluminium for pulleys with up to 46 teeth, steel for 47 teeth or more
- All pulleys have flanges

### Options

- Choose from 10 to 150 teeth

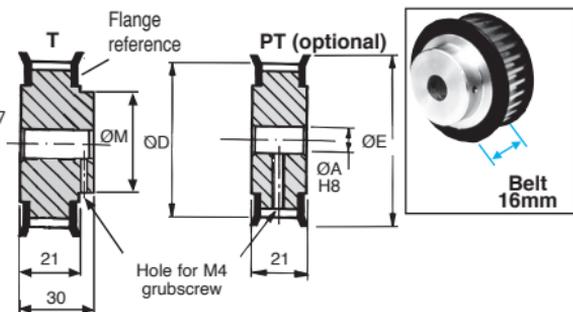

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List -12%	-25%	On request	

Part number	Z Teeth	PCD (mm)	ØD (mm)	ØM (mm)	ØA (mm)	Flange ref.	ØE (mm)	Price each 1 to 5	
								T	PT
10T5-21	10	15,92	15,05	12	5	11XL	23,62	On request	On request
12T5-21	12	19,10	18,25	13	5	12XL	25,15		
14T5-21	14	22,28	21,45	16	5	14XL	28,44		
15T5-21	15	23,87	23,05	16	6	14XL	28,44		
16T5-21	16	25,46	24,60	16	6	14XL	28,44		
17T5-21	17	27,06	26,20	16	6	16XL	31,74		
18T5-21	18	28,65	27,80	20	6	18XL	34,80		
19T5-21	19	30,24	29,40	20	6	18XL	34,80		
20T5-21	20	31,83	31,00	20	6	20XL	38,10		
24T5-21	24	38,20	37,35	25	6	24XL	44,70		
25T5-21	25	39,79	39,00	25	6	24XL	44,70		
30T5-21	30	47,75	46,95	30	8	28XL	51,05		
32T5-21	32	50,93	50,10	30	8	16L	55,56		
36T5-21	36	57,30	56,45	30	8	14H	61,91		
37T5-21	37	58,89	58,05	40	8	15H	66,68		
40T5-21	40	63,66	62,85	40	8	16H	69,85		
45T5-21	45	71,62	70,80	40	8	18H	79,38		
48T5-21	48	76,39	75,55	40	8	19H	82,55		
50T5-21	50	79,58	78,75	60	10	20H	85,73		
56T5-21	56	89,13	88,30	60	10	22H	95,25		
60T5-21	60	95,49	94,65	60	10	24H	103,19		
70T5-21	70	111,41	110,60	60	10	28H	119,06		
80T5-21	80	127,32	126,50	60	10	32H	134,94		
84T5-21	84	133,69	132,85	60	10	33H	134,94		

↓
**Pulleys available up to this size**
↓

150T5-21    150    dimensions : contact us

Dimensions in mm

# T-type timing pulley



Pitch  
**T10**

Aluminium



Belt width 16mm

Economy range


- Pitch 10mm
- Materials:  
Pulley: aluminium  
Flanges: steel

## Info.

- \*\*Pilot bore given as a guide only
- We are unable to modify these parts

## Accessoire

- T10 belt  
(tome 4 p.56)

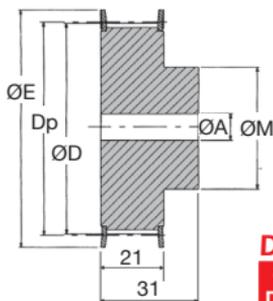

## DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore		Price each 1 to 5
						not guaranteed ØA**	Stock*	
12T10-21-AL	12	38,35	36,35	42	28	6	✓	8,38 €
14T10-21-AL	14	44,70	42,70	48	32	8	-	10,08 €
15T10-21-AL	15	47,90	45,90	51	32	8	✓	11,32 €
16T10-21-AL	16	51,10	49,10	54	35	8	✓	12,42 €
18T10-21-AL	18	57,45	55,45	60	40	8	✓	14,86 €
19T10-21-AL	19	60,65	58,65	66	44	8	-	15,96 €
20T10-21-AL	20	63,80	61,80	66	46	8	✓	17,20 €
22T10-21-AL	22	70,20	68,20	75	52	8	-	21,72 €
24T10-21-AL	24	76,55	74,55	83	58	8	✓	24,34 €
25T10-21-AL	25	79,75	77,75	83	60	8	-	24,50 €
26T10-21-AL	26	82,90	80,90	87	60	8	-	27,31 €
27T10-21-AL	27	86,10	84,10	91	60	8	-	29,75 €
28T10-21-AL	28	89,25	87,25	93	60	8	-	30,00 €
30T10-21-AL	30	95,65	93,65	102	60	8	-	35,75 €
32T10-21-AL	32	102,00	100,00	106	65	10	-	38,61 €
36T10-21-AL	36	114,75	112,75	119	70	10	✓	45,62 €
40T10-21-AL	40	127,45	125,45	131	80	10	-	56,72 €

\*Depending on availability - Dimensions in mm

Aluminium

Pitch  
**T10**

Belt width 25mm




- Pitch 10mm
- Materials:  
Pulley: aluminium  
Flanges: steel

### Info.

- \*\*Pilot bore given as a guide only
- We are unable to modify these parts

### Accessoire

- T10 belt  
(tome 4 p.56)

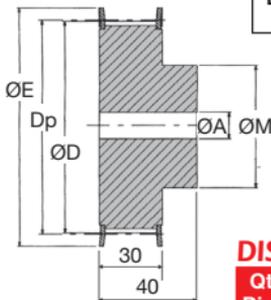

**Economy range**

### DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each
								1 to 5
12T10-30-AL	12	38,35	36,35	42	28	6	✓	9,83 €
14T10-30-AL	14	44,70	42,70	48	32	8	✓	12,17 €
15T10-30-AL	15	47,90	45,90	51	32	8	✓	13,38 €
16T10-30-AL	16	51,10	49,10	54	35	8	✓	14,97 €
18T10-30-AL	18	57,45	55,45	60	40	8	✓	17,78 €
19T10-30-AL	19	60,65	58,65	66	44	8	✓	19,30 €
20T10-30-AL	20	63,80	61,80	66	46	8	✓	20,62 €
22T10-30-AL	22	70,20	68,20	75	52	8	-	26,29 €
24T10-30-AL	24	76,55	74,55	83	58	8	-	29,37 €
25T10-30-AL	25	79,75	77,75	83	60	8	-	29,70 €
26T10-30-AL	26	82,90	80,90	87	60	8	-	32,97 €
27T10-30-AL	27	86,10	84,10	91	60	8	-	36,31 €
28T10-30-AL	28	89,25	87,25	93	60	8	✓	36,53 €
30T10-30-AL	30	95,65	93,65	102	60	8	✓	43,38 €
32T10-30-AL	32	102,00	100,00	106	65	10	-	47,15 €
36T10-30-AL	36	114,75	112,75	119	70	10	✓	55,69 €
40T10-30-AL	40	127,45	125,45	131	80	10	✓	69,31 €

\*Depending on availability - Dimensions in mm

# Nylon T-type timing pulley



## Pitch T10

## Nylon PA6 moulded

Belt width 16mm





- Positioning pulley
- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- We are unable to modify these parts

### Info

- \*\* Pilot bore not guaranteed

### Accessories

- T10 belt (tome 4 p.56)

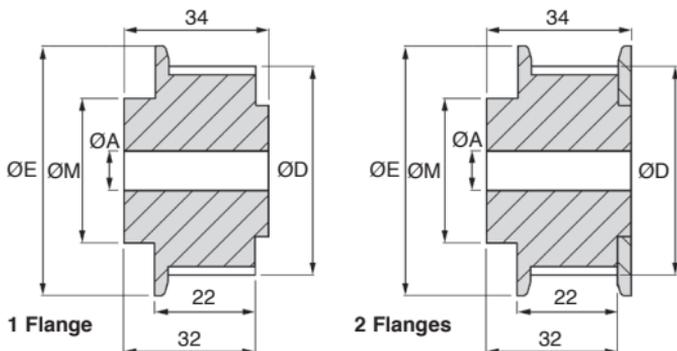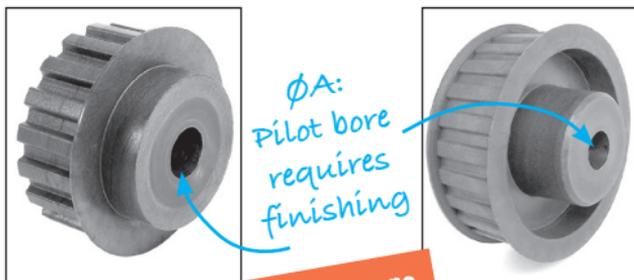

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z teeth	ØD (mm)	ØM (mm)	Pilot bore**			Price each 1 to 5	
				ØA (mm)	ØE (mm)	1 flange	2 flanges	
- 18T10-21-N2F	18	55,45	40	13	60	-	14,35 €	
- 20T10-21-N2F	20	61,80	40	12	67	-	18,42 €	
- 24T10-21-N2F	24	74,75	40	13	83	-	On request	
30T10-21-N1F	-	30	93,65	50	14	99	19,94 €	
32T10-21-N1F	-	32	100,00	50	14	105	On request	

Dimensions in mm