

# Nylon T-type timing pulley





## PITCH T10

## Nylon PA6 moulded



Belt width 16mm



- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- HPC are unable to modify these parts

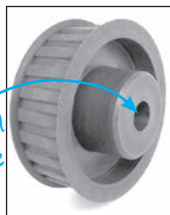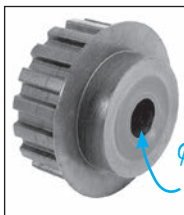

$\varnothing A$ : Pre-bored hole must be finished

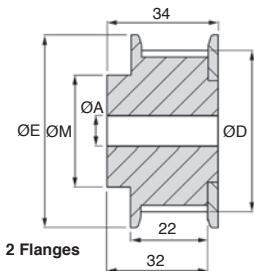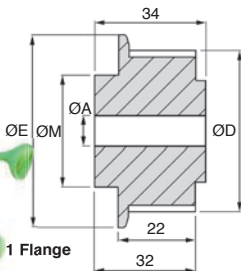

Economy range

### DISCOUNTS

| Qty   | 1+        | 6+   | 20+  | 40+  | 60+        | 100+ |
|-------|-----------|------|------|------|------------|------|
| Disc. | List -12% | -25% | -33% | -37% | On request |      |

| Part number    | Z teeth | OD (mm) | OM (mm) | Pre-bore OA (mm) | OE (mm) | Price each |           |
|----------------|---------|---------|---------|------------------|---------|------------|-----------|
|                |         |         |         |                  |         | 1 flange   | 2 flanges |
| - 18T10-21-N2F | 18      | 55,45   | 40      | 13               | 60      | -          | 9,55 €    |
| - 20T10-21-N2F | 20      | 61,80   | 40      | 12               | 67      | -          | 10,68 €   |
| - 22T10-21-N2F | 22      | 68,20   | 40      | 14               | 75      | -          | 11,64 €   |
| - 24T10-21-N2F | 24      | 74,75   | 40      | 13               | 83      | -          | 12,79 €   |
| 30T10-21-N1F - | 30      | 93,65   | 50      | 14               | 99      | 17,89 €    | -         |
| 32T10-21-N1F - | 32      | 100,00  | 50      | 14               | 105     | 21,57 €    | -         |

Dimensions in mm

## Our other products



SBS\_L

Chain link, Stainless steel



PW\_PWG3

Worm - precision range, Stainless steel



DOM180

Accessories, Clamping lever



AC144

Strike for toggle latch, 22mm



SVT\_CH

Screwjack - pivot mounting, Pivoting bracket



AC

Strike for toggle latch, 15mm



PRF\_CHA\_D

Hinge and joint, Lift-off hinge



BABS

630 Stainless steel compact ball pin, Hardened stainless steel



WJUM10

Drylin® W bearing block, Slide



SSB

Stainless steel bevel gear, 1:1



PGMT

Pull handle, Steel



T2

T type timing belt, T2.5 Steel cored polyurethane

## Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10\_21\_AL

T type timing pulley, Economy range - T10 aluminium



T10-BAR

T type tooth bar stock, T10



T5M\_T10M

T type timing belt per metre, T10 Steel cored polyurethane