

Nylon T-type timing pulley





PITCH T10

Nylon PA6 moulded



Belt width 16mm



- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- HPC are unable to modify these parts

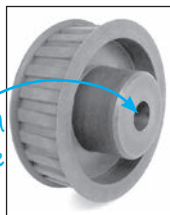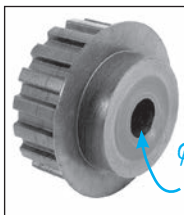

$\varnothing A$: Pre-bored hole must be finished

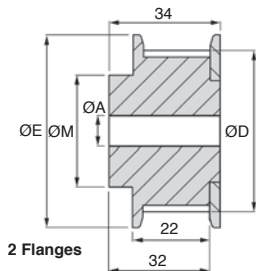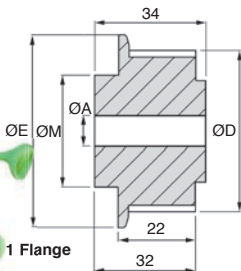

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z teeth	OD (mm)	OM (mm)	Pre-bore OA (mm)	OE (mm)	Price each	
						1 flange	2 flanges
- 18T10-21-N2F	18	55,45	40	13	60	-	9,55 €
- 20T10-21-N2F	20	61,80	40	12	67	-	10,68 €
- 22T10-21-N2F	22	68,20	40	14	75	-	11,64 €
- 24T10-21-N2F	24	74,75	40	13	83	-	12,79 €
30T10-21-N1F -	30	93,65	50	14	99	17,89 €	-
32T10-21-N1F -	32	100,00	50	14	105	21,57 €	-

Dimensions in mm

Our other products



LVT

Miniature motorised actuator 4A, 4 ampers



PSG125

Spur gear - precision range, Case hardened steel 20NCD2



VRBS

Folding lifting ring for welding, Folding - for welding



CHAu

Screwed hinge, 270°



HLA19

Right angle spiro bevel gearbox, Up to 43Nm



ZG2

Plastic spur gear, Machined plastic (delrin)



ZBconique

Machined plastic bevel gear, 1:1



IN2

Internal gear, Steel 20NCD2



BAC105

Storage bin, 8mm



EHD12

Internal epicyclic servo reducers, from 60 to 140 Nm



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



HLC28

Right angle spiro bevel gearbox, Up to 182Nm

Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10_21_AL

T type timing pulley, Economy range - T10 aluminium



T10-BAR

T type tooth bar stock, T10



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane