

Nylon T-type timing pulley





PITCH T10

Nylon PA6 moulded



Belt width 16mm



- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- HPC are unable to modify these parts

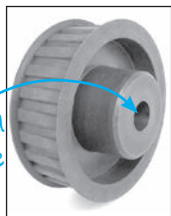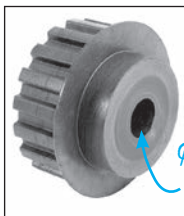

$\varnothing A$: Pre-bored hole must be finished

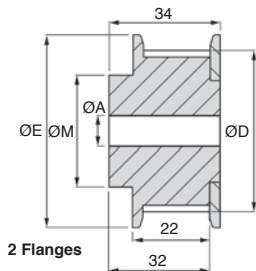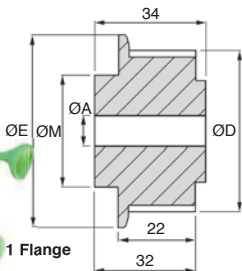

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z teeth	OD (mm)	OM (mm)	Pre-bore OA (mm)	OE (mm)	Price each	
						1 flange	2 flanges
- 18T10-21-N2F	18	55,45	40	13	60	-	9,55 €
- 20T10-21-N2F	20	61,80	40	12	67	-	10,68 €
- 22T10-21-N2F	22	68,20	40	14	75	-	11,64 €
- 24T10-21-N2F	24	74,75	40	13	83	-	12,79 €
30T10-21-N1F -	30	93,65	50	14	99	17,89 €	-
32T10-21-N1F -	32	100,00	50	14	105	21,57 €	-

Dimensions in mm

Our other products



GLB

Small 6 lobe threaded handle - female, Technopolymer - Stainless steel



LSAG

Sleeve for splined ball shaft, Chariot - from 514 N to 15386 N



PVL

Small lobed handle, Polyamide



GAL22

Conveyor wheel, Zinc plated steel



CYS

Internal circlip DIN472, internal DIN 472



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



G-ECO

Eco range Spur gear, Steel C45



DOMI30

Accessories, Plate



 
P30

Worm and wheel gear reducer, up to 8.80



CHN_CHNSS

Straight long link stainless steel chain,



PRF-GPA

Guide for aluminium profile, Parallel rails



RAG

Roller guide,

Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10_21_AL

T type timing pulley, Economy range - T10 aluminium



T10-BAR

T type tooth bar stock, T10



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane