

Nylon T-type timing pulley





PITCH T10

Nylon PA6 moulded



Belt width 16mm



- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- HPC are unable to modify these parts

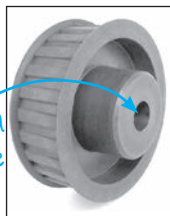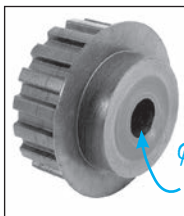

$\varnothing A$: Pre-bored hole must be finished

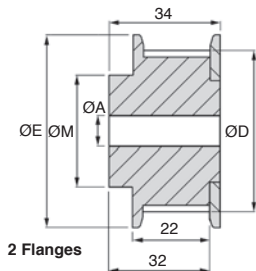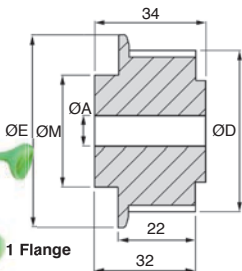

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	


Part number	Z teeth	OD (mm)	OM (mm)	Pre-bore OA (mm)	OE (mm)	Price each	
						1 flange	2 flanges
- 18T10-21-N2F	18	55,45	40	13	60	-	9,55 €
- 20T10-21-N2F	20	61,80	40	12	67	-	10,68 €
- 22T10-21-N2F	22	68,20	40	14	75	-	11,64 €
- 24T10-21-N2F	24	74,75	40	13	83	-	12,79 €
30T10-21-N1F	-	30	93,65	50	14	99	17,89 €
32T10-21-N1F	-	32	100,00	50	14	105	21,57 €

Dimensions in mm

Our other products




Free roller, Steel

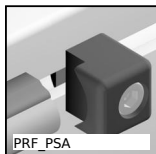

Shaft support for aluminium profile, Shaft stop



Panel stop, Panel stop

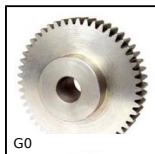

Steel spur gear, Steel 20NCD2



Spur gear - precision range, Pre-hardened Steel 35NCD6



 
Connecting plate for T type timing belts, T10



Standard wire thimble, Steel




Three-lobed knob, Thermoplastic / Brass or stainless steel insert



Hitch pin, Hitch



 Double cross clamp, Crossed



Worm and wheel set, Machined plastic



Worm and wheel set, Hardened steel

Complementary products



T type timing belt, T10 Steel cored polyurethane



T type timing pulley, Economy range - T10 aluminium



T type tooth bar stock, T10



T type timing belt per metre, T10 Steel cored polyurethane