

Nylon T-type timing pulley





PITCH T10

Nylon PA6 moulded



Belt width 16mm



- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- HPC are unable to modify these parts

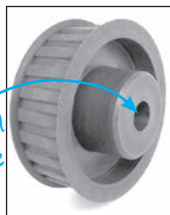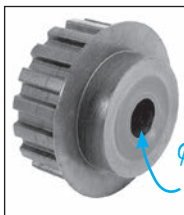

$\varnothing A$: Pre-bored hole must be finished

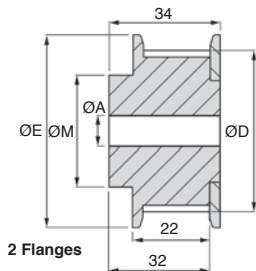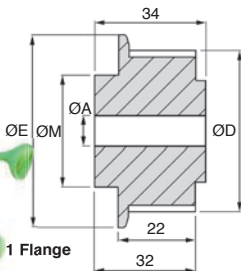

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z teeth	OD (mm)	OM (mm)	Pre-bore OA (mm)	OE (mm)	Price each	
						1 flange	2 flanges
- 18T10-21-N2F	18	55,45	40	13	60	-	9,55 €
- 20T10-21-N2F	20	61,80	40	12	67	-	10,68 €
- 22T10-21-N2F	22	68,20	40	14	75	-	11,64 €
- 24T10-21-N2F	24	74,75	40	13	83	-	12,79 €
30T10-21-N1F -	30	93,65	50	14	99	17,89 €	-
32T10-21-N1F -	32	100,00	50	14	105	21,57 €	-


Dimensions in mm

Our other products



DHX

Dowel pin internal thread, Extractable DIN 7979D

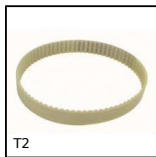

T2

T type timing belt, T2.5 Steel cored polyurethane



 
GSI_A

Stainless steel adjustable gas spring, Stainless steel



BPFss

Pressed stainless steel flange bearing, Stainless steel



LRH

Bi-directional leadscrew, Bi-directional - 1 thread



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



YG2

HEAVY DUTY spur gear, Steel 35NCD6



HK

Manual locking clamp, Manual locking clamp LWH



ERF

Quick fitting threaded cable terminal, Cable



CHAR

Spring hinge, screwed



VPR

Wing screw Hygienic Usit®, Stainless steel



HW_HT

Half-rail guide, Wheel

Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10_21_AL

T type timing pulley, Economy range - T10 aluminium



T10-BAR

T type tooth bar stock, T10



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane