

Aluminium

Pitch
T10



Belt width 25mm



- Pitch 10mm
- Materials:
Pulley: aluminium
Flanges: steel

Info.

- **Pilot bore given as a guide only
- We are unable to modify these parts

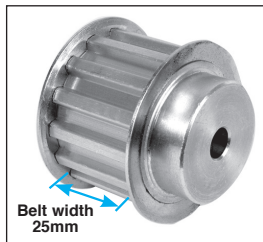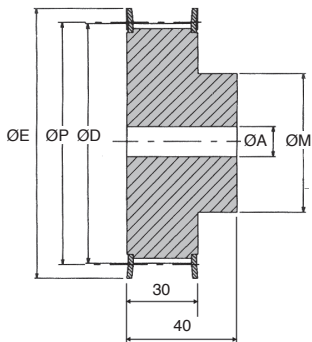

Economy range

DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-30-AL	12	38,35	36,35	42	28	6	✓	9,89 €
14T10-30-AL	14	44,70	42,70	48	32	8	✓	12,22 €
15T10-30-AL	15	47,90	45,90	51	32	8	✓	13,45 €
16T10-30-AL	16	51,10	49,10	54	35	8	✓	15,02 €
18T10-30-AL	18	57,45	55,45	60	40	8	✓	17,95 €
19T10-30-AL	19	60,65	58,65	66	44	8	✓	20,11 €
20T10-30-AL	20	63,80	61,80	66	46	8	✓	21,52 €
22T10-30-AL	22	70,20	68,20	75	52	8	✓	26,93 €
24T10-30-AL	24	76,55	74,55	83	58	8	✓	30,26 €
25T10-30-AL	25	79,75	77,75	83	60	8	-	30,62 €
26T10-30-AL	26	82,90	80,90	87	60	8	-	33,94 €
27T10-30-AL	27	86,10	84,10	91	60	8	✓	37,40 €
28T10-30-AL	28	89,25	87,25	93	60	8	✓	37,46 €
30T10-30-AL	30	95,65	93,65	102	60	8	✓	44,86 €
32T10-30-AL	32	102,00	100,00	106	65	10	✓	48,78 €
36T10-30-AL	36	114,75	112,75	119	70	10	✓	57,66 €
40T10-30-AL	40	127,45	125,45	131	80	10	✓	71,72 €

*Depending on availability - Dimensions in mm

Our other products



HG5
Steel spur gear, Steel
20NCD2



DCA
Suction cup, 1.5
bellows, silicon



IN1
Internal gear, Steel
20NCD2



KB_UU
Closed linear
precision bearing,
Precision - steel



PHG05
Parallel axis helical
gear - Precision range,
20NCD2 case
hardened s...



BLH40
Right angled gearbox,
from 3 to 10.30 Nm




PRF_ART
Articulated bracket for
use with aluminium
profile, With clamping
ha...



CHAuss
Screwed hinge, 270°



 CHAR6035
Spring hinge,
screwed/welded



ACLBT5
Closing system for
aluminium profile, 90°



D19 D29
Compression springs
in metre length steel,



ALIDRP240
24V DC power supply,
10 A

Complementary products



T10courroie
T type timing belt,
T10 Steel cored
polyurethane



T10-BAR
T type tooth bar
stock, T10



GTC
Belt tensioner, For
standard applications



T5M_T10M
T type timing belt per
metre, T10 Steel
cored polyurethane