

Aluminium

Pitch
T10


Belt width 25mm



- Pitch 10mm
- Materials:
Pulley: aluminium
Flanges: steel

Info.

- **Pilot bore given as a guide only
- We are unable to modify these parts

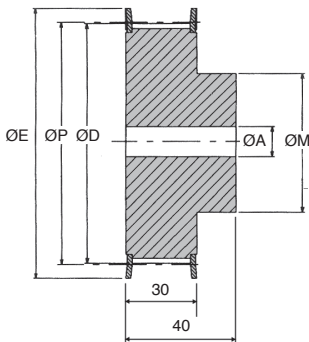

Economy range

DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-30-AL	12	38,35	36,35	42	28	6	✓	9,89 €
14T10-30-AL	14	44,70	42,70	48	32	8	✓	12,22 €
15T10-30-AL	15	47,90	45,90	51	32	8	✓	13,45 €
16T10-30-AL	16	51,10	49,10	54	35	8	✓	15,02 €
18T10-30-AL	18	57,45	55,45	60	40	8	✓	17,95 €
19T10-30-AL	19	60,65	58,65	66	44	8	✓	20,11 €
20T10-30-AL	20	63,80	61,80	66	46	8	✓	21,52 €
22T10-30-AL	22	70,20	68,20	75	52	8	✓	26,93 €
24T10-30-AL	24	76,55	74,55	83	58	8	✓	30,26 €
25T10-30-AL	25	79,75	77,75	83	60	8	-	30,62 €
26T10-30-AL	26	82,90	80,90	87	60	8	-	33,94 €
27T10-30-AL	27	86,10	84,10	91	60	8	✓	37,40 €
28T10-30-AL	28	89,25	87,25	93	60	8	✓	37,46 €
30T10-30-AL	30	95,65	93,65	102	60	8	✓	44,86 €
32T10-30-AL	32	102,00	100,00	106	65	10	✓	48,78 €
36T10-30-AL	36	114,75	112,75	119	70	10	✓	57,66 €
40T10-30-AL	40	127,45	125,45	131	80	10	✓	71,72 €

*Depending on availability - Dimensions in mm

Our other products



BOX-WM

Box set of washer - DIN125, Box set of steel washers



AC156-157

Strike for toggle latch, 25.5mm



RT25

Self-centering flanged locking assembly, Medium/high torque



INS_SS

Self tapping stainless steel insert, 316 stainless steel



 
SSB

Stainless steel bevel gear, 1:1



HTD8M_20

HTD Heavy duty timing pulley, HTD8 Cast




BETASS

Hitch pin, Hitch



PRES4HR

 Manual workbench press, Force up to 600kg



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



UCP_SS

Stainless steel pillow block bearing, Stainless steel



GP

Spring loaded toggle latch, Standard (GP22-GP23)



PRF_ECL

Nut for aluminium profile, Steel square nut with tab

Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10-BAR

T type tooth bar stock, T10



GTC

Belt tensioner, For standard applications



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane