

Aluminium

Pitch
T10


Belt width 25mm



- Pitch 10mm
- Materials:
Pulley: aluminium
Flanges: steel

Info.

- **Pilot bore given as a guide only
- We are unable to modify these parts

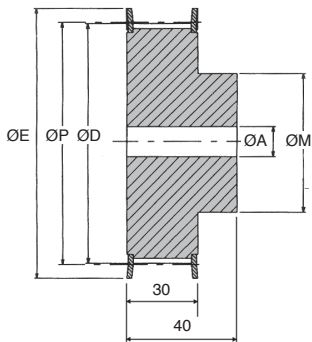

Economy range

DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-30-AL	12	38,35	36,35	42	28	6	✓	9,89 €
14T10-30-AL	14	44,70	42,70	48	32	8	✓	12,22 €
15T10-30-AL	15	47,90	45,90	51	32	8	✓	13,45 €
16T10-30-AL	16	51,10	49,10	54	35	8	✓	15,02 €
18T10-30-AL	18	57,45	55,45	60	40	8	✓	17,95 €
19T10-30-AL	19	60,65	58,65	66	44	8	✓	20,11 €
20T10-30-AL	20	63,80	61,80	66	46	8	✓	21,52 €
22T10-30-AL	22	70,20	68,20	75	52	8	✓	26,93 €
24T10-30-AL	24	76,55	74,55	83	58	8	✓	30,26 €
25T10-30-AL	25	79,75	77,75	83	60	8	-	30,62 €
26T10-30-AL	26	82,90	80,90	87	60	8	-	33,94 €
27T10-30-AL	27	86,10	84,10	91	60	8	✓	37,40 €
28T10-30-AL	28	89,25	87,25	93	60	8	✓	37,46 €
30T10-30-AL	30	95,65	93,65	102	60	8	✓	44,86 €
32T10-30-AL	32	102,00	100,00	106	65	10	✓	48,78 €
36T10-30-AL	36	114,75	112,75	119	70	10	✓	57,66 €
40T10-30-AL	40	127,45	125,45	131	80	10	✓	71,72 €

*Depending on availability - Dimensions in mm

Our other products



SCR

Suction cup threaded insert, Adaptor for insert



TUBE25_25

Square Tube, Aluminium or Stainless steel



CHB

Worm and wheel gear reducer, up to 73 Nm



BLHM50

Right angled gearbox, double output shafts, up to 30 Nm



GPB

Threaded spherical knob, Moulded thread



CHAsb63

Hinge without pin, Polymer pin hinge



BPL

Ball transfer unit light duty, Light



PLA

Flat magnet, Flat magnet with thread



 
CM_CO

Tools Hygienic Usit® and Hygienic Design®, Protective



CHAu

Screwed hinge, 270°



PRF_TOOL

Assembly key for aluminium profile, Assembly key



SHN

Hexagonal nut DIN934, Steel (Class 6|8)

Complementary products



T10courroie

T type timing belt, T10 Steel cored polyurethane



T10-BAR

T type tooth bar stock, T10



GTC

Belt tensioner, For standard applications



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane