

# Nylon T-type timing pulley





## PITCH T10

## Nylon PA6 moulded



Belt width 16mm



- Pitch 10mm (T10)
- Material: Moulded PA6 nylon reinforced with 30% glass fibre
- HPC are unable to modify these parts

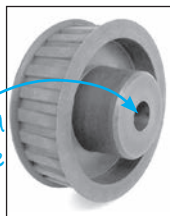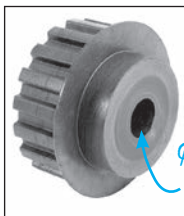

$\varnothing A$ : Pre-bored hole must be finished

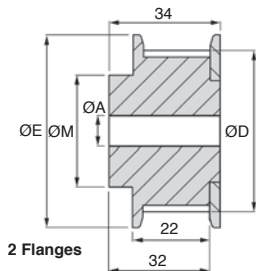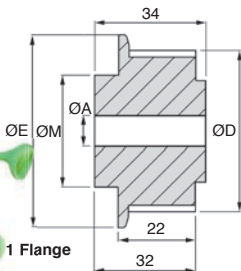

**Economy range**

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z teeth	OD (mm)	OM (mm)	Pre-bore OA (mm)	OE (mm)	Price each	
						1 flange	2 flanges
- 18T10-21-N2F	18	55,45	40	13	60	-	9,55 €
- 20T10-21-N2F	20	61,80	40	12	67	-	10,68 €
- 22T10-21-N2F	22	68,20	40	14	75	-	11,64 €
- 24T10-21-N2F	24	74,75	40	13	83	-	12,79 €
30T10-21-N1F	-	30	93,65	50	14	99	17,89 €
32T10-21-N1F	-	32	100,00	50	14	105	21,57 €

Dimensions in mm

## Our other products



BRI  
Panel holder, Panel holder



ACA  
Steel splined shaft, Steel



 
RUR  
Wheel, Polyurethane - Aluminium rim (Free running)



F7-SN  
Multifunction display, Articulated support



BABpss  
301 Stainless steel ball pin, Stainless steel



SLS  
Bearing block for leadscrew, Fixed Drylin® bearing block



SVR5  
Screwjack with travelling nut, with moving nut



HDSS  
Needle roller double universal joint - Stainless steel, Heavy duty



PTA50  
Articulated levelling foot, pressed base Ø50, Ø 50



NPR  
Reflector support,



TIF  
Threaded rod - DIN975, Stainless steel A2



M1  
Worm and wheel set, Machined plastic (delrin)

## Complementary products



T10courroie  
T type timing belt, T10 Steel cored polyurethane



T10\_21\_AL  
T type timing pulley, Economy range - T10 aluminium



T10-BAR  
T type tooth bar stock, T10



T5M\_T10M  
T type timing belt per metre, T10 Steel cored polyurethane