

Aluminium

Pitch
T10


Belt width 25mm



- Pitch 10mm
- Materials:
Pulley: aluminium
Flanges: steel

Info.

- **Pilot bore given as a guide only
- We are unable to modify these parts

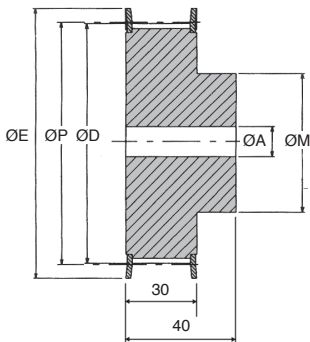

Economy range

DISCOUNTS

Qty	1+	6+	10+	20+
Disc.	List	-12%	-20%	On request

Part number	Z teeth	PCD (mm)	ØD (mm)	ØE (mm)	ØM (mm)	Pilot bore not guaranteed ØA**	Stock*	Price each 1 to 5
12T10-30-AL	12	38,35	36,35	42	28	6	✓	9,89 €
14T10-30-AL	14	44,70	42,70	48	32	8	✓	12,22 €
15T10-30-AL	15	47,90	45,90	51	32	8	✓	13,45 €
16T10-30-AL	16	51,10	49,10	54	35	8	✓	15,02 €
18T10-30-AL	18	57,45	55,45	60	40	8	✓	17,95 €
19T10-30-AL	19	60,65	58,65	66	44	8	✓	20,11 €
20T10-30-AL	20	63,80	61,80	66	46	8	✓	21,52 €
22T10-30-AL	22	70,20	68,20	75	52	8	✓	26,93 €
24T10-30-AL	24	76,55	74,55	83	58	8	✓	30,26 €
25T10-30-AL	25	79,75	77,75	83	60	8	-	30,62 €
26T10-30-AL	26	82,90	80,90	87	60	8	-	33,94 €
27T10-30-AL	27	86,10	84,10	91	60	8	✓	37,40 €
28T10-30-AL	28	89,25	87,25	93	60	8	✓	37,46 €
30T10-30-AL	30	95,65	93,65	102	60	8	✓	44,86 €
32T10-30-AL	32	102,00	100,00	106	65	10	✓	48,78 €
36T10-30-AL	36	114,75	112,75	119	70	10	✓	57,66 €
40T10-30-AL	40	127,45	125,45	131	80	10	✓	71,72 €

*Depending on availability - Dimensions in mm

Our other products



SDCss
Positioning sleeve for indexing pin, For pin Ø4 to Ø12



VB
Small 6 lobe threaded handle - female, Duroplast - Stainless steel



WSSss
Symmetrical S shaped hook stainless steel, Stainless steel



GCB880
Curved track for slat top chain, Ranges 880 and 881



SVG
Adjustable latch clamp with strike plate, Stroke from 118mm to 130,5mm



RFK38B
Hypoid gearbox - Stainless steel, up to 200 Nm



EMS
Stainless steel knurled thumb nut, Knurled



EKN
Bellows coupling Gerwah® , from 0.5 to 12Nm



T5-16ECO
T type timing pulley, Economy range - T5 aluminium



BAGSS
Stainless steel Clamping collar, Stainless steel



BAC105
Storage bin, 8mm



DOG319
Motor-gearbox 12V and 24V DC, from 4 to 9 Nm

Complementary products



T10courroie
T type timing belt, T10 Steel cored polyurethane



T10-BAR
T type tooth bar stock, T10



GTC
Belt tensioner, For standard applications



T5M_T10M
T type timing belt per metre, T10 Steel cored polyurethane