

T-type belt



Pitch T10

Polyurethane with steel core

- Pitch 10mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

Options

- Belt by the metre **T10M**
- Alternative lengths/widths

Accessories

- BTE arm and GTC roller belt tensioner

Info.

- When ordering, add the width to the part number.

Eg: T10/120/4



Compatible with T10 pulley


 
DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 6+ | 20+ |
| Disc. | List | -7% | On request |

| Part number | Length | No. of teeth | Price each 1 to 5 for width | | | |
|-------------|--------|--------------|-----------------------------|---------|------------|------------|
| | | | 16mm | 25mm | 32mm | 50mm |
| T 10/260 | 260 | 26 | 25,34 € | 35,16 € | On request | On request |
| T 10/370 | 370 | 37 | 27,41 € | 38,27 € | | |
| T 10/410 | 410 | 41 | 28,40 € | 39,48 € | | |
| T 10/500 | 500 | 50 | 30,69 € | 41,98 € | | |
| T 10/530 | 530 | 53 | 31,40 € | 43,04 € | | |
| T 10/560 | 560 | 56 | 32,65 € | 44,51 € | | |
| T 10/600 | 600 | 60 | 33,58 € | 45,55 € | | |
| T 10/610 | 610 | 61 | 33,70 € | 46,05 € | | |
| T 10/630 | 630 | 63 | 34,70 € | 47,03 € | | |
| T 10/660 | 660 | 66 | 35,71 € | 48,54 € | | |
| T 10/680 | 680 | 68 | 31,91 € | 53,70 € | | |
| T 10/690 | 690 | 69 | 36,72 € | 50,10 € | | |
| T 10/700 | 700 | 70 | 38,17 € | 45,42 € | | |
| T 10/720 | 720 | 72 | 37,96 € | 51,84 € | | |
| T 10/730 | 730 | 73 | 36,37 € | 56,73 € | | |
| T 10/750 | 750 | 75 | 40,08 € | 58,04 € | | |

Dimensions in mm

Pitch T10

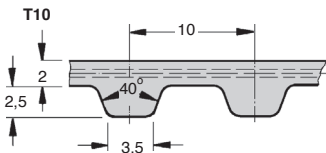

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 6+ | 20+ |
| Disc. | List | -7% | On request |

| Part number | Length | No. of teeth | Price each 1 to 5 for width | | | |
|-------------|--------|--------------|-----------------------------|----------|------------|------------|
| | | | 16mm | 25mm | 32mm | 50mm |
| T 10/780 | 780 | 78 | 40,25 € | 55,10 € | On request | On request |
| T 10/810 | 810 | 81 | 41,49 € | 56,84 € | | |
| T 10/840 | 840 | 84 | 42,78 € | 58,67 € | | |
| T 10/880 | 880 | 88 | 44,25 € | 61,17 € | | |
| T 10/890 | 890 | 89 | 44,75 € | 62,19 € | | |
| T 10/920 | 920 | 92 | 46,05 € | 64,18 € | | |
| T 10/960 | 960 | 96 | 47,54 € | 67,18 € | | |
| T 10/970 | 970 | 97 | 48,06 € | 68,01 € | | |
| T 10/980 | 980 | 98 | 48,54 € | 68,70 € | | |
| T 10/1010 | 1010 | 101 | 50,10 € | 70,75 € | | |
| T 10/1080 | 1080 | 108 | 52,85 € | 75,27 € | | |
| T 10/1110 | 1110 | 111 | 54,53 € | 83,86 € | | |
| T 10/1140 | 1140 | 114 | 55,63 € | 79,35 € | | |
| T 10/1150 | 1150 | 115 | 55,86 € | 79,79 € | | |
| T 10/1210 | 1210 | 121 | 58,67 € | 84,09 € | | |
| T 10/1240 | 1240 | 124 | 60,21 € | 85,81 € | | |
| T 10/1250 | 1250 | 125 | 60,38 € | 86,63 € | | |
| T 10/1300 | 1300 | 130 | 62,89 € | 89,94 € | | |
| T 10/1320 | 1320 | 132 | 63,69 € | 91,15 € | | |
| T 10/1350 | 1350 | 135 | 64,98 € | 93,17 € | | |
| T 10/1390 | 1390 | 139 | 66,96 € | 95,98 € | | |
| T 10/1400 | 1400 | 140 | 67,47 € | 96,44 € | | |
| T 10/1420 | 1420 | 142 | 68,24 € | 97,67 € | | |
| T 10/1460 | 1460 | 146 | 70,00 € | 100,26 € | | |
| T 10/1500 | 1500 | 150 | sur demande | 111,37 € | | |
| T 10/1560 | 1560 | 156 | 73,03 € | 106,27 € | | |
| T 10/1610 | 1610 | 161 | 76,81 € | 110,05 € | | |
| T 10/1750 | 1750 | 175 | 83,60 € | 120,65 € | | |
| T 10/1780 | 1780 | 178 | 85,10 € | 122,88 € | | |
| T 10/1880 | 1880 | 188 | 90,14 € | 130,47 € | | |
| T 10/1960 | 1960 | 196 | 95,69 € | 138,02 € | | |
| T 10/2250 | 2250 | 225 | 118,11 € | 173,42 € | | |

Dimensions in mm

Our other products



CHC

Socket headed screw,
Steel class 12.19



DB

Steel bevel gear, 2:1



DOMI50

Accessories, Plate



GBS

Nut for ballscrew,
Flanged ballscrew nut



BPM

Slotted spring plunger
with ball tip, Stainless
steel 303



DOMI30

Accessories, Plate



VT

Vari-Tork® slip
friction clutch, 0.53 to
1.32 Nm



CLSCLP_SS

Clevis components,
short version,
Stainless steel - short
range



RBGpl

Swivel castor with
double brake, Steel -
grey rubber



CHA38_SS

Stainless steel face
frame hinge, Surface
mount



NDS14C

Angular connector,
Universal angular
connector



OP3_14_06

Reducing sleeve for
OP indicators,
Reduction socket

Complementary products



GTC

Belt tensioner, For
standard applications



T10-BAR

T type tooth bar
stock, T10



T10_21_AL

T type timing pulley,
Economy range - T10
aluminium



T10_21N1F

T type timing pulley,
Economy range - T10
moulded plastic
(nylon)