

# T-type belt

Stock

## Pitch T10

Polyurethane with steel core

- Pitch 10mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

### Options

- Belt by the metre **T10M**
- Alternative lengths/widths

### Accessories

- BTE arm and GTC roller belt tensioner

### Info.

- When ordering, add the width to the part number.

Eg: T10/120/4



Compatible with T10 pulley


 
### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width		
			16mm	25mm	32mm 50mm
T 10/260	260	26	25,34 €	35,16 €	On request
T 10/370	370	37	27,41 €	38,27 €	
T 10/410	410	41	28,40 €	39,48 €	
T 10/500	500	50	30,69 €	41,98 €	
T 10/530	530	53	31,40 €	43,04 €	
T 10/560	560	56	32,65 €	44,51 €	
T 10/600	600	60	33,58 €	45,55 €	
T 10/610	610	61	33,70 €	46,05 €	
T 10/630	630	63	34,70 €	47,03 €	
T 10/660	660	66	35,71 €	48,54 €	
T 10/680	680	68	31,91 €	53,70 €	
T 10/690	690	69	36,72 €	50,10 €	
T 10/700	700	70	38,17 €	45,42 €	
T 10/720	720	72	37,96 €	51,84 €	
T 10/730	730	73	36,37 €	56,73 €	
T 10/750	750	75	40,08 €	58,04 €	

Dimensions in mm

# Pitch T10

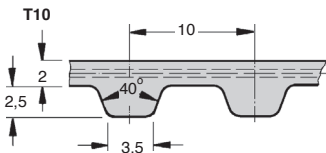

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/780	780	78	40,25 €	55,10 €	On request	On request
T 10/810	810	81	41,49 €	56,84 €		
T 10/840	840	84	42,78 €	58,67 €		
T 10/880	880	88	44,25 €	61,17 €		
T 10/890	890	89	44,75 €	62,19 €		
T 10/920	920	92	46,05 €	64,18 €		
T 10/960	960	96	47,54 €	67,18 €		
T 10/970	970	97	48,06 €	68,01 €		
T 10/980	980	98	48,54 €	68,70 €		
T 10/1010	1010	101	50,10 €	70,75 €		
T 10/1080	1080	108	52,85 €	75,27 €		
T 10/1110	1110	111	54,53 €	83,86 €		
T 10/1140	1140	114	55,63 €	79,35 €		
T 10/1150	1150	115	55,86 €	79,79 €		
T 10/1210	1210	121	58,67 €	84,09 €		
T 10/1240	1240	124	60,21 €	85,81 €		
T 10/1250	1250	125	60,38 €	86,63 €		
T 10/1300	1300	130	62,89 €	89,94 €		
T 10/1320	1320	132	63,69 €	91,15 €		
T 10/1350	1350	135	64,98 €	93,17 €		
T 10/1390	1390	139	66,96 €	95,98 €		
T 10/1400	1400	140	67,47 €	96,44 €		
T 10/1420	1420	142	68,24 €	97,67 €		
T 10/1460	1460	146	70,00 €	100,26 €		
T 10/1500	1500	150	sur demande	111,37 €		
T 10/1560	1560	156	73,03 €	106,27 €		
T 10/1610	1610	161	76,81 €	110,05 €		
T 10/1750	1750	175	83,60 €	120,65 €		
T 10/1780	1780	178	85,10 €	122,88 €		
T 10/1880	1880	188	90,14 €	130,47 €		
T 10/1960	1960	196	95,69 €	138,02 €		
T 10/2250	2250	225	118,11 €	173,42 €		

Dimensions in mm

## Our other products



VTLM  
3 lobed handle,  
Polyamide - Steel



CHML40  
Worm and wheel gear  
reducer, up to 57 Nm  
- Integrated torque  
limiter



LACT\_SS  
Adjustable Stainless  
steel cam lever, Male



 
SCR  
Suction cup threaded  
insert, Insert for  
suction cup - Socket  
screw



P60  
Worm and wheel gear  
reducer, up to 118  
Nm



M1  
Worm and wheel set,  
Hardened steel



KSM  
Cylindrical steel nut,  
Steel - 1 thread



CHAEpac  
Square decorative  
screwed hinges,  
carbon fibre  
reinforced




PM3  
Worm and wheel set,  
Hardened steel



PM2  
Worm and wheel set,  
Bronze



SRG  
Adjustable latch  
clamp with strike  
plate, Stroke from

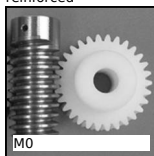

M0  
Worm and wheel set,  
Machined plastic  
(delrin)

## Complementary products



GTC  
Belt tensioner, For  
standard applications



T10-BAR  
T type tooth bar  
stock, T10



T10\_21\_AL  
T type timing pulley,  
Economy range - T10  
aluminium



T10\_21N1F  
T type timing pulley,  
Economy range - T10  
moulded plastic  
(nylon)