

# T-type belt

Stock

## Pitch T10

Polyurethane with steel core

- Pitch 10mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

### Options

- Belt by the metre **T10M**
- Alternative lengths/widths

### Accessories

- **BTE arm and GTC roller belt tensioner**

### Info.

- When ordering, add the width to the part number.

Eg: **T10/120/4**



Compatible with T10 pulley


 
### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/260	260	26	25,34 €	35,16 €	On request	On request
T 10/370	370	37	27,41 €	38,27 €		
T 10/410	410	41	28,40 €	39,48 €		
T 10/500	500	50	30,69 €	41,98 €		
T 10/530	530	53	31,40 €	43,04 €		
T 10/560	560	56	32,65 €	44,51 €		
T 10/600	600	60	33,58 €	45,55 €		
T 10/610	610	61	33,70 €	46,05 €		
T 10/630	630	63	34,70 €	47,03 €		
T 10/660	660	66	35,71 €	48,54 €		
T 10/680	680	68	31,91 €	53,70 €		
T 10/690	690	69	36,72 €	50,10 €		
T 10/700	700	70	38,17 €	45,42 €		
T 10/720	720	72	37,96 €	51,84 €		
T 10/730	730	73	36,37 €	56,73 €		
T 10/750	750	75	40,08 €	58,04 €		

Dimensions in mm

# Pitch T10

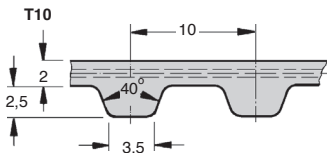

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/780	780	78	40,25 €	55,10 €	On request	On request
T 10/810	810	81	41,49 €	56,84 €		
T 10/840	840	84	42,78 €	58,67 €		
T 10/880	880	88	44,25 €	61,17 €		
T 10/890	890	89	44,75 €	62,19 €		
T 10/920	920	92	46,05 €	64,18 €		
T 10/960	960	96	47,54 €	67,18 €		
T 10/970	970	97	48,06 €	68,01 €		
T 10/980	980	98	48,54 €	68,70 €		
T 10/1010	1010	101	50,10 €	70,75 €		
T 10/1080	1080	108	52,85 €	75,27 €		
T 10/1110	1110	111	54,53 €	83,86 €		
T 10/1140	1140	114	55,63 €	79,35 €		
T 10/1150	1150	115	55,86 €	79,79 €		
T 10/1210	1210	121	58,67 €	84,09 €		
T 10/1240	1240	124	60,21 €	85,81 €		
T 10/1250	1250	125	60,38 €	86,63 €		
T 10/1300	1300	130	62,89 €	89,94 €		
T 10/1320	1320	132	63,69 €	91,15 €		
T 10/1350	1350	135	64,98 €	93,17 €		
T 10/1390	1390	139	66,96 €	95,98 €		
T 10/1400	1400	140	67,47 €	96,44 €		
T 10/1420	1420	142	68,24 €	97,67 €		
T 10/1460	1460	146	70,00 €	100,26 €		
T 10/1500	1500	150	sur demande	111,37 €		
T 10/1560	1560	156	73,03 €	106,27 €		
T 10/1610	1610	161	76,81 €	110,05 €		
T 10/1750	1750	175	83,60 €	120,65 €		
T 10/1780	1780	178	85,10 €	122,88 €		
T 10/1880	1880	188	90,14 €	130,47 €		
T 10/1960	1960	196	95,69 €	138,02 €		
T 10/2250	2250	225	118,11 €	173,42 €		

Dimensions in mm

## Our other products



LVT  
Miniature motorised  
actuator 1A, 1 amper



CAMF80EB  
Articulated foot with  
sheet metal base  
Ø80, Articulated foot



MPS  
Hexagonal spacer,  
Stainless steel 303



BAC110  
Swivel storage bin,  
Storage bin



NT92  
Spur gear coaxial  
gearbox, from 15 to  
40 Nm - In-line



CABtool  
Fitting cable tools,  
Crimping tools



SVG  
Adjustable latch  
clamp with strike  
plate, Stroke from  
174mm to 190mm



MCLred  
Reducing sleeve  
female/female,  
Cylindrical - stainless  
steel




PLM-20SC  
Cylindrical magnet,  
Cylindrical magnet



PSG35  
Spur gear - precision  
range, Stainless steel  
303



 PSG25  
Spur gear - precision  
range, Stainless steel  
316



PRL  
Wear strip for slat top  
chain, L profile to be  
clipped

## Complementary products



GTC  
Belt tensioner, For  
standard applications



T10-BAR  
T type tooth bar  
stock, T10



T10\_21\_AL  
T type timing pulley,  
Economy range - T10  
aluminium



T10\_21N1F  
T type timing pulley,  
Economy range - T10  
moulded plastic  
(nylon)