

# T type toothed timing pulley bar stock

## T2.5-BAR

Aluminium




- **Toolthed bar stock to be cut to length by the customer**
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



### Info.

- We are unable to modify this product

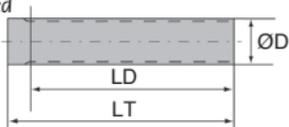

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L <sub>D</sub>	Total length L <sub>T</sub>	Price each
10T2.5-BAR	10	7,45	50	75	2,71 €
12T2.5-BAR	12	9,00	50	75	2,78 €
13T2.5-BAR	13	9,80	50	75	2,90 €
14T2.5-BAR	14	10,60	50	75	3,09 €
15T2.5-BAR	15	11,40	50	75	3,29 €
16T2.5-BAR	16	12,20	50	75	3,38 €
17T2.5-BAR	17	13,00	50	75	3,45 €
18T2.5-BAR	18	13,80	50	75	3,59 €
19T2.5-BAR	19	14,60	90	120	6,54 €
20T2.5-BAR	20	15,40	90	120	6,84 €
21T2.5-BAR	21	16,20	90	120	7,45 €
22T2.5-BAR	22	17,00	125	140	9,72 €
24T2.5-BAR	24	18,55	125	140	10,54 €
26T2.5-BAR	26	20,15	125	140	11,54 €
27T2.5-BAR	27	20,95	125	140	11,65 €
28T2.5-BAR	28	21,75	125	140	11,97 €
29T2.5-BAR	29	22,55	125	140	12,66 €
30T2.5-BAR	30	23,35	125	140	12,73 €
32T2.5-BAR	32	24,95	125	140	13,80 €
34T2.5-BAR	34	26,55	125	140	14,50 €
35T2.5-BAR	35	27,35	132	140	15,42 €
36T2.5-BAR	36	28,10	132	140	16,54 €
38T2.5-BAR	38	29,70	140	140	16,84 €
40T2.5-BAR	40	31,30	140	140	18,16 €
42T2.5-BAR	42	32,90	140	140	20,22 €
44T2.5-BAR	44	34,50	140	140	22,46 €
45T2.5-BAR	45	35,30	140	140	22,92 €
48T2.5-BAR	48	37,70	140	140	24,26 €
50T2.5-BAR	50	39,29	160	160	29,48 €
60T2.5-BAR	60	47,25	160	160	38,23 €
65T2.5-BAR	65	51,20	160	160	44,19 €
70T2.5-BAR	70	55,20	160	160	48,36 €
72T2.5-BAR	72	56,80	160	160	51,03 €
90T2.5-BAR	90	71,12	160	160	74,03 €
100T2.5-BAR	100	79,08	160	160	99,01 €

Dimensions in mm

## Our other products



ZG1  
Plastic spur gear,  
Machined plastic  
(delrin)




DCA  
Suction cup, 1.5  
bellows, silicon



RFVcap  
Stainless steel  
protective cover,  
Closed protective  
cover



R203  
Die spring ISO10243,  
Light

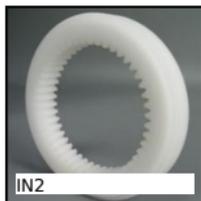


IN2  
Internal gear,  
Machined plastic  
(delrin)



SEV  
Vertical stirrup toggle  
clamp, Vertical Latch  
Clamp - steel



CHAFR  
Adjustable friction  
hinges, Friction

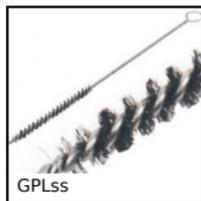

GPLss  
Brush, stainless steel



EHD12  
Internal epicyclic  
servo reducers, from  
60 to 140 Nm



DOMI30  
Domino 30 adjustable  
slide, Slide DOMILINE  
30 with counter and



BOXdhx  
Boxed set of threaded  
dowel pins DIN7970D,  
Boxed set -



TIFss  
Threaded stud -  
DIN976A, Stainless  
steel

## Complementary products




T5-BAR  
T type tooth bar  
stock, T5



T25-6ECO  
T type timing pulley,  
Economy range - T2.5  
aluminium



T2  
T type timing belt,  
T2.5 Steel cored  
polyurethane

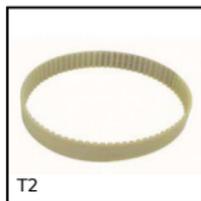

T2  
T type timing belt,  
T2.5 Steel cored  
polyurethane