

- Pitch 2.5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

### Options


 
- Belt by the metre **T2.5M**
- Alternative lengths/widths

### Accessories

- **BTE** arm and **GTC** roller belt tensioner

### Info.

- When ordering, add the width to the part number  
Eg: T2.5/120/4

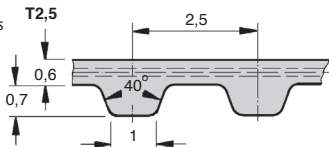

Compatible with  
T2.5 pulley

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Stock*	Stock*	Price each 1 to 5 for width		
			4mm	6mm	4mm	6mm	10mm
T 2.5/120	120,00	48	✓	✓	9,07 €	10,07 €	On request
T 2.5/145	145,00	58	✓	✓	9,19 €	10,17 €	
T 2.5/160	160,00	64	✓	✓	9,22 €	10,22 €	
T 2.5/177	177,50	71	✓	✓	9,42 €	10,46 €	
T 2.5/180	180,00	72	✓	✓	9,42 €	10,46 €	
T 2.5/182	182,50	73	✓	✓	9,42 €	10,46 €	
T 2.5/200	200,00	80	✓	✓	9,42 €	10,46 €	
T 2.5/230	230,00	92	✓	✓	10,08 €	11,24 €	
T 2.5/245	245,00	98	✓	✓	10,00 €	11,12 €	
T 2.5/265	265,00	106	✓	✓	10,09 €	11,25 €	
T 2.5/285	285,00	114	✓	✓	10,15 €	11,29 €	
T 2.5/290	290,00	116	✓	✓	10,57 €	11,77 €	
T 2.5/317	317,50	127	✓	✓	10,53 €	11,71 €	
T 2.5/330	330,00	132	✓	✓	10,66 €	11,83 €	
T 2.5/380	380,00	152	✓	✓	11,25 €	12,50 €	
T 2.5/420	420,00	168	-	✓	14,35 €	12,47 €	
T 2.5/480	480,00	192	✓	✓	11,66 €	12,94 €	
T 2.5/500	500,00	200	✓	✓	11,83 €	13,13 €	
T 2.5/600	600,00	240	✓	✓	16,19 €	17,99 €	
T 2.5/620	620,00	248	-	✓	16,81 €	18,70 €	
T 2.5/650	650,00	260	-	✓	16,46 €	18,25 €	
T 2.5/780	780,00	312	✓	✓	18,97 €	21,11 €	
T 2.5/950	950,00	380	✓	-	20,96 €	23,31 €	

\*Depending on availability - Dimensions in mm

## Our other products



PRF\_FIX\_ANG  
Fastener for aluminium profile, Angular joint



GPB  
Threaded spherical knob, With brass insert



PNA\_R  
PERIFLEX elastic coupling, Replacement tyre



WSRM  
Cylindrical polymer nut, Polymer (Iglidur®) - 1 thread



UCP\_PBT  
Stainless/Polymer pillow block bearing, Polymer and stainless steel



T10\_21N1F  
T type timing pulley, Economy range - T10 moulded plastic (nylon)



GALRUB  
60mm rubber wheel for conveyor belt, Rubber



GCT  
Pipe linch pin, Tube linch pin



MRA\_SS  
Stainless steel Quick link, Stainless steel



CAP880  
Side flexing slim slat top chain acetal,



BSM  
Spring plunger with internal hexagonal



GSI  
Stainless steel gas spring, Stainless steel

## Complementary products



GTC  
Belt tensioner, For standard applications



T2,5-BAR  
T type tooth bar stock, T2.5



T25-6ECO  
T type timing pulley, Economy range - T2.5 aluminium