

- Pitch 2.5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

Options


 
- Belt by the metre **T2.5M**
- Alternative lengths/widths

Accessories

- BTE arm and GTC roller belt tensioner

Info.

- When ordering, add the width to the part number
Eg: T2.5/120/4

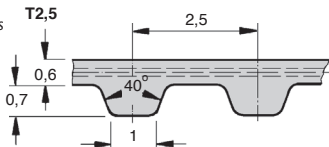

Compatible with
T2.5 pulley

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Stock*	Stock*	Price each 1 to 5 for width		
			4mm	6mm	4mm	6mm	10mm
T 2.5/120	120,00	48	✓	✓	9,07 €	10,07 €	On request
T 2.5/145	145,00	58	✓	✓	9,19 €	10,17 €	
T 2.5/160	160,00	64	✓	✓	9,22 €	10,22 €	
T 2.5/177	177,50	71	✓	✓	9,42 €	10,46 €	
T 2.5/180	180,00	72	✓	✓	9,42 €	10,46 €	
T 2.5/182	182,50	73	✓	✓	9,42 €	10,46 €	
T 2.5/200	200,00	80	✓	✓	9,42 €	10,46 €	
T 2.5/230	230,00	92	✓	✓	10,08 €	11,24 €	
T 2.5/245	245,00	98	✓	✓	10,00 €	11,12 €	
T 2.5/265	265,00	106	✓	✓	10,09 €	11,25 €	
T 2.5/285	285,00	114	✓	✓	10,15 €	11,29 €	
T 2.5/290	290,00	116	✓	✓	10,57 €	11,77 €	
T 2.5/317	317,50	127	✓	✓	10,53 €	11,71 €	
T 2.5/330	330,00	132	✓	✓	10,66 €	11,83 €	
T 2.5/380	380,00	152	✓	✓	11,25 €	12,50 €	
T 2.5/420	420,00	168	-	✓	14,35 €	12,47 €	
T 2.5/480	480,00	192	✓	✓	11,66 €	12,94 €	
T 2.5/500	500,00	200	✓	✓	11,83 €	13,13 €	
T 2.5/600	600,00	240	✓	✓	16,19 €	17,99 €	
T 2.5/620	620,00	248	-	✓	16,81 €	18,70 €	
T 2.5/650	650,00	260	-	✓	16,46 €	18,25 €	
T 2.5/780	780,00	312	✓	✓	18,97 €	21,11 €	
T 2.5/950	950,00	380	✓	-	20,96 €	23,31 €	

 
*Depending on availability - Dimensions in mm

Our other products



BCA

Steel splined collar,
Steel




LAT4

4A motorised linear
actuator, 4 amperes



RT25

 Self-centering flanged
locking assembly,
Medium/high torque



RPP14

RPP heavy duty
timing belt, RPP14



 
RBGpl

Swivel castor with
plate, Steel - grey
rubber



RBntc

Swivel castor with
central hole, Steel -
rubber - with double
brake



PB

Plastic deep groove
ball bearing, Plastic -
balls material : stainle...



RHTpls

High Temperature
Castor, up to 200kg



GP

Spring loaded toggle
latch, Standard



LBE

Miniature closed
linear bearing,
Miniature



PCF4

Conical flexible
mount, Square base
plate



gt64r

Rotating bent lever
with spring, Increased
fitting tolerances

Complementary products



GTC

Belt tensioner, For
standard applications



T2,5-BAR

T type tooth bar
stock, T2.5