

T-type timing pulley



Pitch T2,5

Aluminium

For 6mm belts



- For use with T2.5 belts
- Pitch 2.5mm
- Material:
Aluminium

Accessories

- T2.5 belts
- GTC tension rollers

Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

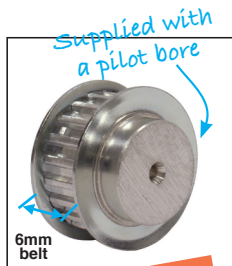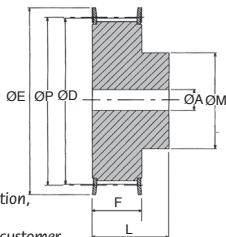

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -12%	On request	

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
12T2.5-10/ECO	12	9,60	9,00	13	13	9	16	solid	6,05 €
14T2.5-10/ECO	14	11,20	10,60	15	15	9	16	solid	6,40 €
15T2.5-10/ECO	15	12,00	11,40	15	15	9	16	solid	6,76 €
16T2.5-10/ECO	16	12,80	12,20	16	16	9	16	solid	7,10 €
18T2.5-10/ECO	18	14,40	13,80	17,5	10	10	16	solid	6,64 €
19T2.5-10/ECO	19	15,20	14,60	20	10	10	16	solid	7,03 €
20T2.5-10/ECO	20	16,00	15,40	20	11	10	16	solid	7,10 €
22T2.5-10/ECO	22	17,60	17,00	22	11	10	16	solid	6,64 €
24T2.5-10/ECO	24	19,15	18,55	22	12	10	16	4	7,25 €
25T2.5-10/ECO	25	19,95	19,35	25	13	10	16	4	7,45 €
26T2.5-10/ECO	26	20,75	20,15	26	14	10	16	4	7,74 €
28T2.5-10/ECO	28	22,35	21,75	26	14	10	16	4	8,09 €
30T2.5-10/ECO	30	23,95	23,35	26	16	10	16	6	8,49 €
32T2.5-10/ECO	32	25,55	24,95	32	16	10	16	6	6,54 €
36T2.5-10/ECO	36	28,75	28,10	36	20	10	16	6	7,25 €
40T2.5-10/ECO	40	31,90	31,30	38	22	10	16	6	7,95 €
44T2.5-10/ECO	44	35,10	34,50	-	24	10	16	6	8,80 €
48T2.5-10/ECO	48	38,30	37,70	-	26	10	16	6	8,09 €
60T2.5-10/ECO	60	47,85	47,25	-	34	10	16	8	10,81 €

Dimensions in mm

Our other products



CHTRB

Single and dual output gearboxes, Up to 4,7 Nm



HTD8M_30

HTD Heavy duty timing pulley, HTD8 Cast



UTKswr

Utilitak® V rail, V rail



RT25

Self-centering flanged locking assembly, Medium/high torque



VAP

Magnetic stud with central hole, With central hole



PVL

Small lobed handle, Polyamide



NSO

Housing for open linear bearing, Opened - long



UGH32

H Type Guide units, For Ø32 actuators



CLSCLP

Clevis components, short version, Steel -



ACL-PLAngle

Joining plate for aluminium profile,



QNU

Single row cylindrical roller bearing, Free



DCG

 
Suction cup, 2.5 bellows, silicon

Complementary products



GTC

Belt tensioner, For standard applications



T2

T type timing belt, T2.5 Steel cored polyurethane



T2,5-BAR

T type tooth bar stock, T2.5



T2

T type timing belt, T2.5 Steel cored polyurethane