

T-type timing pulley



Pitch T2,5

Aluminium

For 6mm belts



- For use with T2.5 belts
- Pitch 2.5mm
- Material:
Aluminium

Accessories

- T2.5 belts
- GTC tension rollers

Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this product

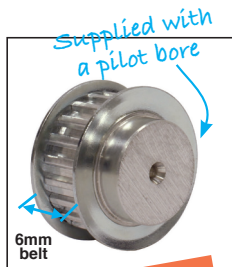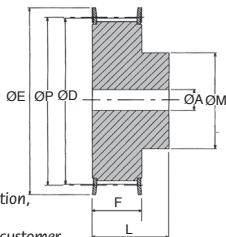

Economy range

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -12%	On request	

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
12T2.5-10/ECO	12	9,60	9,00	13	13	9	16	solid	6,05 €
14T2.5-10/ECO	14	11,20	10,60	15	15	9	16	solid	6,40 €
15T2.5-10/ECO	15	12,00	11,40	15	15	9	16	solid	6,76 €
16T2.5-10/ECO	16	12,80	12,20	16	16	9	16	solid	7,10 €
18T2.5-10/ECO	18	14,40	13,80	17,5	10	10	16	solid	6,64 €
19T2.5-10/ECO	19	15,20	14,60	20	10	10	16	solid	7,03 €
20T2.5-10/ECO	20	16,00	15,40	20	11	10	16	solid	7,10 €
22T2.5-10/ECO	22	17,60	17,00	22	11	10	16	solid	6,64 €
24T2.5-10/ECO	24	19,15	18,55	22	12	10	16	4	7,25 €
25T2.5-10/ECO	25	19,95	19,35	25	13	10	16	4	7,45 €
26T2.5-10/ECO	26	20,75	20,15	26	14	10	16	4	7,74 €
28T2.5-10/ECO	28	22,35	21,75	26	14	10	16	4	8,09 €
30T2.5-10/ECO	30	23,95	23,35	26	16	10	16	6	8,49 €
32T2.5-10/ECO	32	25,55	24,95	32	16	10	16	6	6,54 €
36T2.5-10/ECO	36	28,75	28,10	36	20	10	16	6	7,25 €
40T2.5-10/ECO	40	31,90	31,30	38	22	10	16	6	7,95 €
44T2.5-10/ECO	44	35,10	34,50	-	24	10	16	6	8,80 €
48T2.5-10/ECO	48	38,30	37,70	-	26	10	16	6	8,09 €
60T2.5-10/ECO	60	47,85	47,25	-	34	10	16	8	10,81 €

Dimensions in mm

Our other products



AT10-50ECO

AT type timing pulley,
Economy range -
AT10 aluminium




BH01

Single housed
bearing, Bearing fitted
with adhesive



PCS37K

 Chain sprocket with
hardened teeth,
9.525mm (DIN06B-1)



RPP

Connecting plate for
RPP type timing belts,
RRP5



PTMR

Telescopic furniture
foot, threaded stud



 
WSS

Symmetrical S shaped
hook, Steel



PRF_BR

Clamp for aluminium
profile, Clamp for
profile



KM

Bearing locknut,
Locknut KM



APBC

Circular rod, Round
rod



ZG1

Plastic spur gear,
Machined plastic



BABS

630 Stainless steel
compact ball pin,



YG0

 
HEAVY DUTY spur
gear, Steel 35NCD6

Complementary products



GTC

Belt tensioner, For
standard applications



T2

T type timing belt,
T2.5 Steel cored
polyurethane



T2,5-BAR

T type tooth bar
stock, T2.5



T2

T type timing belt,
T2.5 Steel cored
polyurethane