


- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
 - Steel piano wire conforming to DIN 17223 Class C No 1.1200
 - Stainless steel piano wire conforming to DIN 17224 No 1.4310 (Stainless steel 302 AMS)



steel or stainless steel

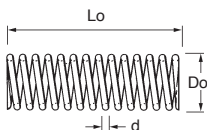

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-10%	On request

Part number	Ø	Free length	Stock*	Stock*	Price each 1 to 5			
					Steel	S/steel		
Steel	S/steel	Outside Do	Wire Ø d	Lo	Steel	S/steel		
T39000	T49000	2,40	0,40	1000	✓	✓	22,36 €	26,83 €
T39010	T49010	3,40	0,40	1000	-	✓	22,36 €	26,83 €
T39020	T49020	3,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39030	T49030	5,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39040	T49040	4,53	0,63	1000	✓	✓	30,17 €	34,27 €
T39050	T49050	7,03	0,63	1000	✓	✓	30,17 €	34,27 €
T39060	T49060	5,50	0,80	1000	✓	✓	31,72 €	40,69 €
T39070	T49070	9,00	0,80	1000	✓	✓	31,72 €	40,69 €
T39080	T49080	7,00	1,00	1000	⚠	✓	34,27 €	42,01 €
T39090	T49090	11,00	1,00	1000	✓	✓	34,27 €	42,01 €
T39100	T49100	8,55	1,25	1000	✓	-	38,36 €	51,11 €
T39110	T49110	13,05	1,25	1000	✓	-	38,36 €	51,11 €
T39120	T49120	11,00	1,60	1000	✓	-	40,69 €	56,24 €
T39130	T49130	17,00	1,60	1000	✓	✓	40,69 €	56,24 €
T39140	T49140	14,00	2,00	1000	✓	-	42,01 €	136,00 €
T39150	T49150	22,00	2,00	1000	✓	-	42,01 €	136,00 €
T39160	T49160	15,00	2,20	1000	✓	-	46,80 €	88,19 €
T39170	T49170	24,00	2,20	1000	⚠	-	46,80 €	88,19 €
T39180	T49180	18,00	2,50	1000	✓	✓	49,66 €	103,81 €
T39190	T49190	28,00	2,50	1000	-	-	49,66 €	103,81 €
T39200	T49200	20,00	2,80	1000	✓	-	53,51 €	122,08 €
T39210	T49210	30,00	2,80	1000	✓	-	53,51 €	122,08 €
T39220	T49220	22,00	3,20	1000	-	-	56,24 €	202,14 €
T39230	T49230	36,00	3,20	1000	✓	-	56,24 €	202,14 €

*Depending on availability - Dimensions in mm

Our other products




PRF4545

Standard stainless steel profile, 45 x 45 mm



PDD

 Actuating plunger, Non-rotating detector shaft



AC

Strike for toggle latch, 18mm



PRF_GAL

Roller for aluminium profile, Flat roller



MEP

Revolving handle for handwheel, Fixed



J52

Spur gear coaxial gearbox, from 0.27 to 0.90 Nm - In-line



LVT

Miniature motorised actuator 4A, 4 amperes



H3

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



SH2

Parallel axis helical gear, Steel 20NCD2



RFK38C

Hypoid gearbox - Stainless steel, up to 200 Nm



RFK58C

Hypoid gearbox - Stainless steel, up to 500 Nm



SSG2_304L

Stainless steel spur gear, Stainless steel 304L

Complementary products



T39_T49

Extension spring in metre length stainless steel, by the metre



ETGamme

Extension springs DIN2097, DIN 2097