


- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
 - Steel piano wire conforming to DIN 17223 Class C No 1.1200
 - Stainless steel piano wire conforming to DIN 17224 No 1.4310 (Stainless steel 302 AMS)



steel or stainless steel

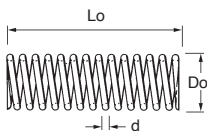

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-10%	On request

Part number	Ø	Free length	Stock*	Stock*	Price each 1 to 5			
					Steel	S/steel		
Steel	S/steel	Outside Do	Wire Ø d	Lo	Steel	S/steel		
T39000	T49000	2,40	0,40	1000	✓	✓	22,36 €	26,83 €
T39010	T49010	3,40	0,40	1000	-	✓	22,36 €	26,83 €
T39020	T49020	3,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39030	T49030	5,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39040	T49040	4,53	0,63	1000	✓	✓	30,17 €	34,27 €
T39050	T49050	7,03	0,63	1000	✓	✓	30,17 €	34,27 €
T39060	T49060	5,50	0,80	1000	✓	✓	31,72 €	40,69 €
T39070	T49070	9,00	0,80	1000	✓	✓	31,72 €	40,69 €
T39080	T49080	7,00	1,00	1000	⚠	✓	34,27 €	42,01 €
T39090	T49090	11,00	1,00	1000	✓	✓	34,27 €	42,01 €
T39100	T49100	8,55	1,25	1000	✓	-	38,36 €	51,11 €
T39110	T49110	13,05	1,25	1000	✓	-	38,36 €	51,11 €
T39120	T49120	11,00	1,60	1000	✓	-	40,69 €	56,24 €
T39130	T49130	17,00	1,60	1000	✓	✓	40,69 €	56,24 €
T39140	T49140	14,00	2,00	1000	✓	-	42,01 €	136,00 €
T39150	T49150	22,00	2,00	1000	✓	-	42,01 €	136,00 €
T39160	T49160	15,00	2,20	1000	✓	-	46,80 €	88,19 €
T39170	T49170	24,00	2,20	1000	⚠	-	46,80 €	88,19 €
T39180	T49180	18,00	2,50	1000	✓	✓	49,66 €	103,81 €
T39190	T49190	28,00	2,50	1000	-	-	49,66 €	103,81 €
T39200	T49200	20,00	2,80	1000	✓	-	53,51 €	122,08 €
T39210	T49210	30,00	2,80	1000	✓	-	53,51 €	122,08 €
T39220	T49220	22,00	3,20	1000	-	-	56,24 €	202,14 €
T39230	T49230	36,00	3,20	1000	✓	-	56,24 €	202,14 €

 
*Depending on availability - Dimensions in mm

Our other products



PRF_ROUL_F

Castor for aluminium profile, With brake



PRF_TOOL

Assembly key for aluminium profile, Assembly key



HW_HT

Half-rail guide, Rail



PW_PWG3

Worm - precision range, Steel



SBF

Sealed flange bearing unit for Food Industry, cover



YG0

HEAVY DUTY spur gear, Steel 35NCD6



BPHRF

Ball transfer unit housed spring loaded, High



GP

Spring loaded toggle latch, Standard



RAGFLOW

Floway2® roller track, Roller track



ACM_TRI

Manual bonnet fastener, Black rubber fastener



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm



RFV63

Stainless steel worm and wheel gearbox, up to 152 Nm

Complementary products



T39_T49

Extension spring in metre length steel, by the metre



ETGamme

Extension springs DIN2097, DIN 2097