


- Spring to be cut to desired length
- Length each: 1000mm
- Materials:
 - Steel piano wire conforming to DIN 17223 Class C No 1.1200
 - Stainless steel piano wire conforming to DIN 17224 No 1.4310 (Stainless steel 302 AMS)



steel or stainless steel

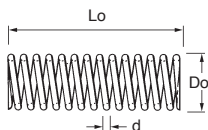

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-10%	On request

Part number	Ø	Free length	Stock*	Stock*	Price each 1 to 5			
					Steel	S/steel		
Steel	S/steel	Outside Do	Wire Ø d	Lo	Steel	S/steel		
T39000	T49000	2,40	0,40	1000	✓	✓	22,36 €	26,83 €
T39010	T49010	3,40	0,40	1000	-	✓	22,36 €	26,83 €
T39020	T49020	3,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39030	T49030	5,50	0,50	1000	✓	✓	26,83 €	31,72 €
T39040	T49040	4,53	0,63	1000	✓	✓	30,17 €	34,27 €
T39050	T49050	7,03	0,63	1000	✓	✓	30,17 €	34,27 €
T39060	T49060	5,50	0,80	1000	✓	✓	31,72 €	40,69 €
T39070	T49070	9,00	0,80	1000	✓	✓	31,72 €	40,69 €
T39080	T49080	7,00	1,00	1000	⚠	✓	34,27 €	42,01 €
T39090	T49090	11,00	1,00	1000	✓	✓	34,27 €	42,01 €
T39100	T49100	8,55	1,25	1000	✓	-	38,36 €	51,11 €
T39110	T49110	13,05	1,25	1000	✓	-	38,36 €	51,11 €
T39120	T49120	11,00	1,60	1000	✓	-	40,69 €	56,24 €
T39130	T49130	17,00	1,60	1000	✓	✓	40,69 €	56,24 €
T39140	T49140	14,00	2,00	1000	✓	-	42,01 €	136,00 €
T39150	T49150	22,00	2,00	1000	✓	-	42,01 €	136,00 €
T39160	T49160	15,00	2,20	1000	✓	-	46,80 €	88,19 €
T39170	T49170	24,00	2,20	1000	⚠	-	46,80 €	88,19 €
T39180	T49180	18,00	2,50	1000	✓	✓	49,66 €	103,81 €
T39190	T49190	28,00	2,50	1000	-	-	49,66 €	103,81 €
T39200	T49200	20,00	2,80	1000	✓	-	53,51 €	122,08 €
T39210	T49210	30,00	2,80	1000	✓	-	53,51 €	122,08 €
T39220	T49220	22,00	3,20	1000	-	-	56,24 €	202,14 €
T39230	T49230	36,00	3,20	1000	✓	-	56,24 €	202,14 €

*Depending on availability - Dimensions in mm

Our other products



PF45
Worm and wheel gear reducer, up to 40 Nm



DB
Steel bevel gear, 2:1



RTK
BoWex® curved tooth gear coupling, Nylon and steel



LVT
Miniature motorised actuator 2A, 2 ampers



E20
Right angle helical reducers, from 0.60 to 3.84 Nm



ACLEPP
Right angled bracket for aluminium profile, 4 holes




RT61
Self-centering locking Assembly, Medium/low torque



DCA
Suction cup, 1.5 bellows, nitrile



HG5
Steel spur gear, Steel 20NCD2

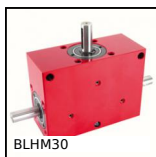

BLHM30
Right angled gearbox, double output shafts,



PGM52-M4
Pull handle, Aluminium



TFR
Rigid manual tensioner, Fixed

Complementary products



T39_T49
Extension spring in metre length steel, by the metre



ETGamme
Extension springs DIN2097, DIN 2097