

Aluminium

Pitch  
T5

**Economy range**



For 10mm belts



- For use with T5 belts
- Pitch 5mm
- Material: Aluminium

### Accessories

- T5 belts
- GTC tension rollers

### Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this products

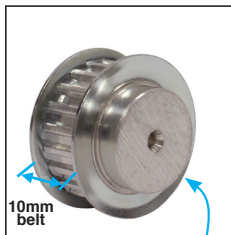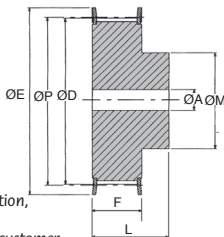

*Supplied with a pilot bore*

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
10T5-15/ECO	10	15,92	15,05	19,5	8	15	21	solid	3,96 €
12T5-15/ECO	12	19,10	18,25	23	11	15	21	solid	4,45 €
14T5-15/ECO	14	22,29	21,45	25	13	15	21	solid	4,86 €
15T5-15/ECO	15	23,88	23,05	28	16	15	21	6	5,22 €
16T5-15/ECO	16	25,47	24,60	32	18	15	21	6	5,78 €
18T5-15/ECO	18	28,65	27,80	32	20	15	21	6	6,13 €
19T5-15/ECO	19	30,25	29,40	36	22	15	21	6	6,76 €
20T5-15/ECO	20	31,83	31,00	36	23	15	21	6	7,10 €
22T5-15/ECO	22	35,02	34,15	38	24	15	21	6	8,09 €
24T5-15/ECO	24	38,21	37,40	42	26	15	21	6	8,64 €
25T5-15/ECO	25	39,80	38,95	44	26	15	21	6	9,21 €
26T5-15/ECO	26	41,39	40,60	44	26	15	21	6	9,98 €
27T5-15/ECO	27	42,98	42,20	48	30	15	21	8	10,33 €
28T5-15/ECO	28	44,58	43,75	48	32	15	21	8	11,04 €
30T5-15/ECO	30	47,76	46,95	51	34	15	21	8	11,81 €
32T5-15/ECO	32	50,94	50,10	54	38	15	21	8	13,30 €
36T5-15/ECO	36	57,31	56,45	64	38	15	21	8	15,37 €
40T5-15/ECO	40	63,66	62,85	66,5	40	15	21	8	17,48 €
42T5-15/ECO	42	66,86	66,00	70	40	15	21	8	18,80 €
44T5-15/ECO	44	70,05	69,20	-	45	15	21	8	18,88 €
48T5-15/ECO	48	76,42	75,55	-	50	15	21	8	21,26 €
60T5-15/ECO	60	95,52	94,65	-	65	15	21	8	31,70 €

Dimensions in mm

## Our other products



OP3\_14\_06  
Reducing sleeve for  
OP indicators,  
Reduction socket



IN2  
Internal gear, Steel  
20NCD2




BDP1R  
Adjustable support  
arm, Single clamp




WW20  
Drylin® W slide, slide  
assembly



 BOX-INS-W  
Box set of self tapping  
inserts, Boxed set -  
For wood



LAT1  
1A motorised linear  
actuator, 1 ampere

 

PTR  
Idle chain sprocket,  
For standard  
applications



VLBS  
Folding lifting ring for  
welding, Folding - for  
welding



 
PDD  
Spring plunger, With  
sensor adaptor



ERC  
Quick fitting cable  
terminal, Eye version



ZB  
Shaft for linear  
guides, Hardened  
ground stainless steel



SBF  
Open flange bearing  
unit for food industry,  
cover


## Complementary products



 GTC  
Belt tensioner, For  
standard applications



T5-BAR  
T type tooth bar  
stock, T5



T5courroie  
T type timing belt, T5  
Steel cored  
polyurethane



AT5M AT10M  
AT type timing belt  
per metre, AT5 Steel  
cored polyurethane