

Aluminium

Pitch
T5

Economy range





- For use with T5 belts
- Pitch 5mm
- Material:
Aluminium

Accessories

- T5 belts
- GTC tension rollers

Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this products

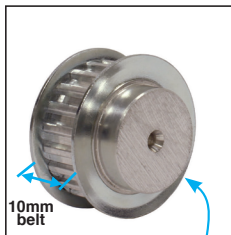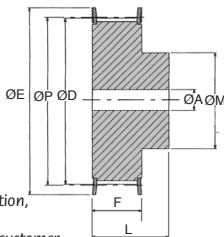

Supplied with a pilot bore

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
10T5-15/ECO	10	15,92	15,05	19,5	8	15	21	solid	3,96 €
12T5-15/ECO	12	19,10	18,25	23	11	15	21	solid	4,45 €
14T5-15/ECO	14	22,29	21,45	25	13	15	21	solid	4,86 €
15T5-15/ECO	15	23,88	23,05	28	16	15	21	6	5,22 €
16T5-15/ECO	16	25,47	24,60	32	18	15	21	6	5,78 €
18T5-15/ECO	18	28,65	27,80	32	20	15	21	6	6,13 €
19T5-15/ECO	19	30,25	29,40	36	22	15	21	6	6,76 €
20T5-15/ECO	20	31,83	31,00	36	23	15	21	6	7,10 €
22T5-15/ECO	22	35,02	34,15	38	24	15	21	6	8,09 €
24T5-15/ECO	24	38,21	37,40	42	26	15	21	6	8,64 €
25T5-15/ECO	25	39,80	38,95	44	26	15	21	6	9,21 €
26T5-15/ECO	26	41,39	40,60	44	26	15	21	6	9,98 €
27T5-15/ECO	27	42,98	42,20	48	30	15	21	8	10,33 €
28T5-15/ECO	28	44,58	43,75	48	32	15	21	8	11,04 €
30T5-15/ECO	30	47,76	46,95	51	34	15	21	8	11,81 €
32T5-15/ECO	32	50,94	50,10	54	38	15	21	8	13,30 €
36T5-15/ECO	36	57,31	56,45	64	38	15	21	8	15,37 €
40T5-15/ECO	40	63,66	62,85	66,5	40	15	21	8	17,48 €
42T5-15/ECO	42	66,86	66,00	70	40	15	21	8	18,80 €
44T5-15/ECO	44	70,05	69,20	-	45	15	21	8	18,88 €
48T5-15/ECO	48	76,42	75,55	-	50	15	21	8	21,26 €
60T5-15/ECO	60	95,52	94,65	-	65	15	21	8	31,70 €

Dimensions in mm

Our other products



RBGtc

Swivel castor with central hole, Steel - grey rubber



VDS

Sliding lock adjustment system, Sliding lock for oblong hole



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



GLT3-46

Telescopic drawer,



RBGtc

Swivel castor with central hole, Steel - grey rubber - with double b...



PO

Pull handle - Multi-selector, Tapped recessed insert



 
RHTplss

High Temperature Castor, up to 200kg



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



IN1

Internal gear, Machined plastic



ATZY

Diabolo shaped elastomount, Steel



T5M T10M

T type timing belt per metre, T5 Steel cored



GG1

Ground spur gear, Heat treated steel

Complementary products



 
GTC

Belt tensioner, For standard applications



T5-BAR

T type tooth bar stock, T5



T5courroie

T type timing belt, T5 Steel cored polyurethane



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane