

Aluminium

Pitch
T5

Economy range





- For use with T5 belts
- Pitch 5mm
- Material: Aluminium

Accessories

- T5 belts
- GTC tension rollers

Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this products

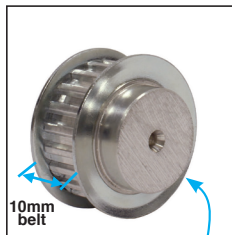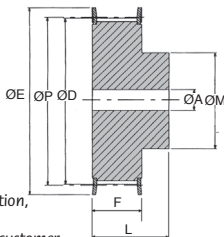

Supplied with a pilot bore

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
10T5-15/ECO	10	15,92	15,05	19,5	8	15	21	solid	3,96 €
12T5-15/ECO	12	19,10	18,25	23	11	15	21	solid	4,45 €
14T5-15/ECO	14	22,29	21,45	25	13	15	21	solid	4,86 €
15T5-15/ECO	15	23,88	23,05	28	16	15	21	6	5,22 €
16T5-15/ECO	16	25,47	24,60	32	18	15	21	6	5,78 €
18T5-15/ECO	18	28,65	27,80	32	20	15	21	6	6,13 €
19T5-15/ECO	19	30,25	29,40	36	22	15	21	6	6,76 €
20T5-15/ECO	20	31,83	31,00	36	23	15	21	6	7,10 €
22T5-15/ECO	22	35,02	34,15	38	24	15	21	6	8,09 €
24T5-15/ECO	24	38,21	37,40	42	26	15	21	6	8,64 €
25T5-15/ECO	25	39,80	38,95	44	26	15	21	6	9,21 €
26T5-15/ECO	26	41,39	40,60	44	26	15	21	6	9,98 €
27T5-15/ECO	27	42,98	42,20	48	30	15	21	8	10,33 €
28T5-15/ECO	28	44,58	43,75	48	32	15	21	8	11,04 €
30T5-15/ECO	30	47,76	46,95	51	34	15	21	8	11,81 €
32T5-15/ECO	32	50,94	50,10	54	38	15	21	8	13,30 €
36T5-15/ECO	36	57,31	56,45	64	38	15	21	8	15,37 €
40T5-15/ECO	40	63,66	62,85	66,5	40	15	21	8	17,48 €
42T5-15/ECO	42	66,86	66,00	70	40	15	21	8	18,80 €
44T5-15/ECO	44	70,05	69,20	-	45	15	21	8	18,88 €
48T5-15/ECO	48	76,42	75,55	-	50	15	21	8	21,26 €
60T5-15/ECO	60	95,52	94,65	-	65	15	21	8	31,70 €

Dimensions in mm

Our other products



GLB
Small 6 lobe female handle,
Technopolymer -
Stainless steel



BG
Oldham coupling,
With set screw



DFG
Flat suction cup,
nitrile



ACL-PLAngle
Joining plate for
aluminium profile,
Angle connection



BTCW
Cap for square tube to
be welded, To be
welded



SRP
Slotted spring pin
ISO8752, Split ISO
8752




UGAC_UGET
Actuator guide kit,
Coupling for threaded
cylinder end



F7-I
Multifunction display,
With internal sensor



 SH3
Parallel axis helical
gear, Machined plastic
(delrin)



RPP14
RPP heavy duty
timing belt, RPP14



HLC28
Right angle spiro
bevel gearbox, Up to
182Nm



DOMI80
Domino 80 adjustable
slide, Slide DOMILINE
80 with counter and
handw...

 
Complementary products



GTC
Belt tensioner, For
standard applications



T5-BAR
T type tooth bar
stock, T5



T5courroie
T5 type timing belt, T5
Steel cored
polyurethane



AT5M AT10M
AT type timing belt
per metre, AT5 Steel
cored polyurethane