

Aluminium

Pitch
T5

Economy range



For 10mm belts



- For use with T5 belts
- Pitch 5mm
- Material: Aluminium

Accessories

- T5 belts
- GTC tension rollers

Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- We are unable to modify this products

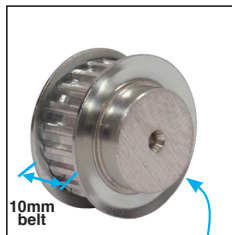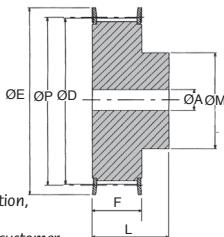

Supplied with a pilot bore

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	ØP PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
10T5-15/ECO	10	15,92	15,05	19,5	8	15	21	solid	3,96 €
12T5-15/ECO	12	19,10	18,25	23	11	15	21	solid	4,45 €
14T5-15/ECO	14	22,29	21,45	25	13	15	21	solid	4,86 €
15T5-15/ECO	15	23,88	23,05	28	16	15	21	6	5,22 €
16T5-15/ECO	16	25,47	24,60	32	18	15	21	6	5,78 €
18T5-15/ECO	18	28,65	27,80	32	20	15	21	6	6,13 €
19T5-15/ECO	19	30,25	29,40	36	22	15	21	6	6,76 €
20T5-15/ECO	20	31,83	31,00	36	23	15	21	6	7,10 €
22T5-15/ECO	22	35,02	34,15	38	24	15	21	6	8,09 €
24T5-15/ECO	24	38,21	37,40	42	26	15	21	6	8,64 €
25T5-15/ECO	25	39,80	38,95	44	26	15	21	6	9,21 €
26T5-15/ECO	26	41,39	40,60	44	26	15	21	6	9,98 €
27T5-15/ECO	27	42,98	42,20	48	30	15	21	8	10,33 €
28T5-15/ECO	28	44,58	43,75	48	32	15	21	8	11,04 €
30T5-15/ECO	30	47,76	46,95	51	34	15	21	8	11,81 €
32T5-15/ECO	32	50,94	50,10	54	38	15	21	8	13,30 €
36T5-15/ECO	36	57,31	56,45	64	38	15	21	8	15,37 €
40T5-15/ECO	40	63,66	62,85	66,5	40	15	21	8	17,48 €
42T5-15/ECO	42	66,86	66,00	70	40	15	21	8	18,80 €
44T5-15/ECO	44	70,05	69,20	-	45	15	21	8	18,88 €
48T5-15/ECO	48	76,42	75,55	-	50	15	21	8	21,26 €
60T5-15/ECO	60	95,52	94,65	-	65	15	21	8	31,70 €

 
Dimensions in mm

Our other products



HAS

Captive C washer,
Slotted flat headed
shoulder screw



RPP14

RPP heavy duty
timing belt, RPP14



SA_SAKH

Housing for linear
bearing, Closed - light
load



WJUM16

Drylin® W bearing
block, Slide



RURp

Swivel castor with
double brake,
Polyurethane -
Aluminium rim (Free



TBEASE10

Economic mini-table
with trapezoidal
leadscrew, 1kg



BOX-TOR-G

Box set of Nitrile O-
rings in nitrile, 3.00 x
1.50mm to 30.20 x
3.00



F7-I

Multifunction display,
With internal sensor



VTA

Vari-Tork® slip
friction clutch, 0.53 to



GLP

Small 6 lobe threaded
handle - male,



CHN_CHNSS

Straight long link
chain, Galvanised



GG1

Ground spur gear,
Heat treated steel

Complementary products



 
GTC

Belt tensioner, For
standard applications



T5-BAR

T type tooth bar
stock, T5



T5courroie

T type timing belt, T5
Steel cored
polyurethane



AT5M AT10M

AT type timing belt
per metre, AT5 Steel
cored polyurethane