

# T-type timing pulley



## Pitch T5

## Aluminium



For 16mm belts


- For use with T5 belts
- Pitch 5mm
- Material:  
Aluminium

### Accessories

- T5 belts
- GTC tension rollers

### Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

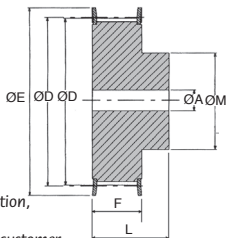

**Economy range**



*Supplied with a pilot bore*

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	Ø PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
10T5-21/ECO	10	15,92	15,05	19,5	8	21	27	solid	4,31 €
12T5-21/ECO	12	19,10	18,25	23	11	21	27	solid	5,07 €
14T5-21/ECO	14	22,29	21,45	25	13	21	27	solid	5,56 €
15T5-21/ECO	15	23,88	23,05	28	16	21	27	6	6,13 €
16T5-21/ECO	16	25,47	24,60	32	18	21	27	6	6,64 €
18T5-21/ECO	18	28,65	27,80	32	20	21	27	6	7,10 €
19T5-21/ECO	19	30,25	29,40	36	22	21	27	6	7,88 €
20T5-21/ECO	20	31,83	31,00	36	23	21	27	6	8,24 €
22T5-21/ECO	22	35,02	34,15	38	24	21	27	6	9,49 €
24T5-21/ECO	24	38,21	37,40	42	26	21	27	6	10,20 €
25T5-21/ECO	25	39,80	38,95	44	26	21	27	6	10,81 €
26T5-21/ECO	26	41,39	40,60	44	26	21	27	6	11,81 €
27T5-21/ECO	27	42,98	42,20	48	30	21	27	8	11,95 €
28T5-21/ECO	28	44,58	43,75	48	32	21	27	8	13,06 €
30T5-21/ECO	30	47,76	46,95	51	34	21	27	8	13,89 €
32T5-21/ECO	32	50,94	50,10	54	38	21	27	8	15,66 €
36T5-21/ECO	36	57,31	56,45	64	38	21	27	8	18,46 €
40T5-21/ECO	40	63,66	62,85	66,5	40	21	27	8	20,78 €
42T5-21/ECO	42	66,86	66,00	70	40	21	27	8	22,32 €
44T5-21/ECO	44	70,05	69,20	-	45	21	27	8	23,02 €
48T5-21/ECO	48	76,42	75,55	-	50	21	27	8	25,88 €
60T5-21/ECO	60	95,52	94,65	-	65	21	27	8	38,64 €

Dimensions in mm

## Our other products



PCS8ECO  
Chain sprocket - steel,  
8mm (DIN 05B-1)



PR40  
Articulated foot Ø40,  
Ø 40




PRES  
Manual workbench  
press accessory for  
PRES-3HR end  
PRES-4HR, Tool hol...



PP50  
Worm and wheel gear  
reducer, from 6.50 to  
12.80 Nm



 UTKswc  
Utilitrak® 3 wheels  
carriage, Series V  
precision steel wheel



RPPM  
RPP type belt per  
metre, RPP5 Steel  
cored polyurethane



CDR  
Retaining cable for  
ball pin, Retaining  
cable



UCFL  
Cast iron flanged  
bearing, Cast iron



CLR  
Straight clevis,  
Straight clevis for use  
with a male clevis



BOXdhx  
Boxed set of threaded  
dowel pins DIN7979D,  
Boxed set -



ADL\_F  
Female eye bolt  
conforms to DIN582,  
Steel




VRSSss  
Male swivelling lifting  
rings stainless steel,  
Male swivelling -...

## Complementary products



 GTC  
Belt tensioner, For  
standard applications



T5courroie  
T type timing belt, T5  
Steel cored  
polyurethane



T5-BAR  
T type tooth bar  
stock, T5



T5M\_T10M  
T type timing belt per  
metre, T5 Steel cored  
polyurethane