

# T-type timing pulley



## Pitch T5

## Aluminium



For 16mm belts


- For use with T5 belts
- Pitch 5mm
- Material:  
Aluminium

### Accessories


- T5 belts
- GTC tension rollers

### Info

- Pilot bore size given as indication, may vary between batches.
- Will require re-machining by customer
- **We are unable to modify this product**

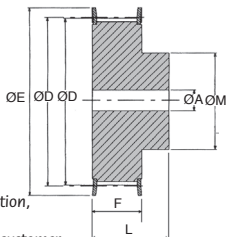

**Economy range**

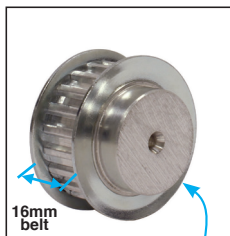

*Supplied with a pilot bore*

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No of teeth	Ø PCD	ØD external	ØE flange	ØM	F	L	Pilot bore no guaranteed ØA	Price each 1 to 5
10T5-21/ECO	10	15,92	15,05	19,5	8	21	27	solid	4,31 €
12T5-21/ECO	12	19,10	18,25	23	11	21	27	solid	5,07 €
14T5-21/ECO	14	22,29	21,45	25	13	21	27	solid	5,56 €
15T5-21/ECO	15	23,88	23,05	28	16	21	27	6	6,13 €
16T5-21/ECO	16	25,47	24,60	32	18	21	27	6	6,64 €
18T5-21/ECO	18	28,65	27,80	32	20	21	27	6	7,10 €
19T5-21/ECO	19	30,25	29,40	36	22	21	27	6	7,88 €
20T5-21/ECO	20	31,83	31,00	36	23	21	27	6	8,24 €
22T5-21/ECO	22	35,02	34,15	38	24	21	27	6	9,49 €
24T5-21/ECO	24	38,21	37,40	42	26	21	27	6	10,20 €
25T5-21/ECO	25	39,80	38,95	44	26	21	27	6	10,81 €
26T5-21/ECO	26	41,39	40,60	44	26	21	27	6	11,81 €
27T5-21/ECO	27	42,98	42,20	48	30	21	27	8	11,95 €
28T5-21/ECO	28	44,58	43,75	48	32	21	27	8	13,06 €
30T5-21/ECO	30	47,76	46,95	51	34	21	27	8	13,89 €
32T5-21/ECO	32	50,94	50,10	54	38	21	27	8	15,66 €
36T5-21/ECO	36	57,31	56,45	64	38	21	27	8	18,46 €
40T5-21/ECO	40	63,66	62,85	66,5	40	21	27	8	20,78 €
42T5-21/ECO	42	66,86	66,00	70	40	21	27	8	22,32 €
44T5-21/ECO	44	70,05	69,20	-	45	21	27	8	23,02 €
48T5-21/ECO	48	76,42	75,55	-	50	21	27	8	25,88 €
60T5-21/ECO	60	95,52	94,65	-	65	21	27	8	38,64 €

Dimensions in mm

## Our other products



LC

Friction clutch, 190 to 1800 Nm



E15

Right angle helical reducers, from 0.40 to 2.53 Nm



DB

Steel bevel gear, 2:1



BTC\_M

End cap with threaded insert for square tube, With threaded insert



PCS62

Chain sprocket - steel, 15.875 (DIN 10B-1)



PAP

Handle for aluminium profile, Ergonomic handle



BG

Oldham coupling, With set screw



BABam

Self-locking ball pin lifting ring for threaded hole, Self-locking




PSG08

Spur gear - precision range, Case hardened steel 20NCD2



TCC\_SS

 Stainless steel rigging screw (hook/hook), Stainless steel



CYS

Internal circlip DIN472, internal DIN 472



BTC20\_10


End cap for rectangular tube, Standard

## Complementary products



 GTC

Belt tensioner, For standard applications



T5courroie

T type timing belt, T5 Steel cored polyurethane



T5-BAR

T type tooth bar stock, T5



T5M\_T10M

T type timing belt per metre, T5 Steel cored polyurethane