

T-type timing pulley



Pitch T5

Aluminium

Belt width 6mm

- Pitch 5mm

- Materials:



Pulley: Aluminium 6082

Flanges: Aluminium for pulleys with up to 46 teeth, steel for 47 teeth or more

- All pulleys have flanges

Options

- Choose from 10 to 150 teeth

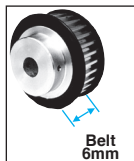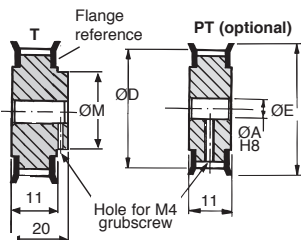

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	PCD (mm)	ØD (mm)	ØM (mm)	ØA (mm)	Flange ref.	ØE (mm)	Price each 1 to 5			
								T	PT		
10T5-11	10	15,92	15,05	12	5	11XL	23,62	On request	On request		
12T5-11	12	19,10	18,25	13	5	12XL	25,15				
14T5-11	14	22,28	21,45	16	5	14XL	28,44				
15T5-11	15	23,87	23,05	16	6	14XL	28,44				
16T5-11	16	25,46	24,60	16	6	14XL	28,44				
17T5-11	17	27,06	26,20	16	6	16XL	31,74				
18T5-11	18	28,65	27,80	20	6	18XL	34,80				
19T5-11	19	30,24	29,40	20	6	18XL	34,80				
20T5-11	20	31,83	31,00	20	6	20XL	38,10				
24T5-11	24	38,20	37,80	25	6	24XL	44,70				
25T5-11	25	39,79	39,00	25	6	24XL	44,70				
30T5-11	30	47,75	46,95	30	8	28XL	51,05				
32T5-11	32	50,93	50,10	30	8	16L	55,56				
36T5-11	36	57,30	56,45	30	8	14H	61,91				
37T5-11	37	58,89	58,05	40	8	15H	66,68				
40T5-11	40	63,66	62,85	40	8	16H	69,85				
45T5-11	45	71,62	70,80	40	8	18H	79,38				
48T5-11	48	76,39	75,55	40	8	19H	82,55				
50T5-11	50	79,58	78,75	60	10	20H	85,73				
56T5-11	56	89,13	88,30	60	10	22H	95,25				
60T5-11	60	95,49	94,65	60	10	24H	103,19				
70T5-11	70	111,41	110,60	60	10	28H	119,06				
80T5-11	80	127,32	126,50	60	10	32H	134,94				
84T5-11	84	133,69	132,85	60	10	33H	139,70				
↓ Pulleys available up to this size ↓											
150T5-11	150	dimensions : contact us									

Dimensions in mm

Our other products



KITbuh
24V DC motorisation
kit, Planetary gears



SHWbr
Washer - DIN125,
Brass



HLU
Spoked handwheel
without handle,
Aluminium



BABss
303 Stainless steel
ball pin, 303 Stainless
steel



CHN_CHNSS
Straight long link
stainless steel chain,
Stainless steel



ABL100000
Antistatic brush, For
sensitive surfaces



CLSCLP_SS
Clevis components,
short version,
Stainless steel - short
range



WSS
Symmetrical S shaped
hook, Steel



SVT_CH
Screwjack - pivot
mounting, Pivoting
bracket



APB_F
Adjusting rod for
clamp - Male,
Threaded




INS100
Self tapping inserts-
coarse thread, Coarse
thread



PTKFss
Cap nut for foot for
the food industry,
Stainless steel blind
nut - ...

 Complementary products




T5courroie
T type timing belt, T5
Steel cored
polyurethane



T5-BAR
T type tooth bar
stock, T5



T5-10ECO
T type timing pulley,
Economy range - T5
aluminium

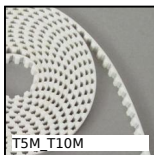

T5M_T10M
T type timing belt per
metre, T5 Steel cored
polyurethane