

# T-type timing pulley



## Pitch T5

Aluminium

Belt width 6mm

- Pitch 5mm

- Materials:



Pulley: Aluminium 6082

Flanges: Aluminium for pulleys with up to 46 teeth, steel for 47 teeth or more

- All pulleys have flanges

### Options

- Choose from 10 to 150 teeth

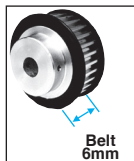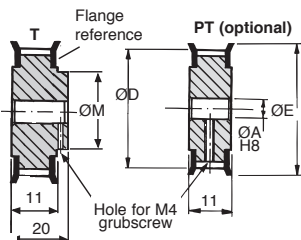

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	PCD (mm)	ØD (mm)	ØM (mm)	ØA (mm)	Flange ref.	ØE (mm)	Price each 1 to 5		
								T	PT	
10T5-11	10	15,92	15,05	12	5	11XL	23,62	On request	On request	
12T5-11	12	19,10	18,25	13	5	12XL	25,15			
14T5-11	14	22,28	21,45	16	5	14XL	28,44			
15T5-11	15	23,87	23,05	16	6	14XL	28,44			
16T5-11	16	25,46	24,60	16	6	14XL	28,44			
17T5-11	17	27,06	26,20	16	6	16XL	31,74			
18T5-11	18	28,65	27,80	20	6	18XL	34,80			
19T5-11	19	30,24	29,40	20	6	18XL	34,80			
20T5-11	20	31,83	31,00	20	6	20XL	38,10			
24T5-11	24	38,20	37,80	25	6	24XL	44,70			
25T5-11	25	39,79	39,00	25	6	24XL	44,70			
30T5-11	30	47,75	46,95	30	8	28XL	51,05			
32T5-11	32	50,93	50,10	30	8	16L	55,56			
36T5-11	36	57,30	56,45	30	8	14H	61,91			
37T5-11	37	58,89	58,05	40	8	15H	66,68			
40T5-11	40	63,66	62,85	40	8	16H	69,85			
45T5-11	45	71,62	70,80	40	8	18H	79,38			
48T5-11	48	76,39	75,55	40	8	19H	82,55			
50T5-11	50	79,58	78,75	60	10	20H	85,73			
56T5-11	56	89,13	88,30	60	10	22H	95,25			
60T5-11	60	95,49	94,65	60	10	24H	103,19			
70T5-11	70	111,41	110,60	60	10	28H	119,06			
80T5-11	80	127,32	126,50	60	10	32H	134,94			
84T5-11	84	133,69	132,85	60	10	33H	139,70			
↓ Pulleys available up to this size ↓										
150T5-11	150	dimensions : contact us								

Dimensions in mm

## Our other products



ETQ

Magnetic label holder for aluminium profile, Label holder



F7-I

Multifunction display, With internal sensor



CABPVC

PVC covered galvanised steel cable, Galvanised steel with



AFM

Flanged polymer bush, Food grade polymer



CHA35

Hinge for aluminium profile, Hinge



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg



PW\_PWG05

Worm - precision range, Stainless steel




BOX-TOR-MAX

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53



SSG1

 Stainless steel spur gear, Stainless steel 304L



RPP5

RPP heavy duty timing belt, RPP5



P30


Worm and wheel gear reducer, up to 8.80 Nm



RFV40

Stainless steel worm and wheel gearbox, up to 47 Nm

## Complementary products

 

T5courroie

T type timing belt, T5 Steel cored polyurethane



T5-BAR

T type tooth bar stock, T5



T5-10ECO

T type timing pulley, Economy range - T5 aluminium



T5M\_T10M

T type timing belt per metre, T5 Steel cored polyurethane