

# T-type timing pulley



## Pitch T5

Aluminium

Belt width 6mm

- Pitch 5mm

- Materials:



Pulley: Aluminium 6082

Flanges: Aluminium for pulleys with up to 46 teeth, steel for 47 teeth or more

- All pulleys have flanges

### Options

- Choose from 10 to 150 teeth

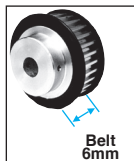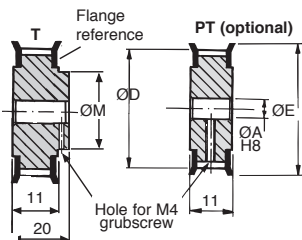

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	PCD (mm)	ØD (mm)	ØM (mm)	ØA (mm)	Flange ref.	ØE (mm)	Price each 1 to 5		
								T	PT	
10T5-11	10	15,92	15,05	12	5	11XL	23,62	On request	On request	
12T5-11	12	19,10	18,25	13	5	12XL	25,15			
14T5-11	14	22,28	21,45	16	5	14XL	28,44			
15T5-11	15	23,87	23,05	16	6	14XL	28,44			
16T5-11	16	25,46	24,60	16	6	14XL	28,44			
17T5-11	17	27,06	26,20	16	6	16XL	31,74			
18T5-11	18	28,65	27,80	20	6	18XL	34,80			
19T5-11	19	30,24	29,40	20	6	18XL	34,80			
20T5-11	20	31,83	31,00	20	6	20XL	38,10			
24T5-11	24	38,20	37,80	25	6	24XL	44,70			
25T5-11	25	39,79	39,00	25	6	24XL	44,70			
30T5-11	30	47,75	46,95	30	8	28XL	51,05			
32T5-11	32	50,93	50,10	30	8	16L	55,56			
36T5-11	36	57,30	56,45	30	8	14H	61,91			
37T5-11	37	58,89	58,05	40	8	15H	66,68			
40T5-11	40	63,66	62,85	40	8	16H	69,85			
45T5-11	45	71,62	70,80	40	8	18H	79,38			
48T5-11	48	76,39	75,55	40	8	19H	82,55			
50T5-11	50	79,58	78,75	60	10	20H	85,73			
56T5-11	56	89,13	88,30	60	10	22H	95,25			
60T5-11	60	95,49	94,65	60	10	24H	103,19			
70T5-11	70	111,41	110,60	60	10	28H	119,06			
80T5-11	80	127,32	126,50	60	10	32H	134,94			
84T5-11	84	133,69	132,85	60	10	33H	139,70			
↓ Pulleys available up to this size ↓										
150T5-11	150	dimensions : contact us								

 
Dimensions in mm

## Our other products



CMM

Male rod ends DIN ISO12240-4, Steel / bronze



CT

Telescopic universal joint, Normal duty



S20

Short housing for open linear bearing, Opened - slim



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



LF

Precision locknut, Precision locknut



KB\_OP

Open precision linear bearing, Precision - steel



CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



 
SHTC

Drylin® Linear table, Maintenance free




BOXsap

Boxed set of spring pins ISO8752, Boxed



MBrondelle

 Stop washer, Stop washer MB



RPP


Connecting plate for RPP type timing belts, Connecting plate for RPP type timing belts, Up to 9,1 Nm



PW\_PWG1

Worm - precision range, Steel

## Complementary products

 

T5courroie

T type timing belt, T5 Steel cored polyurethane



T5-BAR

T type tooth bar stock, T5



T5-10ECO

T type timing pulley, Economy range - T5 aluminium



T5M\_T10M

T type timing belt per metre, T5 Steel cored polyurethane