 


# T-type timing belt **per metre**




Pitch  
**T5**  
**T10**

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length  $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

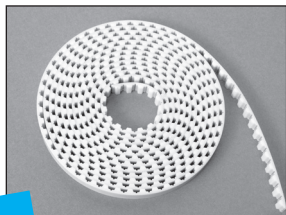

**For linear positioning**

## Uses


- Alternating back-and-forth movements

## Accessories



- Connecting plate T.../P

## Info.

- Min. length: 1000mm
  - Supplied in multiples of 1 metre
  - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

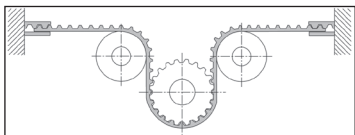

Typical application

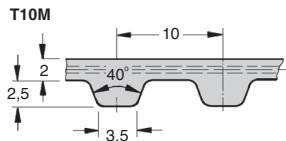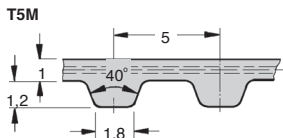

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

## Our other products



SFWR

End support, Surface mounting



PRF\_SDD\_1820

Support for Ø18 or Ø20mm Prox detector, Ø18 and Ø20



CHML50

Worm and wheel gear reducer, up to 107 Nm - Integrated torque limiter



CRM

Moulded nylon rack, Nylon




CQA30

Adjustment slide-system miniature, 30



TB\_ECO

 Eco. range steel bevel gear, 3:1



RPP

Connecting plate for RPP type timing belts, RPP14




BOX-TOR-DRING

Box set of Nitrile D-rings NBR90Sh A, Flange seals



NK40

 Drylin®N miniature guiding system, Witdh



T5courroie

T type timing belt, T5 Steel cored



CHARcav


Spring hinge, to install



AXTR

Axle for tensioner pulley, Shaft

## Complementary products

 

T5courroie

T type timing belt, T5 Steel cored polyurethane